




Quality Products. Service Excellence.

DIN Clips 1427DINCLIP Series
Nylon & Extruded Aluminum

Nylon DIN Clip (1427DINCLIP)



- Designed for mounting enclosures to 35 mm wide DIN rails
- Includes hardware (quantity 4 of a #6 X 1/4" self tapping, phillips head screw) & drilling template
- Center to center hole spacing is 1.18" (30mm)
- Material is a rugged black nylon
- Recommended maximum weight load is 35 lbs. each (70 lbs. per pair)
- Units are 1.8" (45.7mm) long, 0.4" (10.1mm) wide - overall
- Sold in packages of 2

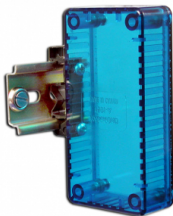

- Example: DIN Clip shown mounted to our **1591ATBU** and clipped to a panel mounted DIN rail.
- Two screws per clip.
- 35 mm wide DIN rail not included but - is available [here](#).



Heavy Duty Aluminum DIN clips

- Designed for mounting enclosures to 35 mm wide DIN rails
- Choice of three lengths
- Includes enclosure mounting hardware
- Material is clear anodized aluminum with spring steel wire
- Maximum weight capacity of 125 lbs. (56 kg) per unit



1427DIN42M



1427DIN75M



1427DIN100M

Part Number	Material	Weight Rating	Length	Width	Qty Per Package
1427DINCLIP	Nylon	35 lbs / 15.8 kg per clip	1.70	0.40	2
1427DIN42M	Aluminum	125 lbs / 56 kg	2.02	1.65	1
1427DIN75M	Aluminum	125 lbs / 56 kg	2.02	2.95	1
1427DIN100M	Aluminum	125 lbs / 56 kg	2.02	3.94	1

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Hammond:](#)

[1427DINCLIP](#) [1427DIN100M](#) [1427DIN42M](#) [1427DIN75M](#)