



Quality Products. Service Excellence.

Steel Chassis 1441 Series

Powder Coated, Real Walnut Side Option



Key Features:

- Spot welded steel - heavy duty construction chassis.
- Finished in ASA 61 smooth grey or satin black powder paint.
- Optional bottom plates are punched with 4 holes – 3/16" diameter (Chassis now includes 1/8" holes to allow installation of optional bottom plates).
- Hardware not provided, please order separately - Part number **1421J6** (Pkg. of 6, 6-32 Philips head screws).
- **Rubber feet** sold separately.
- Some models accept chassis covers (1451 series).
- UPGRADE to our Satin Black Chassis with Walnut Sides (available for some sizes, refer to table below).

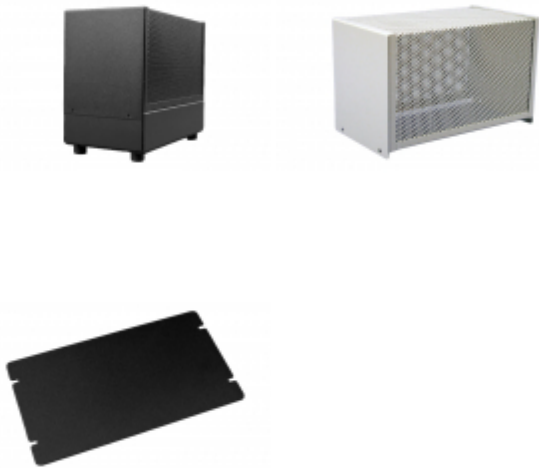


Photo Features:



Chassis available in black or gray.

Six models available with walnut sides (see table below for compatibility).



Perforated covers for most sizes. Bottom panels available for all sizes (sold separately from chassis).

Accessories

- Sheet Metal Screws

Chassis

Gray Chassis	Satin Black Chassis	Satin Black Chassis	Steel Gauge	Width	Depth	Height	Gray Bottom Panel	Satin Black Bottom Panel	Gray Perforated	Satin Black Perforated Chassis Cover
		w/ Walnut Sides							Chassis Cover	
1441-6	1441-6BK3		20	4.00	4.00	2.00	1431-6	1431-6BK3		
1441-8	1441-8BK3		20	6.00	4.00	2.00	1431-8	1431-8BK3		
1441-12	1441-12BK3	1441-12BK3CWW	20	7.00	5.00	2.00	1431-12	1431-12BK3		
1441-9	1441-9BK3		20	8.00	4.00	1.00	1431-10	1431-10BK3	1451-10	1451-10BK3
1441-10	1441-10BK3		20	8.00	4.00	2.00	1431-10	1431-10BK3	1451-10	1451-10BK3
1441-14	1441-14BK3		20	9.00	5.00	2.00	1431-14	1431-14BK3	1451-14	1451-14BK3
1441-15	1441-15BK3		20	10.00	6.00	1.00	1431-16	1431-16BK3	1451-16	1451-16BK3
1441-16	1441-16BK3	1441-16BK3CWW	20	10.00	6.00	2.00	1431-16	1431-16BK3	1451-16	1451-16BK3
1441-22	1441-22BK3	1441-22BK3CWW	20	12.00	8.00	2.00	1431-22	1431-22BK3	1451-22	1451-22BK3
1441-24	1441-24BK3	1441-24BK3CWW	20	12.00	8.00	3.00	1431-22	1431-22BK3	1451-22	1451-22BK3
1441-29	1441-29BK3		20	12.00	10.00	2.00	1431-29	1431-29BK3	1451-29	1451-29BK3
1441-18	1441-18BK3		20	13.50	5.00	2.00	1431-18	1431-18BK3		
1441-26	1441-26BK3		20	16.00	8.00	2.00	1431-26	1431-26BK3	1451-26	1451-26BK3
1441-28	1441-28BK3		20	16.00	8.00	3.00	1431-26	1431-26BK3	1451-26	1451-26BK3
1441-20	1441-20BK3		20	17.00	4.00	3.00	1431-20	1431-20BK3		
1441-30	1441-30BK3		20	17.00	10.00	2.00	1431-30	1431-30BK3	1451-30	1451-30BK3
1441-32	1441-32BK3	1441-32BK3CWW	20	17.00	10.00	3.00	1431-30	1431-30BK3	1451-30	1451-30BK3
1441-33	1441-33BK3	1441-33BK3CWW	20	17.00	10.00	4.00	1431-30	1431-30BK3	1451-30	1451-30BK3
1441-34	1441-34BK3		18	17.00	12.00	2.00	1431-34	1431-34BK3		
1441-36	1441-36BK3		18	17.00	12.00	3.00	1431-34	1431-34BK3		
1441-38	1441-38BK3		18	17.00	14.00	3.00	1431-38	1431-38BK3		
1441-40	1441-40BK3		18	17.00	14.00	4.00	1431-38	1431-38BK3		
1441-42	1441-42BK3		18	17.00	14.00	5.00	1431-38	1431-38BK3		

Hardware

Gray Chassis	Qty	Description	Note
1421J6	6	6-32 x 1/4" pan head, type C. screws	Use for attaching bottom plate to chassis
SC1440KT	25	#8 x 5/16" truss head screws and #8 serrated zinc plated lock washer	Use for attaching 1441 walnut sides (where applicable)

Tags: chassis, classic, vintage, tube, steel chassis

Data subject to change without notice

© 2025. Hammond Manufacturing Ltd. All rights reserved.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Hammond:](#)

[1441-9BK3](#) [1441-15BK3](#) [1441-40BK3](#) [1441-8BK3](#) [1431-8BK3](#) [1431-26BK3](#) [1451-26](#) [1451-26BK3](#) [1441-38BK3](#)
[1431-38BK3](#) [1431-16](#) [1431-22](#) [1431-30](#) [1431-18](#) [1431-34](#) [1431-20](#) [1431-12](#) [1431-38](#) [1431-10](#) [1431-14](#) [1431-26](#)
[1431-29](#) [1431-18BK3](#) [1441-33BK3](#) [1441-18BK3](#) [1431-6BK3](#) [1441-32](#) [1441-33](#) [1441-36](#) [1441-34](#) [1441-6BK3](#)
[1441-24BK3](#) [1441-30](#) [1441-38](#) [1441-22BK3](#) [1431-22BK3](#) [1431-12BK3](#) [1441-12BK3](#) [1441-18](#) [1441-28](#) [1441-14](#)
[1441-20](#) [1441-22](#) [1441-16](#) [1441-29](#) [1441-12](#) [1441-26](#) [1441-10](#) [1441-24](#) [1441-15](#) [1431-20BK3](#) [1441-20BK3](#)
[1451-10BK3](#) [1431-10BK3](#) [1441-10BK3](#) [1441-30BK3](#) [1431-30BK3](#) [1441-42](#) [1441-40](#) [1441-8](#) [1441-9](#) [1441-6](#) [1441-](#)
[32BK3](#) [1431-16BK3](#) [1441-16BK3](#) [1441-42BK3](#) [1431-34BK3](#) [1441-34BK3](#) [1451-14](#) [1451-10](#) [1451-30](#) [1451-16](#)
[1451-22](#) [1441-36BK3](#) [1431-6](#) [1431-8](#) [1441-28BK3](#) [1431-29BK3](#) [1441-29BK3](#) [1441-14BK3](#) [1431-14BK3](#) [1451-](#)
[14BK3](#) [1441-26BK3](#) [1451-16BK3](#) [1451-22BK3](#) [1451-29](#) [1451-29BK3](#) [1451-30BK3](#) [1441-12BK3CWW](#) [1441-](#)
[16BK3CWW](#) [1441-22BK3CWW](#) [1441-24BK3CWW](#) [1441-32BK3CWW](#) [1441-33BK3CWW](#)