



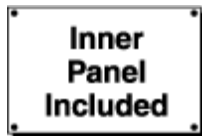

*Quality Products. Service Excellence.*

## Type 12 Modular Console Cabinet 1472 Series

### Sloped Front

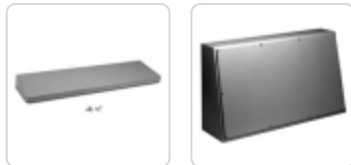

### Application

- Designed to house electrical, electronic, hydraulic or pneumatic controls and instruments
- Heavy-duty construction provides protection from dirt, dust, oil and water.
- Sloping front control and instrument panels provide an ideal surface for mounting operator controls or instrumentation.
- Interior mounting is provided for with a removable inner panel located on the rear of the basic console.

### Standards

- UL 508A Type 12
- CSA Type 12
- **Complies with**
  - NEMA Type 12
  - IEC 60529, IP65

### Base Console Construction

- Formed 14 gauge steel.
- Smooth, continuously welded seams, without knockouts, cutouts or holes.
- Sloped front instrument panel is continuously hinged on the front (bottom) edge and secured with captive panel screws, threaded into sealed wells.
- Front instrument panel may be removed by pulling the hinge pin.
- Flush doors are secured with a three point latch and operated with a key locking automotive type handle.
- Two door model has overlapping front doors, with three point latch on right door.
- Oil resistant gaskets are permanently secured.
- Includes a removable inner panel formed from 12 gauge steel, mounted to the back of the enclosure interior.
- Collar studs are provided for mounting inner panels.
- A bonding stud is provided on the door and a grounding stud is provided in the enclosure for each door.
- A literature pocket is provided.

### Turret Construction

- Formed and welded from 14 gauge steel.
- Sloping instrument panel and vertical rear access are completely removable.
- Captive panel screws fasten into sealed wells.

### Writing Surface Construction

- Formed and welded from 14 gauge steel.
- Fastens to the front of the console with screws

### Finish

- Cover and enclosure are phosphatized and finished in ANSI 61 gray powder coating on the outside and on the inside.
- Removable inner panels are finished in white powder coating.

Accessories

- Door Stop Kit
- Window Kits
- Lighting
- Type 12 Handle Kits
- Climate Control
- General Accessories

**New and improved PDF part drawing files with more detail now available.**

Click part number in table below to access PDF, DXF, and STEP files.

Base Console

Part No.	Enclosure					Panel	
	H1	H2	W	D1	D2	H	W
1472-24 <sup>1</sup>	36.00	40.00	24.00	17.00	20.00	18.75	27.25
1472-36 <sup>1</sup>	32.00	36.00	36.00	20.00	24.00	30.00	32.00
1472-48 <sup>1, 2</sup>	32.00	36.00	48.00	20.00	24.00	42.00	32.00

<sup>1</sup> UL Listed  
<sup>2</sup> 2 Door Version

Turret

Part No.	H	W	D1	D2
1472-24T	16.00	24.00	5.00	3.00
1472-36T	20.00	36.00	10.00	6.00
1472-48T	20.00	48.00	10.00	6.00

Writing Surface

Part No.	H	W	D
1472-24W	4.00	24.00	10.00
1472-36W	4.00	36.00	10.00
1472-48W	4.00	48.00	10.00

Tags: console, cabinet, Type 12, controls, interface, sloped front, hinged cover, heavy duty, writing, turret      *Data subject to change without notice*

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Hammond:](#)

[1472-48W](#) [1472-48T](#) [1472-24T](#) [1472-24](#) [1472-24W](#) [1472-48](#) [1472-36](#) [1472-36W](#) [1472-36T](#)