




Quality Products. Service Excellence.

Mild Steel and Stainless Steel Window Kits 1481WN4 Series



Features

- Maintain environmental protection level of Type 4, 4X (for stainless steel) as noted
- Window is 0.25" thick, UV resistant Polycarbonate.
- Frame is heavy gauge steel, or 304 stainless steel with integral weld studs and compression clips.
- Oil resistant neoprene gasket ensures a watertight seal.
- Finished in ANSI 61 gray recoatable powder or natural brushed stainless steel.

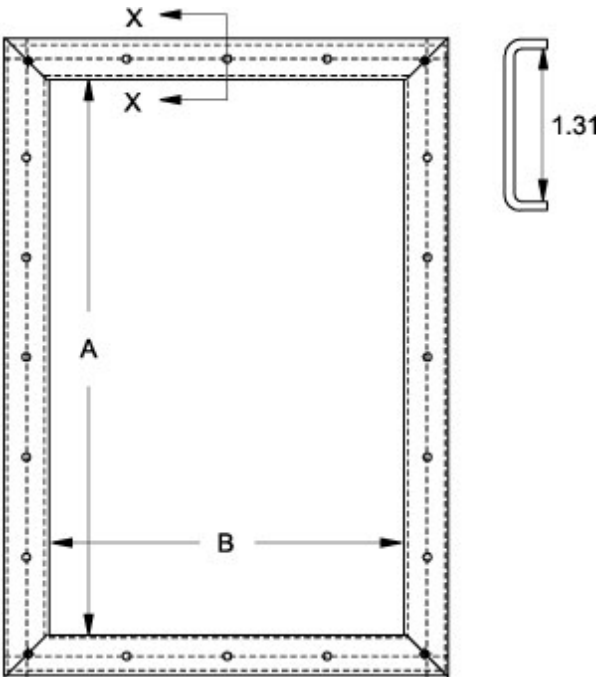

Part No.	Material	Window Dimensions		Recommended Cut-Out Size	
		A	B		
1481WN40503 ¹	Steel	5.00	3.00	6.69	4.69
1481WN40905 ¹	Steel	9.00	5.50	10.69	7.19
1481WN41303 ¹	Steel	13.00	3.00	14.69	4.69
1481WN41308 ¹	Steel	13.00	8.00	14.69	9.69
1481WN41705 ¹	Steel	17.00	5.50	18.69	7.19
1481WN41711 ¹	Steel	17.00	11.00	18.69	12.69
1481WN42315 ¹	Steel	23.00	15.00	24.69	16.69
1481WN42919 ¹	Steel	29.00	19.00	30.69	20.69
1481WN43523 ¹	Steel	35.00	23.00	36.69	24.69
1481WN4SS0503 ²	Stainless Steel	5.00	3.00	6.69	4.69
1481WN4SS0905 ²	Stainless Steel	9.00	5.50	10.69	7.19
1481WN4SS1308 ²	Stainless Steel	13.00	8.00	14.69	9.69
1481WN4SS1711 ²	Stainless Steel	17.00	11.00	18.69	12.69
1481WN4SS2315 ²	Stainless Steel	23.00	15.00	24.69	16.69
1481WN4SS2919 ²	Stainless Steel	29.00	19.00	30.69	20.69

¹ UL/ CSA Type 12 and Type 4
² UL/ CSA Type 12, Type 4 and Type 4x

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Hammond:](#)

[1481WN41308](#) [1481WN40503](#) [1481WN40905](#) [1481WN41303](#) [1481WN41705](#) [1481WN41711](#) [1481WN42315](#)
[1481WN42919](#) [1481WN43523](#) [1481WN4SS0503](#) [1481WN4SS0905](#) [1481WN4SS1308](#) [1481WN4SS1711](#)
[1481WN4SS2315](#) [1481WN4SS2919](#)