

RESETTABLE CIRCUIT BREAKER

LIGHTED ON/OFF POWER SWITCH

482.60 mm  
[19.000 in]


43.64 mm  
[1.718 in]

165.10 mm  
[6.500 in]

38.10 mm TYP  
[1.500 in]

76.20 mm TYP  
[3.000 in]

ASSEMBLY - VIEW FROM FRONT

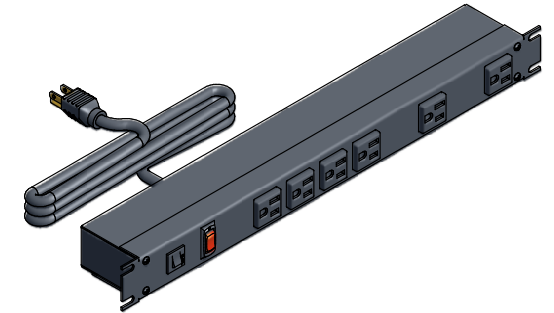

ISOMETRIC VIEW

19.05 mm  
[0.750 in]

444.50 mm  
[17.500 in]

5.08 mm  
[0.200 in]

67.58 mm  
[2.661 in]

6' FOOT POWER CORD  
(NEMA 5-15P)

ASSEMBLY - VIEW FROM BOTTOM

ASSEMBLY - VIEW FROM SIDE

**1582H6A1BK**

Finish - Front - Black Painted Steel
Back - Black Painted Steel
Rated - 125 VAC, 60 Hz, 15 Amps
Approvals - CSA Certified Standards C22.2 (No. 21-95, 42-99)
- UL Recognized Standard UL1363

**Colours & Cord Length**

1582H6A1BK - Black w/ 6' Foot Power Cord (NEMA 5-15P)
1582H6A1- ASA 61 Grey w/ 6' Foot Power Cord (NEMA 5-15P)
1582H6B1BK - Black w/ 15' Foot Power Cord (NEMA 5-15P)
1582H6B1- ASA 61 Grey w/ 15' Foot Power Cord (NEMA 5-15P)

10.31 mm  
[0.406 in]

461.98 mm  
[18.188 in]

5.97 mm  
[0.235 in]

31.70 mm  
[1.248 in]

127.00 mm  
[5.000 in]

SECTION A-A

R3.18 mm  
[0.125 in]



**HAMMOND  
MANUFACTURING™**

**1582H6A1BK**

www.hammondmfg.com

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Hammond:](#)

[1582H6A1BKRA](#) [1582H6A1BK](#) [1582H6B1](#) [1582H6A1](#) [1582H6B1BK](#)