



Quality Products. Service Excellence.

## Heavy Duty Outlet Strip 1584 Series


15A | 125V | 5-15R Outlets

### Features



- Built to meet the rugged requirements of commercial and industrial use.
- All metal housing - tough extruded aluminum case with a black powder paint coated steel cover.
- Heavy duty NEMA 5-15R receptacles.
- Mounting feet (with keyhole slots) allow temporary work station mounting if desired.
- On-Off switch is rocker type with pilot light (on units with on-off switch - listed below). A red pilot light is used to indicate power on (on units with no switch).
- [Click here for our surge protected version.](#)

### Specifications

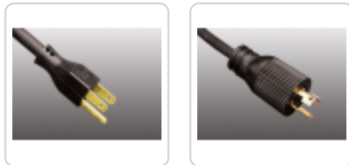

- Heavy duty 14 gauge wire cord - 14/3 SJT type for extreme temperature ranges and integral molded plug.
- Plug types available are NEMA 5-15P straight blade or NEMA L5-15P locking type (see table below).
- Includes 15 amp, 125 volt resettable circuit breaker to prevent accidental line overload.
- UL/cUL Listed Standard UL1363 file No. E166039 & CSA C22.2 No. 308-14 & CSA C22.2 No. 0.4-04



### Accessories

- Rack Cabinet Vertical Mount Adaptor

Part No.	Part No.	Overall Dimensions			Outlet Qty	Outlet NEMA Type	Rotated Outlet	Cord Length (ft)	Plug Type	Plug NEMA Type
On/Off Switch	Illuminated Light Only	Height	Width	Length						
1584H4A1	1584T4A1	2.33	2.12	10.18	4	5-15R	No	6	Straight	5-15P
1584H4A1RA	1584T4A1RA	2.33	2.13	13.36	4	5-15R	Yes	6	Straight	5-15P
1584H4B1	1584T4B1	2.33	2.12	10.18	4	5-15R	No	15	Straight	5-15P
1584H4B1RA	1584T4B1RA	2.33	2.13	13.36	4	5-15R	Yes	15	Straight	5-15P
1584H4C1	1584T4C1	2.33	2.12	10.18	4	5-15R	No	6	Locking	L5-15P
1584H4C1RA	1584T4C1RA	2.33	2.13	13.36	4	5-15R	Yes	6	Locking	L5-15P
1584H4D1	1584T4D1	2.33	2.12	10.18	4	5-15R	No	15	Locking	L5-15P
1584H4D1RA	1584T4D1RA	2.33	2.13	13.36	4	5-15R	Yes	15	Locking	L5-15P
1584H5A1	1584T5A1	2.33	2.12	13.36	5	5-15R	No	6	Straight	5-15P
1584H5B1	1584T5B1	2.33	2.12	13.36	5	5-15R	No	15	Straight	5-15P
1584H5C1	1584T5C1	2.33	2.12	13.36	5	5-15R	No	6	Locking	L5-15P
1584H5D1	1584T5D1	2.33	2.12	13.36	5	5-15R	No	15	Locking	L5-15P
1584H6A1	1584T6A1	2.33	2.12	13.36	6	5-15R	No	6	Straight	5-15P
1584H6A1RA	1584T6A1RA	2.33	2.13	16.51	6	5-15R	Yes	6	Straight	5-15P
1584H6B1	1584T6B1	2.33	2.12	13.36	6	5-15R	No	15	Straight	5-15P

Illuminated On/Off Switch Part No.	Illuminated Light Only Part No.	Overall Dimensions			Outlet Qty	Outlet NEMA Type	Rotated Outlet	Cord Length (ft)	Plug Type	Plug NEMA Type
		Height	Width	Length						
1584H6B1RA	1584T6B1RA	2.33	2.13	16.51	6	5-15R	Yes	15	Straight	5-15P
1584H6C1	1584T6C1	2.33	2.12	13.36	6	5-15R	No	6	Locking	L5-15P
1584H6C1RA	1584T6C1RA	2.33	2.13	16.51	6	5-15R	Yes	6	Locking	L5-15P
1584H6D1	1584T6D1	2.33	2.12	13.36	6	5-15R	No	15	Locking	L5-15P
1584H6D1RA	1584T6D1RA	2.33	2.13	16.51	6	5-15R	Yes	15	Locking	L5-15P
1584H7A1	1584T7A1	2.33	2.12	16.51	7	5-15R	No	6	Straight	5-15P
1584H7B1	1584T7B1	2.33	2.12	16.51	7	5-15R	No	15	Straight	5-15P
1584H7C1	1584T7C1	2.33	2.12	16.51	7	5-15R	No	6	Locking	L5-15P
1584H7D1	1584T7D1	2.33	2.12	16.51	7	5-15R	No	15	Locking	L5-15P
1584H8A1	1584T8A1	2.33	2.12	16.51	8	5-15R	No	6	Straight	5-15P
1584H8B1	1584T8B1	2.33	2.12	16.51	8	5-15R	No	15	Straight	5-15P
1584H8C1	1584T8C1	2.33	2.12	16.51	8	5-15R	No	6	Locking	L5-15P
1584H8D1	1584T8D1	2.33	2.12	16.51	8	5-15R	No	15	Locking	L5-15P

### Replacement Mounting Foot (One Foot)

Part No.
1584MF

*Data subject to change without notice*

© 2021. Hammond Manufacturing Ltd. All rights reserved.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

## Hammond:

[1584T6A1](#) [1584T6C1](#) [1584T5C1](#) [1584T5A1](#) [1584T6B1](#) [1584T6D1](#) [1584T4A1](#) [1584T4C1](#) [1584H6A1RA](#)  
[1584H4A1RA](#) [1584H4A1](#) [1584H8C1](#) [1584H8D1](#) [1584H8B1](#) [1584T7C1](#) [1584H8A1](#) [1584T4A1RA](#) [1584T5B1](#)  
[1584H4B1RA](#) [1584T7B1](#) [1584H4B1](#) [1584H4D1](#) [1584H4C1](#) [1584T7A1](#) [1584T4B1RA](#) [1584T8D1](#) [1584T8B1](#)  
[1584T6B1RA](#) [1584H5B1](#) [1584H6B1RA](#) [1584H7B1](#) [1584H7A1](#) [1584H7C1](#) [1584T6A1RA](#) [1584T4B1](#) [1584T4D1](#)  
[1584H6C1](#) [1584H6A1](#) [1584H6D1](#) [1584H6B1](#) [1584T8A1](#) [1584H5A1](#) [1584H5C1](#) [1584T8C1](#) [1584T6D1RA](#)  
[1584T6C1RA](#) [1584H4C1RA](#) [1584T4C1RA](#) [1584T4D1RA](#) [1584H6C1RA](#) [1584MF](#)