




Quality Products. Service Excellence.

Power Cords 1584C Series

Gallery

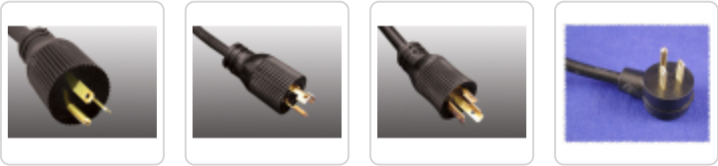

6.5 ft Cord	15.5 ft Cord						
Part No.	Part No.	Description	Amps	Cord Type	Cord Gauge	Plug Blade Type	
1584C6	1584C15	Straight Blade Molded Plug	15	SJT	14/3	NEMA 5-15P	
1584C6RP	1584C15RP	Straight Blade - 90 Degree - Right Angle Molded Plug	15	SJT	14/3	NEMA 5-15P	
1584C6S20	1584C15S20	Straight Blade Molded Plug	20	SJT	12/3	NEMA 5-20P	
1584C6TW	1584C15TW	Locking Type Molded Plug	15	SJT	14/3	NEMA L5-15P	
1584C6TW20	1584C15TW20	Locking Type Molded Plug	20	SJT	12/3	NEMA L5-20P	

All cords are SJT or equivalent.

Input Accessory Cords

Part No.	Description	Amps	Volts AC	Cord Length	Cord Type	Cord Gauge	Plug Region	Plug Blade Type	Connector Type
1581C6EU	European Schuko plug	10	250	72.00	SVT	18/3	European	Schuko	IEC 320-C13
1581C6NA250	North American Nema 6-15P plug	10	250	72.00	SJT	18/3	North America	NEMA 6-15P	IEC 320-C13
1581C6NA	North American Nema 5-15P plug	10	125	72.00	SVT	18/3	North America	NEMA 5-15P	IEC 320-C13
1581C6UK	UK (BS1363) plug	10	250	72.00	SVT	18/3	UK	BS1363	IEC 320-C13
1581C6IEC	Male & Female IEC 320-C13 Jumper Cord	10	125	72.00	SVT	18/3	Universal	IEC 320-C13	IEC 320-C14

Data subject to change without notice

© 2025. Hammond Manufacturing Ltd. All rights reserved.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Hammond:](#)

[1584C15](#) [1584C6TW](#) [1584C6](#) [1584C6TW20](#) [1584C15S20](#) [1584C6S20](#) [1584C15TW](#) [1584C15TW20](#) [1584C15RP](#)
[1584C6RP](#)