




**TOP VIEW**

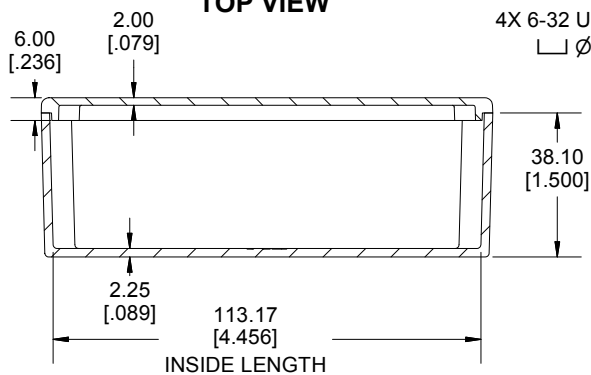

**SECTION B-B  
SIDE VIEW**

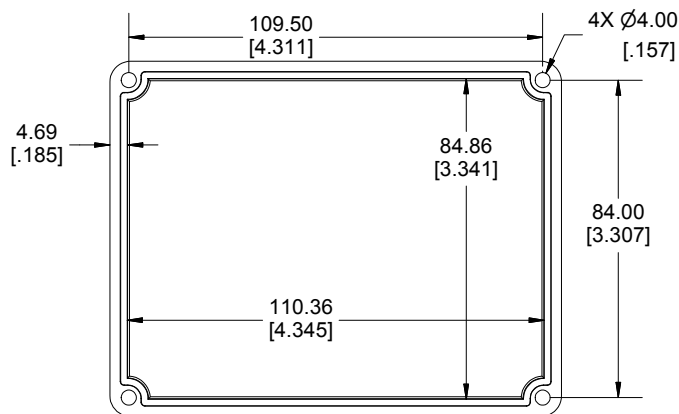


**INSIDE LID**

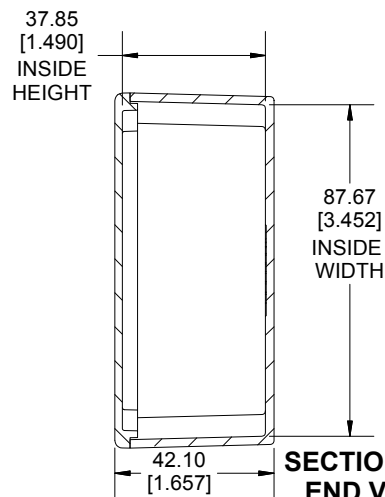


**SECTION A-A  
END VIEW**

4X 6-32 UNC  $\nabla$  11.00  
 $\sqcap$  Ø3.90  $\nabla$  3.00

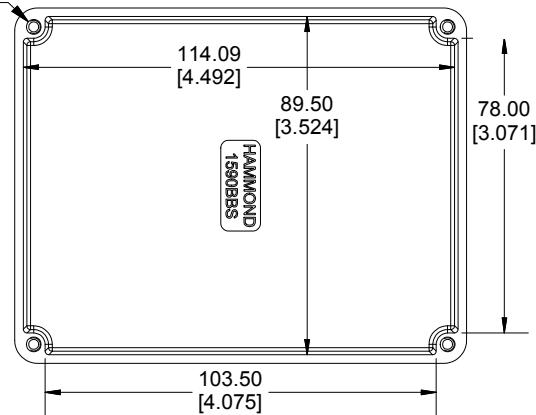

**INSIDE BOX**

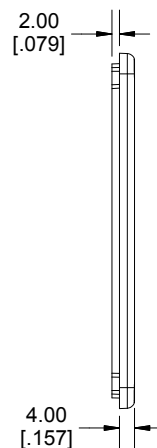

Enclosures can be Factory Modified ( Milling, Drilling, Printing etc.)  
 Contact Factory [mjm@hammondmg.com](mailto:mjm@hammondmg.com) for quotes  
 Solid models of this enclosure available in STEP or IGES.  
 (Part number and text placement/orientation on our products are subject to change,  
 we do not recommend using them as a locating reference for modification purposes)

**NOTE**

Purchased assembly includes box, lid and 4 cover screws.  
 Box and lid are made from Diecast Aluminum Alloy.  
 Silicone Gasket supplied with liquid resistant enclosure.

**Recommended Torque: 50-55 cN.m [71-78 ozf.in]**

**Recommended Torque with Gasket : 25-30 cN.m [36-43 ozf.in]**

**PART NUMBERS**

1590BBS Enclosure	
Natural Finish Enclosure	1590BBS
Black Textured Enclosure	1590BBSBK
1590BBS Liquid Resistant Enclosure (Silicone Gasket)	
Natural Finish Enclosure	1590WBBS
Black Textured Enclosure	1590WBBSBK

**ACCESSORIES**

**Liquid Resistant Cover Screws**

Stainless Steel Cover Screws (Pkg 100) [6-32 x 1/2" With O-Ring]	1590WMS100
Black Stainless Steel Cover Screws (Pkg 100) [6-32 x 1/2" With O-Ring]	1590WMS100BK

**Standard Cover Screws**

Plated Cover Screws (Pkg 100) [6-32 x 1/2"]	1590MS100
Black Cover Screws (Pkg 100) [6-32 x 1/2"]	1590MS100BK

**HAMMOND  
MANUFACTURING®**

**1590BBS**

[www.hammondmg.com](http://www.hammondmg.com)

**Dimensions:**  
 mm  
 [inches]

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

## Hammond:

[1590BLID](#) [1590BBS](#) [1590BBSBK](#) [1593LPCB](#) [1590BBSRD](#) [1590BBSGR](#) [1590BBSCB](#) [1590BBSLG](#) [1590BBSYL](#)  
[1590ORING2-100](#) [1550Z115PL](#) [1592XCBK](#) [1593NLBK-BULK](#) [1590XXGY](#) [1592XCGY](#)