




Quality Products. Service Excellence.

Hard Wired 170E Series



Features

- Single winding, does not provide isolation, for use where equipment is already isolated and only voltage change is required.
- Flexible world wide applications, 50 or 60 Hz. operation, step down (230VAC to 115 VAC) or step up (115VAC to 230VAC).
- Totally enclosed rear case, includes handy internal grounding bolt.
- Extra vacuum varnish for use in high humidity.
- Includes a rear mounted (but not wired), standard 115VAC, 3-wire receptacle.
- Enclosed case with convenient knockouts and includes two cable clamps allowing for easy wire connections.
- Models 170SE, 170AE, 170BE, 170CE & 170DE are CSA certified (209651)
- Connection by flexible leads, 8" minimum length
- Remember - These units do NOT convert line frequency

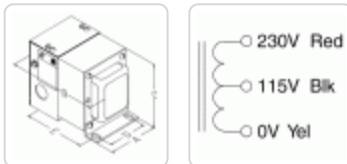

Part No.	Capacity	Overall Dimensions					Weight
	VA	A	B	C	D	E	Lbs
170SE	50	3.13	4.00	4.10	2.30	3.10	3.5
170AE	100	3.13	4.00	4.10	2.30	3.10	4
170BE	200	3.13	4.30	4.10	2.30	3.40	5
170CE	300	3.13	4.80	4.10	2.30	3.90	6.5
170DE	500	3.75	5.00	4.90	2.80	4.10	10
170EE	750	3.75	6.00	4.90	2.80	5.10	15
170FE	1000	3.75	6.00	4.90	2.80	5.10	15.5
170GE	1500	4.38	7.00	5.50	3.30	5.90	23.5
170JE	2000	4.38	7.00	5.50	3.30	5.90	24

Tags: autotransformer, line transformer, hard wired, single winding, voltage change, step down, step up *Data subject to change without notice*

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Hammond:](#)

[170AE](#) [170EE](#) [170DE](#) [170FE](#) [170CE](#) [170BE](#) [170GE](#) [170SE](#) [170JE](#)