


# Aluminum Chassis (1444 & 1434 Series)

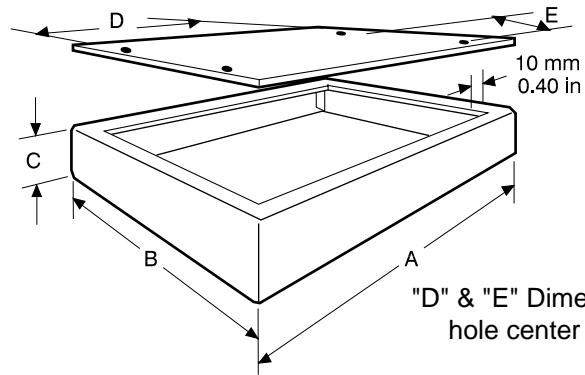

## KEY FEATURES

- Spot welded heavy duty construction chassis.
- Natural finish (as shown above - right group)
- Cover holes are punched with 4 holes – 3/16" diameter. Hardware not provided, please order separately - Part number **1421J6** (Pkg. of 6, 6-32 Philips head screws).

Part Number		In. Thick	Units	Dimensions				
Aluminum Chassis	Cover			A	B	C	D	E
<b>1444-6</b>	<b>1434-6</b>	.040	inch mm	4 102	4 102	2 51	3.6 92	3 76
<b>1444-8</b>	<b>1434-8</b>	.040	inch mm	6 152	4 102	2 51	5.6 143	3 76
<b>1444-12</b>	<b>1434-12</b>	.040	inch mm	7 178	5 127	2 51	6.6 168	3 76
<b>1444-9</b>	<b>1434-10</b>	.040	inch mm	8 203	4 102	1 25	7.6 194	3 76
<b>1444-10</b>	<b>1434-10</b>	.040	inch mm	8 203	4 102	2 51	7.6 194	3 76
<b>1444-14</b>	<b>1434-14</b>	.040	inch mm	9 229	5 127	2 51	8.6 219	3 76
<b>1444-15</b>	<b>1434-16</b>	.040	inch mm	10 254	6 152	1 25	9.6 244	4 102
<b>1444-16</b>	<b>1434-16</b>	.040	inch mm	10 254	6 152	2 51	9.6 244	4 102
<b>1444-22</b>	<b>1434-22</b>	.051	inch mm	12 305	8 203	2 51	11.6 295	6 152
<b>1444-24</b>	<b>1434-22</b>	.051	inch mm	12 305	8 203	3 76	11.6 295	6 152
<b>1444-29</b>	<b>1434-29</b>	.051	inch mm	12 305	10 254	2 51	11.6 295	8 203
<b>1444-18</b>	<b>1434-18</b>	.040	inch mm	13.5 343	5 127	2 51	13.1 333	3 76
<b>1444-26</b>	<b>1434-26</b>	.051	inch mm	16 406	8 203	2 51	15.6 397	6 152
<b>1444-28</b>	<b>1434-26</b>	.051	inch mm	16 406	8 203	3 76	15.6 397	6 152
<b>1444-20</b>	<b>1434-20</b>	.040	inch mm	17 432	4 102	3 76	16.6 422	3 76
<b>1444-30</b>	<b>1434-30</b>	.051	inch mm	17 432	10 254	2 51	16.6 422	8 203
<b>1444-32</b>	<b>1434-30</b>	.051	inch mm	17 432	10 254	3 76	16.6 422	8 203
<b>1444-33</b>	<b>1434-30</b>	.051	inch mm	17 432	10 254	4 102	16.6 422	8 203

Metal

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

## Hammond:

[1434-18](#) [1434-10](#) [1434-16](#) [1434-29](#) [1434-12](#) [1434-14](#) [1434-22](#) [1434-20](#) [1434-26](#) [1434-30](#) [1444-8](#) [1444-6](#)  
[1444-9](#) [1434-6](#) [1434-8](#) [1444-26](#) [1444-16](#) [1444-24](#) [1444-15](#) [1444-32](#) [1444-29](#) [1444-22](#) [1444-18](#) [1444-14](#) [1444-](#)  
[20](#) [1444-12](#) [1444-33](#) [1444-28](#) [1444-10](#) [1444-30](#)