




Quality Products. Service Excellence.

Fan Top Panel *C2TF Series*

Features

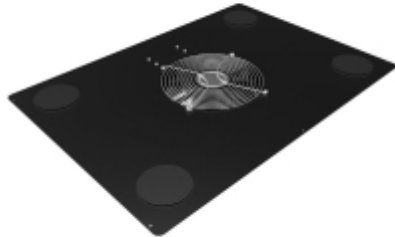

- Use with **C2, C2RR, C4, C4RR, H1** or **CLC** cabinet series.
 - H1 requires H1TC Series for mounting.
- 14 gauge steel construction.
- cURus recognized to UL507 and CSA C22.2 No.113.
- **CLPKIT832-6** Cabinet mounting hardware included.
- Finished in RAL9005 black or ASA61 gray powder paint coat.
 - Complies with the Greenguard guidelines for indoor air quality.
- TAA-compliant for GSA Schedule purchases.
- RoHS Compliant.
- Manufactured in North America.



Fan Tops for use with 4" Fans:

- 4" fan top panel - fans not included (**DNFK4AC120** Sold separately).
- 4 or 6 openings, depending on the depth of the rack.
- Maximum flexibility - add fans OR leave holes open (for cable access) OR use covers (see below) OR any combination.

Pre-Wired Fan Tops:

- Available with (4) 4" fans or (1) 10" fan (factory wired).
- Long life, ball bearing, 4", 115 volts, 50/60 Hz. AC fan(s).
- Available in three depths and two colors.
- 4.7" versions are available with or without adjustable thermostats.
- 10" versions are available with or without cable entry holes.

Accessories

- Tube Axial Fans
- Filter Fan Grills
- Metal Fan Guard



Part No. Black	Part No. Light Gray	Description	Fan Quantity	Fan Size	CFM	dB	Thermostat Included	Cable Entry
C2T1923FBK1	C2T1923FLG1	Cutout for Fan or Cable Entry	4 (Opening Only)	4.70	-	-	No	Optional
C2T1931FBK1	C2T1931FLG1	Cutout for Fan or Cable Entry	6 (Opening Only)	4.70	-	-	No	Optional
C2T1936FBK1	C2T1936FLG1	Cutout for Fan or Cable Entry	6 (Opening Only)	4.70	-	-	No	Optional
C2T2423FBK1	C2T2423FLG1	Cutout for Fan or Cable Entry	4 (Opening Only)	4.70	-	-	No	Optional
C2T2431FBK1	C2T2431FLG1	Cutout for Fan or Cable Entry	6 (Opening Only)	4.70	-	-	No	Optional
C2T2436FBK1	C2T2436FLG1	Cutout for Fan or Cable Entry	6 (Opening Only)	4.70	-	-	No	Optional
C2T1923VFBK1	-	Fan Grill for Fan or Venting	4 (Fan Grill Only)	4.70	-	-	No	No

Part No. Black	Part No. Light Gray	Description	Fan Quantity	Fan Size	CFM	dB	Thermostat Included	Cable Entry
C2T1931VFBK1	-	Fan Grill for Fan or Venting	6 (Fan Grill Only)	4.70	-	-	No	No
C2T1936VFBK1	-	Fan Grill for Fan or Venting	6 (Fan Grill Only)	4.70	-	-	No	No
C2T2423VFBK1	C2T2423VFLG1	Fan Grill for Fan or Venting	4 (Fan Grill Only)	4.70	-	-	No	No
C2T2431VFBK1	C2T2431VFLG1	Fan Grill for Fan or Venting	4 (Fan Grill Only)	4.70	-	-	No	No
C2T2436VFBK1	C2T2436VFLG1	Fan Grill for Fan or Venting	6 (Fan Grill Only)	4.70	-	-	No	No
C2T1923F10BK1	C2T1923F10LG1	Pre-Wired Fan	1	10.00	550	60	No	No
C2T1931F10BK1	C2T1931F10LG1	Pre-Wired Fan	1	10.00	550	60	No	No
C2T1936F10BK1	C2T1936F10LG1	Pre-Wired Fan	1	10.00	550	60	No	No
C2T2431F10BK1	C2T2431F10LG1	Pre-Wired Fan	1	10.00	550	60	No	No
C2T2436F10BK1	C2T2436F10LG1	Pre-Wired Fan	1	10.00	550	60	No	No
C2T1923F10CEBK1	C2T1923F10CELG1	Pre-wired fan with cable entry grommets	1	10.00	550	60	No	Yes
C2T1931F10CEBK1	C2T1931F10CELG1	Pre-wired fan with cable entry grommets	1	10.00	550	60	No	Yes
C2T1936F10CEBK1	C2T1936F10CELG1	Pre-wired fan with cable entry grommets	1	10.00	550	60	No	Yes
C2T2423F10CEBK1	C2T2423F10CELG1	Pre-wired fan with cable entry grommets	1	10.00	550	60	No	Yes
C2T2431F10CEBK1	C2T2431F10CELG1	Pre-wired fan with cable entry grommets	1	10.00	550	60	No	Yes
C2T2436F10CEBK1	C2T2436F10CELG1	Pre-wired fan with cable entry grommets	1	10.00	550	60	No	Yes
C2T1923F4BK1	C2T1923F4LG1	Pre-wired fans	4	4.70	400	64	No	No
C2T1931F4BK1	C2T1931F4LG1	Pre-wired fans	4	4.70	400	64	No	No
C2T1936F4BK1	C2T1936F4LG1	Pre-wired fans	4	4.70	400	64	No	No
C2T2431F4BK1	C2T2431F4LG1	Pre-wired fans	4	4.70	400	64	No	No
C2T2436F4BK1	C2T2436F4LG1	Pre-wired fans	4	4.70	400	64	No	No
C2T1923F4TBK1	C2T1923F4TLG1	Pre-wired fans with thermostat	4	4.70	400	64	Yes	No
C2T1931F4TBK1	C2T1931F4TLG1	Pre-wired fans with thermostat	4	4.70	400	64	Yes	No
C2T1936F4TBK1	C2T1936F4TLG1	Pre-wired fans with thermostat	4	4.70	400	64	Yes	No
C2T2423F4TBK1	C2T2423F4TLG1	Pre-wired fans with thermostat	4	4.70	400	64	Yes	No
C2T2431F4TBK1	C2T2431F4TLG1	Pre-wired fans with thermostat	4	4.70	400	64	Yes	No
C2T2436F4TBK1	C2T2436F4TLG1	Pre-wired fans with thermostat	4	4.70	400	64	Yes	No

Cabinet Compatibility

Fan Top		C2 Cabinet		C4 Cabinet		DCZ4 Cabinet		H1	RCK
Size		Width	Depth	Width	Depth	Width	Depth	Cabinet	Cabinet
C2T1923*		23.00	23.63	24.00	31.50	-	-	All Sizes	All Sizes
C2T1931*		23.00	31.50	24.00	36.00	-	-	-	-
C2T1936*		23.00	36.00	24.00	42.00	-	-	-	-
C2T2423*		-	-	30.00	31.50	-	-	-	-
C2T2431*		-	-	30.00	36.00	30.00	42.00	-	-
C2T2436*		-	-	30.00	42.00	-	-	-	-

Fan Cover Plate

Part No.	DNFPBK1
----------	---------

Individually packaged 4 inch hole cover (hardware included)

What's Inside the Box

Qty Included	Description	Replacement Part No.
1	Top Panel	
6	8-32 Clip Nut (Black Oxide Finish)	CLPKIT832-6
6	8-32 x 0.5" Machine Screw (Zinc Plated)	CLPKIT832-6

Data subject to change without notice

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Hammond:](#)

[C2T1931F4BK1](#) [C2T1931FBK1](#) [C2T1923F10CEBK1](#) [C2T1936FBK1](#) [C2T2423F10CEBK1](#) [C2T1923F4BK1](#)
[C2T1923F10BK1](#) [C2T1931F10BK1](#) [C2T1936F10BK1](#) [C2T1936F4BK1](#) [C2T1931F10CEBK1](#) [C2T2431F10CEBK1](#)
[C2T2436F4BK1](#) [C2T2436F10CEBK1](#) [C2T1923FBK1](#) [C2T1936F10CEBK1](#) [C2T2436F10BK1](#) [C2T1931F4TBK1](#)
[C2T1923F10CELG1](#) [C2T1931F10CELG1](#) [C2T1931FLG1](#) [C2T1936F4TBK1](#) [C2T2436VFBK1](#) [C2T1923F4TBK1](#)
[C2T1931F4LG1](#) [C2T1936F4LG1](#) [C2T1931F4TLG1](#) [C2T1923F10LG1](#) [C2T1936FLG1](#) [C2T1923F4TLG1](#)
[C2T1931F10LG1](#) [C2T1923FLG1](#) [C2T1923F4LG1](#) [C2T1936F10CELG1](#) [C2T2423F10CELG1](#) [C2T2431F10CELG1](#)
[C2T2431F4TLG1](#) [C2T2436F10CELG1](#) [C2T2436F10LG1](#) [C2T2436F4LG1](#) [C2T1923VFBK1](#) [C2T1931VFBK1](#)
[C2T1936VFBK1](#) [C2T2423F10BK1](#) [C2T2423F4BK1](#) [C2T2423F4TBK1](#) [C2T2423FBK1](#) [C2T2423VFBK1](#)
[C2T2431F10BK1](#) [C2T2431F4BK1](#) [C2T2431F4TBK1](#) [C2T2431FBK1](#) [C2T2431VFBK1](#) [C2T2436F4TBK1](#)
[C2T2436FBK1](#) [C2T1936F10LG1](#) [C2T1936F4TLG1](#) [C2T2423FLG1](#) [C2T2431FLG1](#) [C2T2436FLG1](#) [C2T2423VFLG1](#)
[C2T2436VFLG1](#) [C2T2431VFLG1](#) [C2T2423F10LG1](#) [C2T2423F4LG1](#) [C2T2423F4TLG1](#) [C2T2431F10LG1](#)
[C2T2431F4LG1](#) [C2T2436F4TLG1](#)