


Type 1 Lay In Screw Cover Wireway - w/o Knockouts

CWSC NK Series

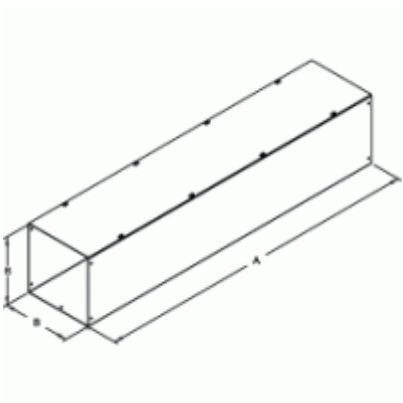

Painted Steel

A=12"	A=18"	A=24"	A=36"	A=48"	Size
CWSC212NK	-	CWSC224NK	CWSC236NK	CWSC248NK	2.5 x 2.5
CWSC412NK	CWSC418NK	CWSC424NK	CWSC436NK	CWSC448NK	4 x 4
CWSC612NK	CWSC618NK	CWSC624NK	CWSC636NK	CWSC648NK	6 x 6
CWSC812NK	CWSC818NK	CWSC824NK	CWSC836NK	CWSC848NK	8 x 8
CWSC1012NK	-	CWSC1024NK	CWSC1036NK	CWSC1048NK	10 x 10
CWSC1212NK	-	CWSC1224NK	CWSC1236NK	CWSC1248NK	12 x 12

A=60"	A=72"	A=96"	A=120"	Size
CWSC260NK	-	-	CWSC2120NK	2.5 x 2.5
CWSC460NK	CWSC472NK	-	CWSC4120NK	4 x 4
CWSC660NK	CWSC672NK	-	CWSC6120NK	6 x 6
CWSC860NK	CWSC872NK	-	CWSC8120NK	8 x 8
CWSC1060NK	CWSC1072NK	CWSC1096NK	CWSC10120NK	10 x 10
CWSC1260NK	CWSC1272NK	CWSC1296NK	CWSC12120NK	12 x 12

Tags: straight section, CWSC, no knockouts, screw cover, wireway, CW

Data subject to change without notice

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Hammond:](#)

[CWSC10120NK](#) [CWSC1012NK](#) [CWSC1024NK](#) [CWSC1036NK](#) [CWSC1048NK](#) [CWSC1060NK](#) [CWSC1072NK](#)
[CWSC12120NK](#) [CWSC1212NK](#) [CWSC1224NK](#) [CWSC1236NK](#) [CWSC1248NK](#) [CWSC1260NK](#) [CWSC2120NK](#)
[CWSC212NK](#) [CWSC224NK](#) [CWSC236NK](#) [CWSC248NK](#) [CWSC260NK](#) [CWSC4120NK](#) [CWSC412NK](#)
[CWSC418NK](#) [CWSC424NK](#) [CWSC448NK](#) [CWSC460NK](#) [CWSC472NK](#) [CWSC6120NK](#) [CWSC612NK](#)
[CWSC618NK](#) [CWSC624NK](#) [CWSC636NK](#) [CWSC648NK](#) [CWSC660NK](#) [CWSC672NK](#) [CWSC8120NK](#)
[CWSC812NK](#) [CWSC818NK](#) [CWSC824NK](#) [CWSC836NK](#) [CWSC848NK](#) [CWSC860NK](#) [CWSC872NK](#)
[CWSC1096NK](#) [CWSC1272NK](#) [CWSC1296NK](#) [CWSC436NK](#)