




Quality Products. Service Excellence.


Centered Rack Shelf *DNDM Series*

Load rated to 200 lbs (91 kg)

Features

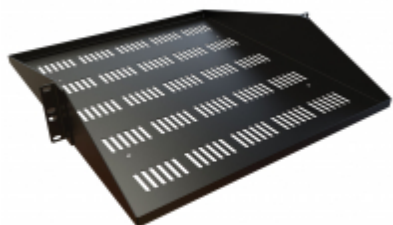

- 16-gauge steel construction.
- The vented version provides a sturdy shelf while allowing passive airflow.
- Rugged textured black powder paint finish.
- The solid version is available in either 19" or 23" rack mounting width.
- 200 lbs (91 kg) **load rating**.
- Finished in textured RAL9005 black powder coat. Complies with the Greenguard guidelines for indoor air quality.
- TAA-compliant for GSA Schedule purchases. BAA/TAA-compliant documentation available upon request.
- RoHS and REACH compliant.
- Manufactured in North America.

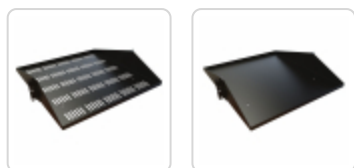

Accessories

- Hardware for Rack Mounting Solutions
- Hook and Loop Convenience Roll



19" Mounting

Part No. Vented	Part No. Solid	Overall Dimensions		Rack Units	Mounting Width
		Height	Depth		
-	DNDMS1916BK1	3.50	16.00	2U	19.00
DNDMV1918BK1	DNDMS1918BK1	3.50	18.00	2U	19.00
DNDMV19BK1	DNDMS19BK1	3.50	19.50	2U	19.00
-	DNDMS1920BK1	3.50	20.00	2U	19.00
-	DNDMS1922BK1	3.50	22.00	2U	19.00
-	DNDMS1924BK1	3.50	24.00	2U	19.00

23" Mounting

Part No. Solid Only	Overall Dimensions		Rack Units	Mounting Width
	Height	Depth		
DNDMS23BK1	3.50	19.50	2U	23.00

Data subject to change without notice

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Hammond:](#)

[DNDMS23BK1](#) [DNDMS19BK1](#) [DNDMV19BK1](#) [DNDMV1918BK1](#) [DNDMS1918BK1](#) [DNDMS1916BK1](#)
[DNDMS1920BK1](#) [DNDMS1924BK1](#) [DNDMS1922BK1](#)