



Quality Products. Service Excellence.

900-1200 BTU/H Outdoor Air Conditioner *DTS Series*

Type 3R, 4, 4X, Side Mounting



Description

- Compact design for side mounting on any enclosure surface where spot cooling or low capacity cooling is required.
- Closed loop cooling ensures clean enclosure air is recirculated without ever mixing with contaminated ambient air.
- Ideal for outdoor or very wet conditions.

Standards


- UL, cUL, and CE
- Complies with
 - IP56
 - NEMA 3R, 4, 4X

Features

- R134a refrigerant.
- Thermostat control accessible from inside enclosure.
- Expansion valve prevents evaporator freeze up while minimizing heavy inrush currents on large BTU/H units.
- Direct condensate discharge via 1/4" NPT threaded port.
- Continuous air circulation from high capacity fans.
- EMI/RFI suppression meets CE.
- Provision for door contact allowing power down when enclosure door is opened.
- Gasket, mounting kit and template for enclosure cutout and drilling are included.
- Washable aluminum mesh filter.

Accessories

- Remote Door Switches
- Gasket Kits
- Condensate Bottle
- Filter Kits
- Water Condensate Evaporator

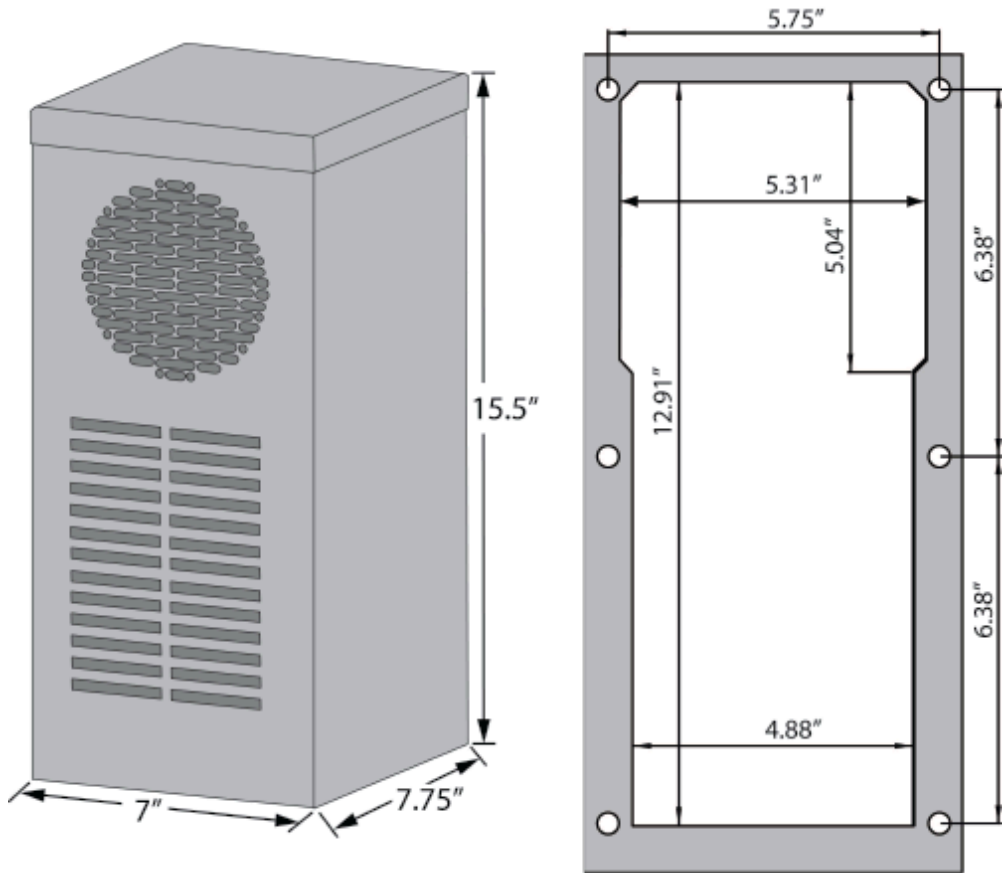

Part No.	Overall Dimensions		
	H	W	D
DTS3031A115N4SS	15.50	7.00	7.75
DTS3031A230N4SS	15.50	7.00	7.75

Electrical Data	DTS3031A115N4SS	DTS3031A230N4SS
Rated Voltage	115 V 60 Hz	230 V 50/60 Hz
Range of Operation	103- 127 V	207-253 V
Power Consumption	243 W	253 W
Running Amps	2.1 A	1.1 A
Starting Current	10	5
Line Cord	With Plug	With Plug

Refrigeration Data	
Cooling Capacity BTU (Watts) +95/+95F +35/+35C	1194 BTU/h (350 Watts)
Type of Refrigerant	R134a
Refrigeration Charge	145 g
Adjustable Control Range	+50F..+105F (+10C..+40 C) Factory setting +95F (+35C)
Max Ambient Air Temp	+114F (+45C)
Min Ambient Air Temp	-40F (-40C)
Air Capacity (unrestricted)	Internal 37 CFM
	External 99 CFM
Condensation Discharge	Condensate Drain
Filter Mat	Aluminum Mesh
Db noise level	<64 db
Unit Weight	30 lbs (13.6kg)
Exterior Case	304 Stainless Steel
Finish Stainless Steel	Number 4 Brush finish
Nema Rating	enclosures IP56 / NEMA 4,4X
Nema Rating	enclosures IP56 / NEMA 3R/4

Tags: DTS, air conditioner, cooler, stainless steel, outdoor, low capacity, 1200 BTU, side mounting, NEMA 4X, Type 4X Data subject to change without notice

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Hammond:](#)

[DTS3031A115N4SS](#) [DTS3031A230N4SS](#)