



*Quality Products. Service Excellence.*

## Server Rack Finger Cable Manager *FRCM Series*

Heavy Duty Design for High Volume of Cables



The vertical Fingered Rack Cable Manager (FRCM) from Hammond Mfg can be used for managing sensitive fiber, large bundles of network and coax cables combined into a structurally strong vertical cable manager. The double-hinged/reversible slam-latch door is simple to install and is visually pleasing.

### Features:

- Sturdy T-shape steel high-density fingers are spaced at 2RU and provide support for large cable bundles and heavy gauge cables.
- Separated space easily allows for cables to be added or removed without fishing the cable.
- Includes clip-on plastic finger guards (ships loose) for 1.25in cable bend radius.
- The Slam-latch door is reversible and can be opened from either side or removed with ease.
- Includes mounting provisions for optional **Cable Spools**, **dividers** for slack management
- Also includes mounting for up to eight (8) low-density **rear management rings**.
- Hardware included for securing to rack.

### Specifications:


- The manager body is constructed of 16-gauge steel, while the manager door is constructed of 18-gauge steel.
- Compatible with **DNRRHDW**, **DC4R**, **DRZ4**, **RB-2P** and **RB-2PA** Series of open frame racks.
- Finished in textured RAL9005 black powder paint finish.
- TAA-compliant for GSA Schedule purchases.
- RoHS and REACH compliant.
- Manufactured in North America.

### Gallery



### Accessories

- Vertical Cable Ring
- Cable Channel Divider
- Hook and Loop Convenience Roll
- Cable Spool
- Vertical Cable Manager Extensions
- Vertical Manager Rack Spacer Bracket

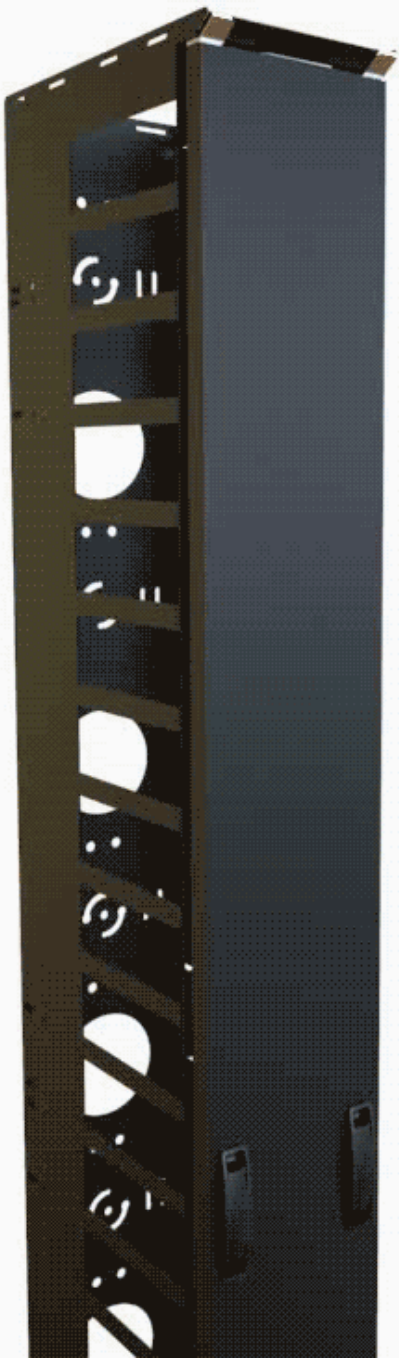

Part No.	Overall Dimensions (Inches)			Mounting Dimensions		Door Included
	Height	Width	Depth	Units	Rack Units	
FRCM44U88	82.00	8.00	9.64	77.00	44	Yes
FRCM44U812	82.00	8.00	13.64	77.00	44	Yes
FRCM44U1012	82.00	10.00	13.64	77.00	44	Yes
FRCM44U128	82.00	12.00	9.64	77.00	44	Yes
FRCM44U1212	82.00	12.00	13.64	77.00	44	Yes

Estimated Cable Fill Capacities

Part No.	Description	Recommended Cable Fill (50% Fill Ratio)		Maximum Cable Fill (100% Fill Ratio)	
		Cat 6	Cat 6a	Cat 6	Cat 6a
FRCM44U88	Channel Opening	293	204	587	407
	Finger Opening	65	45	130	91
	Rear Pass Through	103	71	206	143
FRCM44U812	Channel Opening	416	289	831	577
	Finger Opening	92	64	183	127
	Rear Pass Through	103	71	206	143
FRCM44U1012	Channel Opening	554	385	1108	770
	Finger Opening	92	64	183	127
	Rear Pass Through	103	71	206	143
FRCM44U128	Channel Opening	587	407	1173	815
	Finger Opening	65	45	130	91
	Rear Pass Through	103	71	206	143
FRCM44U1212	Channel Opening	831	577	1662	1154
	Finger Opening	92	64	183	127
	Rear Pass Through	103	71	206	143

Cable Manager > Hammond Rack Compatability

Part No.	RB-2P	RB-2PA19	RB-2PA23	DNRR (19")	DNRR (23")	DC4R44*		DRZ4*
All Sizes of FRCM Compatible	RB-2P77	RB-2PA1945BK	RB-2PA2345BK	DNRR77HDW	DNRR2377HDWB	DC4R44	DC4RT44	DRZ477

Tags: 2-Hinged, Dual Hinged

Data subject to change without notice

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Hammond:](#)

[FRCM44U1012](#) [FRCM44U128](#) [FRCM44U812](#) [FRCM44U88](#) [FRCM44U1212](#)