




Quality Products. Service Excellence.

Window Door *HMEWD Series*



- For use with HME Single Door Series only
- Provides maximum viewing area of enclosure equipment
- Maintains NEMA/UL/CSA Type 12 rating
- UL - 94-VO clear polycarbonate window
- Removable and reversible for left or right hand opening
- Complete with double bit insert latching mechanism
- Door opening 135°
- **Note: check compatibility with HFMD and HFMDT**

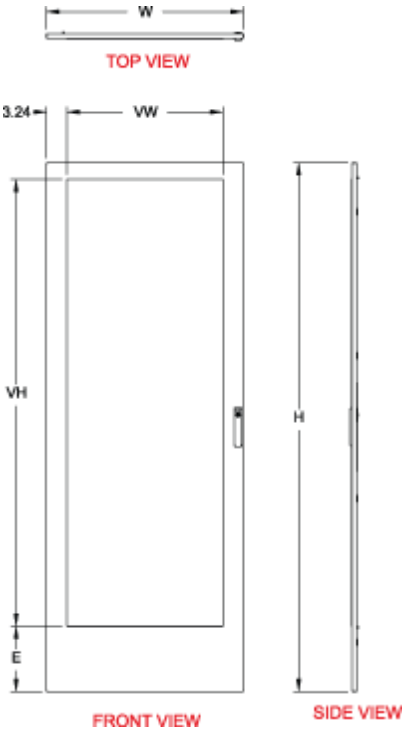

Part No.	Viewing Area			For use with Cabinet	
	H	W	E	H	W
HMEDW146	1219	434	67	1400	600
HMEDW148	1219	635	67	1400	800
HMEDW166	1419	434	67	1600	600
HMEDW168	1419	635	67	1600	800
HMEDW186	1617	434	67	1800	600
HMEDW188	1617	635	67	1800	800
HMEDW206	1819	434	67	2000	600
HMEDW208	1819	635	67	2000	800
HMEDW226	1819	434	266	2200	600
HMEDW228	1819	635	266	2200	800

Tags: **HME, door, window door, Type 12, single door**

Data subject to change without notice

© 2025. Hammond Manufacturing Ltd. All rights reserved.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Hammond:](#)

[HMEDW168](#) [HMEDW208](#) [HMEDW226](#) [HMEDW146](#) [HMEDW148](#) [HMEDW228](#) [HMEDW186](#) [HMEDW166](#)
[HMEDW188](#) [HMEDW206](#)