




Quality Products. Service Excellence.

Type 4X Stainless Steel Two Door Wallmount Enclosure *HN4 WM SS*

Series

Continuous Hinge Door with Handle

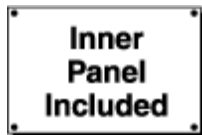

Application

- Designed to house electrical, electronic, hydraulic or pneumatic controls and instruments
- Provides protection where equipment may be hosed down or otherwise be very wet, or in specific applications where corrosion is a serious problem.

Construction

- Formed 12 gauge 304 or 316 stainless steel.
- Smooth, continuously welded seams without knockouts, cutouts or holes.
- Doors are supported with heavy gauge continuous hinges.
- 3-pt padlocking door handle.
- Seamless poured-in place gasket.
- A grounding stud is provided in the enclosure and a bonding stud is provided on the door.
- Center post is removable for easy installation of the inner panel.

Standards

- UL 508A Type 3R, 4X, and 12
- CSA Type 3R, 4X, and 12
- Complies with
 - NEMA Type 3R, 4X, 12 and 13
 - IEC 60529, IP66

Finish

- Cover and enclosure are natural stainless steel with a smooth brushed finish.
- Removable inner panel is finished in white powder coating.

Accessories

- Door Stop Kit
- Drip Shield Kit
- Mechanical Interlock
- Climate Control
- General Accessories
- Type 12/4, 4X Handle Kits
- Window Kits
- Barrier Kits for Type 4 Wallmount
- Lighting

New and improved PDF part drawing files with more detail now available.

Click part number in table below to access PDF, DXF, and STEP files.

304 S.S. Part Number	316 S.S. Part Number	Enclosure			Panel	
		H	W	D	H	W
HN4WM24428SS	HN4WM24428S16	24.00	42.00	8.00	21.00	39.00
HN4WM24488SS	HN4WM24488S16	24.00	48.00	8.00	21.00	45.00
HN4WM304210SS	HN4WM304210S16	30.00	42.00	10.00	27.00	39.00
HN4WM304810SS	HN4WM304810S16	30.00	48.00	10.00	27.00	45.00
HN4WM306010SS	HN4WM306010S16	30.00	60.00	10.00	27.00	57.00
HN4WM364212SS	HN4WM364212S16	36.00	42.00	12.00	33.00	39.00
HN4WM364812SS	HN4WM364812S16	36.00	48.00	12.00	33.00	45.00
HN4WM366012SS	HN4WM366012S16	36.00	60.00	12.00	33.00	57.00
HN4WM424212SS	HN4WM424212S16	42.00	42.00	12.00	39.00	39.00
HN4WM424812SS	HN4WM424812S16	42.00	48.00	12.00	39.00	45.00
HN4WM426012SS	HN4WM426012S16	42.00	60.00	12.00	38.00	56.00
HN4WM484812SS	HN4WM484812S16	48.00	48.00	12.00	44.00	44.00

Tags: **HN4WM**, **wallmount**, **two door**, **stainless steel**, **304**, **316**, **outdoor**, **hydraulic**, **pneumatic**, **controls**, *Data subject to change without notice*
Type 4X, **NEMA 4X**

© 2024. Hammond Manufacturing Ltd. All rights reserved.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Hammond:](#)

[HN4WM366012SS](#) [HN4WM304210SS](#) [HN4WM484812SS](#) [HN4WM304810SS](#) [HN4WM364212S16](#)
[HN4WM364212SS](#) [HN4WM364812SS](#) [HN4WM426012S16](#) [HN4WM24428SS](#) [HN4WM24488SS](#) [HN4WM304210S16](#)
[HN4WM424212SS](#) [HN4WM424812SS](#) [HN4WM426012SS](#) [HN4WM364812S16](#) [HN4WM424812S16](#)
[HN4WM484812S16](#) [HN4WM24488S16](#) [HN4WM306010SS](#) [HN4WM424212S16](#) [HN4WM24428S16](#)
[HN4WM304810S16](#) [HN4WM366012S16](#) [HN4WM306010S16](#)