




Quality Products. Service Excellence.

HWC Locking Door *HWCD Series*

Exclusively for use with the HWC Series

Features:

- 16-gauge steel construction.
- Door styles available solid, tinted **acrylic window** with venting, 64% airflow vented.
- For use with the Hammond **HWC** Series.
- In addition, the hinges can be mounted on the left or right.
- Includes snap-latch lock and two keys.
- Includes door mounting hardware.
- Finished in textured RAL9005 black powder paint coat.
 - Complies with the Greenguard guidelines for indoor air quality.
- TAA-compliant for GSA Schedule purchases.
- RoHS and REACH compliant.
- Manufactured in North America.

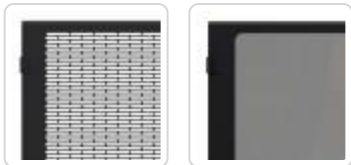

Accessories

- Latch Replacement Kits



Compatible with Cabinet				
Height	Width	Solid	64% Vented	Tinted Window
12U	24	HWCS ^D 2412UBK	HWCVD2412UBK	HWCWD2412UBK
18U	24	HWCS ^D 2418UBK	HWCVD2418UBK	HWCWD2418UBK
27U	24	HWCS ^D 2427UBK	HWCVD2427UBK	HWCWD2427UBK
12U	30	HWCS ^D 3012UBK	HWCVD3012UBK	HWCWD3012UBK
18U	30	HWCS ^D 3018UBK	HWCVD3018UBK	HWCWD3018UBK
27U	30	HWCS ^D 3027UBK	HWCVD3027UBK	HWCWD3027UBK

Data subject to change without notice

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Hammond:](#)

[HWCWD2412UBK](#) [HWCWD2427UBK](#) [HWCSD2418UBK](#) [HWCVD2427UBK](#) [HWCWD3018UBK](#) [HWCVD3012UBK](#)
[HWCSD3012UBK](#) [HWCVD2418UBK](#) [HWCVD3018UBK](#) [HWCWD3027UBK](#) [HWCSD2412UBK](#) [HWCSD2427UBK](#)
[HWCSD3018UBK](#) [HWCWD3012UBK](#) [HWCWD2418UBK](#) [HWCSD3027UBK](#) [HWCVD2412UBK](#) [HWCVD3027UBK](#)