



Quality Products. Service Excellence.

Fan Panel Assembly *PPG Series*


Features



- Choice of two or three fan models - mounted on a standard width 19" rack panel - shipped assembled as shown.
- The front of the panel is punched for finger protection and the rear of the fans assembled with metal guards
- Perfect as an exhaust fan panel or when using "push-pull" cooling (ie..unit pulls air out of the rack cabinet)
- Rugged textured black powder paint finish.
- Two (2) or Three (3) fan daisy chain wire lead/cord, 72" in length.
- TAA-compliant for GSA Schedule purchases.
- RoHS Compliant.
- Manufactured in North America.



Gallery

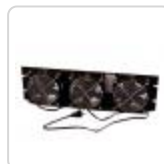

Accessories

- Hardware for Rack Mounting Solutions

Part No.	Number of Fans	Voltage (50/60Hz.)	Power Consumption (W)		Fan		115VAC Plug	Mounting Dimensions	
			50Hz	60Hz	Panel CFM	Noise (dB)		Rack Units	Height
PPGPFA	2	115 VAC	48	44	210	60	Yes	3U	5.25
PPGPFA230	2	230 VAC	44	42	210	60	No	3U	5.25
FP3F115	3	115 VAC	72	66	315	63	Yes	3U	5.25
FP3F230	3	230 VAC	66	63	315	63	No	3U	5.25

Each fan is rated for 22W - 0.57A at 115Vac.

Data subject to change without notice

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Hammond:](#)

[PPGPFPA](#) [FP3F115](#) [PPGPFPA230](#) [FP3F230](#)