



Quality Products. Service Excellence.

Watertight - Thick Wall Diecast Aluminum R190-R191 Series

aluCASE



Key Features:



- Modern, high quality instrument enclosure
- Diecast aluminum material (GD Al Si 12/DIN 1725)
- Shallow lid, deep body
- Captive stainless steel lid screws
- Enclosure can be mounted after closing lid
- Integrated 1.7 mm recess in lid for membrane keypads and front panels
- TPE preformed gasket included (not installed)
- Clip-on design covers hide mounting and lid screws
- Covers are polyoxymethylene plastic in grey (RAL 7040)
- Degree of protection: NEMA 4X, IP67
- CSA and UL listed, Type 4
- Textured polyester powder coat, grey RAL 7040. (can be supplied unpainted on special order)




Features (click to enlarge)

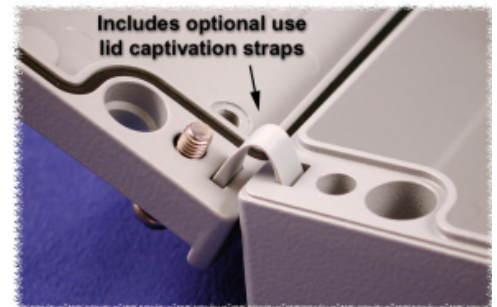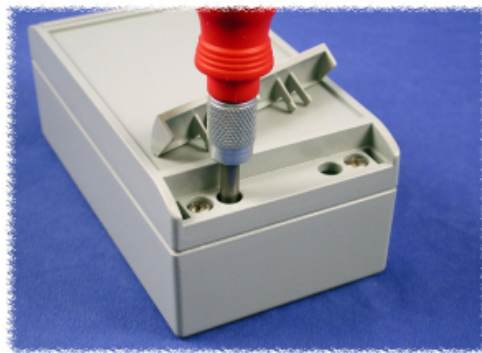

Enclosure can be installed after closing lid.

Includes optional-use lid captivation straps.

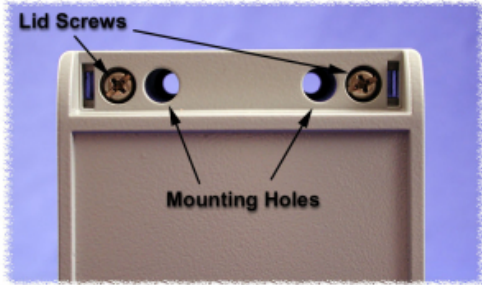

Snap-in design covers hide both lid screws and installation holes.
 Mounting holes are accessible with lid closed. All holes are outside of gasket seal.

Part Number	Length (mm)	Width (mm)	Depth With Lid (mm)
R191-052-000	50	75	33
R191-054-000	50	100	33
R191-070-000	70	100	50
R191-090-000	90	120	60
R191-072-000	70	140	50
R190-110-000	110	140	60
R191-092-000	90	160	60
R190-130-000	130	160	70
R191-074-000	70	180	50
R190-150-000	150	180	60
R191-150-000	150	180	90
R190-112-000	110	200	60
R190-170-000	170	200	60
R191-170-000	170	200	90
R190-132-000	130	220	70
R191-200-100	200	230	120
R191-094-000	90	250	60
R190-152-000	150	260	60
R191-152-000	150	260	90
R190-172-000	170	280	60
R191-172-000	170	280	90
R191-202-100	200	330	120

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Hammond:](#)

[R190-170-000](#) [R190-152-000](#) [R191-172-000](#) [R190-112-000](#) [R190-130-000](#) [R191-200-100](#) [R191-052-000](#) [R191-054-000](#) [R191-070-000](#) [R191-072-000](#) [R191-074-000](#) [R191-094-000](#) [R191-202-100](#) [R190-110-000](#) [R190-132-000](#) [R190-150-000](#) [R190-172-000](#) [R191-090-000](#) [R191-092-000](#) [R191-150-000](#) [R191-152-000](#) [R191-170-000](#) [R191-172-010](#)