




*Quality Products. Service Excellence.*

## Adjustable-Depth Rackmount Angle Bracket *RAAB Series*

Load rated to 200 lbs (91 kg)

The Rackmount Adjustable Angle Bracket (RAAB) accommodates the weight of heavy equipment that isn't installed on a rack. The RAAB, which comes in two depth ranges, can support up to 200 lbs and vary from 24 to 48 inches deep.

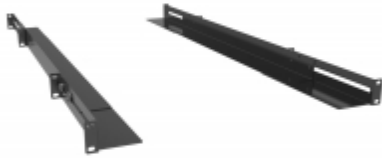

### Features

- Constructed in 16-gauge steel.
- Angles mount to 19", 23", or 24" EIA rack mounting rails.
- Requires two pairs of mounting rails.
- Designed to support equipment such as servers, switchgear, and computer/server chassis on their side.
- The free-floating design easily adjusts in depth to accommodate different equipment dimensions.
- Two adjustable depth options.
- **Sold in pairs.**
- Requires mounting hardware.
- 200 lbs (91 kg) **load rating.**
- Finished in smooth RAL9005 black powder coat. Complies with the Greenguard guidelines for indoor air quality.
- TAA-compliant for GSA Schedule purchases. BAA/TAA-compliant documentation available upon request.
- RoHS Compliant.
- Manufactured in North America within an ISO 9001:2015 certified facility.

### Accessories

- Hardware for Rack Mounting Solutions
- Rack Equipment Installation Tool



Part No.	Height	Width	Overall Dimensions		Rack Units
			Min Depth	Max Depth	
RAAB2436BK	1.72	3.14	23.70	36.00	1U
RAAB3648BK	1.72	3.14	35.70	48.00	1U

Tags: **Equipment Support Frame, Variable depth**

*Data subject to change without notice*

© 2025. Hammond Manufacturing Ltd. All rights reserved.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Hammond:](#)

[RAAB2436BK](#) [RAAB3648BK](#)