




Quality Products. Service Excellence.

Universal Rack Shelf *RAS Series*

Load rated to 200 lbs (91 kg)

Features

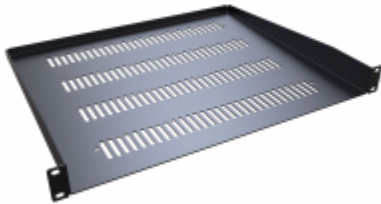

- Constructed of 14 or 16 gauge steel.
- Universal design mounts to any standard EIA-compliant rack or cabinet.
- Allows easy rack mounting of equipment or items that do not have rack mounting capabilities.
- Mounts to rack rails either as an internal shelf or external shelf/work area.
- Available in either vented or solid versions.
- Up to 200 lbs (91 kg) **static load rating**.
- Rugged textured RAL9005 black powder coat finish. Complies with the Greenguard guidelines for indoor air quality.
- TAA-compliant for GSA Schedule purchases. BAA/TAA-compliant documentation available upon request.
- RoHS and REACH compliant.
- Manufactured in North America within an ISO 9001:2015 certified facility.

Accessories

- Hardware for Rack Mounting Solutions
- Hook and Loop Convenience Roll



19 Inch Mounting Shelves

Part No. Vented	Part No. Solid (Un-Vented)	Mounting Dimensions			Rack Units	Stiffener Lip(s) Folded	Suggested Load Capacity*
		Height	Width	Depth			
RASV190107UBK1	RASU190107UBK1	1.75	19.30	7.00	1U	Up (Front & Back)	16ga 42 lbs (19 kg)
RASV190107DBK1	RASU190107DBK1	1.75	19.30	7.00	1U	Down (Front & Back)	16ga 42 lbs (19 kg)
RASV190110BK1	RASU190110BK1	1.75	19.30	10.00	1U	Up (Back Only)	16ga 42 lbs (19 kg)
RASV190112BK1	RASU190112BK1	1.75	19.30	12.00	1U	Up (Back Only)	16ga 42 lbs (19 kg)
RASV190115BK1	RASU190115BK1	1.75	19.30	15.00	1U	Up (Back Only)	16ga 42 lbs (19 kg)
RASV190120BK1	RASU190120BK1	1.75	19.30	20.00	1U	Up (Back Only)	16ga 42 lbs (19 kg)
RASV190312BK1	RASU190312BK1	3.50	19.30	12.00	2U	Up (Back Only)	14ga 100 lbs (45 kg)
RASV190315BK1	RASU190315BK1	3.50	19.30	15.00	2U	Up (Back Only)	14ga 100 lbs (45 kg)
RB-SHELFV	RB-SHELF	3.50	19.30	16.00	2U	Down (Front & Back)	16ga 50 lbs (22 kg)
RASV190318BK1	RASU190318BK1	3.50	19.30	18.00	2U	Up (Back Only)	14ga 100 lbs (45 kg)
RASV190320BK1	RASU190320BK1	3.50	19.30	20.00	2U	Up (Back Only)	14ga 100 lbs (45 kg)
RASV190515BK1	RASU190515BK1	5.25	19.30	15.00	3U	Up (Back Only)	14ga 200 lbs (91 kg)
-	RASU190516BK1	5.25	19.30	16.00	3U	Up (Back Only)	14ga 200 lbs (91 kg)
RASV190520BK1	RASU190520BK1	5.25	19.30	20.00	3U	Up (Back Only)	14ga 200 lbs (91 kg)
-	RASU190522BK1	5.25	19.30	22.00	3U	Up (Back Only)	14ga 200 lbs (91 kg)

Part No. Vented	Part No. Solid (Un-Vented)	Mounting Dimensions			Rack Units	Stiffener Lip(s) Folded	Suggested Load Capacity*
		Height	Width	Depth			
-	RASU190524BK1	5.25	19.30	24.00	3U	Up (Back Only)	14ga 200 lbs (91 kg)
RASV190715BK1	RASU190715BK1	7.00	19.30	15.00	4U	Up (Back Only)	14ga 200 lbs (91 kg)
RASV190720BK1	RASU190720BK1	7.00	19.30	20.00	4U	Up (Back Only)	14ga 200 lbs (91 kg)

*This product was tested to double the suggested load rating.

23 Inch Mounting Shelves

Part No. Vented	Part No. Solid	Mounting Dimensions			Rack Units	Stiffener Lip(s) Folded	Suggested Load Capacity
		Height	Width	Depth			
RASV230515BK1	RASU230515BK1	5.25	23.30	15.00	3U	Up (Back Only)	200 lbs (91 kg)
RASV230520BK1	RASU230520BK1	5.25	23.30	20.00	3U	Up (Back Only)	200 lbs (91 kg)

Tested to nearly double the suggested load rating.

Tags: Cantilevered Shelf, 2-Post Shelf, 1 u shelf

Data subject to change without notice

© 2025. Hammond Manufacturing Ltd. All rights reserved.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Hammond:](#)

[RASV190520BK1](#) [RASV230515BK1](#) [RASU230515BK1](#) [RASU190520BK1](#) [RASV190515BK1](#) [RASU190515BK1](#)
[RASU190115BK1](#) [RASU190120BK1](#) [RASU190315BK1](#) [RASU190320BK1](#) [RASV190115BK1](#) [RASV190120BK1](#)
[RASV190315BK1](#) [RASV190320BK1](#) [RASV190720BK1](#) [RASU190107UBK1](#) [RASUL190314BK1](#) [RASVL190314BK1](#)
[RASU190107DBK1](#) [RASV190107UBK1](#) [RASV240520BK1](#) [RASU230520BK1](#) [RASV230520BK1](#) [RASU190720BK1](#)
[RASV190715BK1](#) [RASVL190514BK1](#) [RASV240515BK1](#) [RASUL190514BK1](#) [RASU190715BK1](#) [RASV190107DBK1](#)
[RASU190110BK1](#) [RASU190112BK1](#) [RASU190318BK1](#) [RASV190318BK1](#) [RASV190110BK1](#) [RASV190112BK1](#)
[RASV190312BK1](#) [RASU190312BK1](#) [RASU190516BK1](#) [RASU190518BK1](#) [RASU190522BK1](#) [RASU190524BK1](#)