



Quality Products. Service Excellence.

Instrument Rack Cabinet *RCBS Series*


600 lbs (272 kg) Weight Capacity

Features:



- Constructed in 16-gauge steel.
- Two pairs of fixed 19" EIA compliant round hole punched rails.
- Includes rubber feet, two lifting handles, a starter pack **CLPKIT1032-10** clip nuts and rack screws.
- Finished in textured RAL9005 black or RAL 7035 light gray powder paint.
- Tested to nearly double the suggested load rating of 600 lbs (272 kg).
- TAA-compliant for GSA Schedule purchases.
- RoHS Compliant.
- Manufactured in North America within an ISO 9001:2015 certified facility.

Accessories

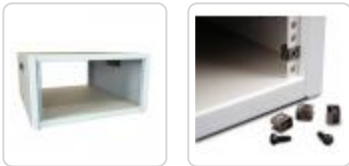

- Rack Shelves
- Rack Panels
- PDUs and Outlet Strips
- 10-32 Mounting Screw and Clip Nut Combo-Pack



Part No.	Part No.	Overall Dimensions			Rack Units	Usable Mounting Dimensions		Similar Size Part No.
		Height	Width	Depth		Height	Depth	
Black	RAL 7035 Light Gray							
RCBS1900313BK1	RCBS1900313LG1	5.50	21.00	13.00	2U	3.50	12.38	
RCBS1900513BK1	RCBS1900513LG1	7.25	21.00	13.00	3U	5.25	12.38	
RCBS1900713BK1	RCBS1900713LG1	9.00	21.00	13.00	4U	7.00	12.38	

Part No. Black	Part No. RAL 7035 Light Gray	Overall Dimensions			Rack Units	Usable Mounting Dimensions		Similar Size Part No.
		Height	Width	Depth		Height	Depth	
RCBS1900813BK1	RCBS1900813LG1	10.75	21.00	13.00	5U	8.75	12.38	
RCBS1901013BK1	RCBS1901013LG1	12.50	21.00	13.00	6U	10.50	12.38	
RCBS1901213BK1	RCBS1901213LG1	14.25	21.00	13.00	7U	12.25	12.38	
RCBS1901413BK1	RCBS1901413LG1	16.00	21.00	13.00	8U	14.00	12.38	
RCBS1900317BK1	RCBS1900317LG1	5.50	21.00	17.50	2U	3.50	16.88	
RCBS1900517BK1	RCBS1900517LG1	7.25	21.00	17.50	3U	5.25	16.88	SDC243U17BK
RCBS1900717BK1	RCBS1900717LG1	9.00	21.00	17.50	4U	7.00	16.88	
RCBS1900817BK1	RCBS1900817LG1	10.75	21.00	17.50	5U	8.75	16.88	
RCBS1901017BK1	RCBS1901017LG1	12.50	21.00	17.50	6U	10.50	16.88	SDC246U17BK
RCBS1901217BK1	RCBS1901217LG1	14.25	21.00	17.50	7U	12.25	16.88	
RCBS1901417BK1	RCBS1901417LG1	16.00	21.00	17.50	8U	14.00	16.88	RCHS1901417BK1
RCBS1900324BK1	RCBS1900324LG1	5.50	21.00	24.50	2U	3.50	23.88	
RCBS1900524BK1	RCBS1900524LG1	7.25	21.00	24.50	3U	5.25	23.88	SDC243U24BK
RCBS1900724BK1	RCBS1900724LG1	9.00	21.00	24.50	4U	7.00	23.88	
RCBS1900824BK1	RCBS1900824LG1	10.75	21.00	24.50	5U	8.75	23.88	
RCBS1901024BK1	RCBS1901024LG1	12.50	21.00	24.50	6U	10.50	23.88	SDC246U24BK
RCBS1901224BK1	RCBS1901224LG1	14.25	21.00	24.50	7U	12.25	23.88	
RCBS1901424BK1	RCBS1901424LG1	16.00	21.00	24.50	8U	14.00	23.88	RCHS1901424BK1

Data subject to change without notice

© 2022. Hammond Manufacturing Ltd. All rights reserved.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Hammond:

[RCBS1901413BK1](#) [RCBS1900713BK1](#) [RCBS1900313BK1](#) [RCBS1900817BK1](#) [RCBS1901213BK1](#)
[RCBS1900513BK1](#) [RCBS1901417BK1](#) [RCBS1900717BK1](#) [RCBS1900517BK1](#) [RCBS1901217BK1](#)
[RCBS1901017BK1](#) [RCBS1900813BK1](#) [RCBS1901013BK1](#) [RCBS1900713LG1](#) [RCBS1900513LG1](#)
[RCBS1900824LG1](#) [RCBS1900317LG1](#) [RCBS1900324LG1](#) [RCBS1900717LG1](#) [RCBS1900324BK1](#)
[RCBS1901217LG1](#) [RCBS1900524LG1](#) [RCBS1900317BK1](#) [RCBS1900724BK1](#) [RCBS1901413LG1](#)
[RCBS1901024LG1](#) [RCBS1901024BK1](#) [RCBS1900313LG1](#) [RCBS1901424BK1](#) [RCBS1901017LG1](#)
[RCBS1900524BK1](#) [RCBS1901417LG1](#) [RCBS1900517LG1](#) [RCBS1901213LG1](#) [RCBS1901224LG1](#)
[RCBS1901224BK1](#) [RCBS1900817LG1](#) [RCBS1900813LG1](#) [RCBS1900824BK1](#) [RCBS1901013LG1](#)
[RCBS1900724LG1](#) [RCBS1901424LG1](#)