




*Quality Products. Service Excellence.*

## Vertical Cable Manager with Door *RRCM Series*

For use with Open Frame Racks

**Note:** This product line will soon be discontinued as a stocked series. Available while quantities last. For alternative solution assistance, please **contact Hammond here** or call: USA (716) 630-7030, Canada and International (519) 822-2960.

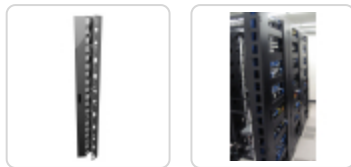

Vertical cable managers facilitate cable organization for a single or multiple rack installation. The RRCM Series includes a magnetic hinged door that hides cables and improves the esthetics of the installation. The RRCM includes crossbars to support your heavy-duty cable applications.

### Features

- All-steel construction with side and rear cut-outs for cable pass-through.
- Includes cable mounting lances for hook and loop cable organization.
- Mounts to either side of an open-frame rack (includes mounting hardware).
- The attached hinged door opens to one side and secures closed with a magnetic strip.
- Can be used with top wire management accessories below (excludes RRAL Series).
- Manager body and door are constructed of 16-gauge steel.
- Manager and door finished in textured RAL9005 black powder paint finish.
- Designed for use with the **DNRR\*\*HDW** and is also compatible with **RB-2P**, **DC4R**, **DRZ4**, **RB-2PA** as well as several of our competitor's open racks.
  - Hardware included for securing to rack.
- TAA-compliant for GSA Schedule purchases.
- RoHS and REACH compliant.
- Manufactured in North America.

### Accessories

- Vertical Cable Manager Extensions
- Hook and Loop Convenience Roll
- Top Wire Management
- Vertical Manager Rack Spacer Bracket

Part No.	Overall Dimensions			Mounting Dimensions			Managers Included	Similar Size Part No.
	Height	Width	Depth	Height	Rack Units	Door Included		
RRCM44UD	82.00	6.00	5.00	77.00	44U	Yes	1	RB-VCM44
RRCM48UD	89.00	6.00	5.00	84.00	48U	Yes	1	RB-VCM48
RRCM844UD	82.00	8.00	6.00	77.00	44U	Yes	1	RB-VFM45-8-1
RRCM848UD	89.00	8.00	6.00	84.00	48U	Yes	1	
RRCM1244UD	82.00	12.00	6.00	77.00	44U	Yes	1	FRCM44U128

77 inch part numbers are also compatible with 78.75 (45U)

Estimated Cable Fill Capacities

Part No.	Description	Opening	Recommended Cable Fill (50% Fill Ratio)		Maximum Cable Fill (100% Fill Ratio)	
		Quantity	Cat 6	Cat 6a	Cat 6	Cat 6a
RRCM44UD	Channel Opening	1	149	103	297	207
	Side Opening	2 x 19 = 38	31	21	61	42
	Rear Pass Through	10	28	19	55	38
RRCM48UD	Channel Opening	1	149	103	297	207
	Side Opening	2 x 21 = 42	31	21	61	42
	Rear Pass Through	11	28	19	55	38
RRCM844UD	Channel Opening	1	226	157	452	314
	Side Opening	2 x 19 = 38	31	21	61	42
	Rear Pass Through	10	28	19	55	38
RRCM848UD	Channel Opening	1	226	157	452	314
	Side Opening	2 x 21 = 42	31	21	61	42
	Rear Pass Through	11	28	19	55	38
RRCM1244UD	Channel Opening	1	341	237	681	473
	Side Opening	2 x 19 = 38	31	21	61	42
	Rear Pass Through	2 x 10 = 20	28	19	55	38

Cable Manager > Hammond Rack Compatability

Part No.	RB-2P	RB-2PA19	RB-2PA23	DNRR (19")	DNRR (23")	DC4R	DRZ4
RRCM44UD	RB-2P77	RB-2PA1945BK	RB-2PA2345BK	DNRR77HDW	DNRR2377HDWB	DC4R44	DRZ477
RRCM844UD	RB-2P77	RB-2PA1945BK	RB-2PA2345BK	DNRR77HDW	DNRR2377HDWB	DC4R44	DRZ477
RRCM1244UD	RB-2P77	RB-2PA1945BK	RB-2PA2345BK	DNRR77HDW	DNRR2377HDWB	DC4R44	DRZ477
RRCM48UD	RB-2P84	-	-	DNRR84HDW	DNRR2384HDWB	-	-
RRCM848UD	RB-2P84	-	-	DNRR84HDW	DNRR2384HDWB	-	-

Data subject to change without notice

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Hammond:](#)

[RRCM844UD](#) [RRCM1248UD](#) [RRCM44UD](#) [RRCM48UD](#) [RRCM1244UD](#) [RRCM848UD](#)