




Quality Products. Service Excellence.

Rack Cabinet Fixed Shelf (Flange Folded Up) RZVS Series

Load rated to 170 lbs (77 kg)

Features

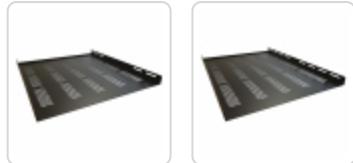

- Constructed of heavy-duty 14 gauge steel.
- Attaches to the side of both pairs of rack combination rails.
- No obstruction to the front panel space or equipment.
- Requires no front rail mounting or front rack space.
- Vented to provide a sturdy shelf without obstructing upward heat movement.
- The rear lip is folded up for extra strength & acts as a rear equipment retainer.
- The rear lip is covered with a rubber channel to avoid equipment scratching and cable chafing.
- The sides are folded up for easy hardware installation from above.
- Sides are slotted for easy adjustment with most rail depth locations.
- Rugged textured RAL9005 black powder paint coat. Complies with the Greenguard guidelines for indoor air quality.
- **170 lbs (77 kg) load rating.**
- TAA-compliant for federal GSA schedule purchases within the USA.
- RoHS and REACH compliant.
- Manufactured in North America.



Please note that to mount this product, you must have two (2) pairs of combination rails within your cabinet. To mount this product to a traditional equipment rack, please order the FSRA or see our RAAB Series.



If used with our **CPR square hole rails** you will need to order **CPRSA rail adaptor** for each shelf ordered.

Accessories

- Fixed Shelf Rail Adapter
- Square Hole Mounting Rail Adaptor
- Hook and Loop Convenience Roll

Vented Part No.	Height	Flange Location	Overall Dimensions		
			Height	Width	Depth
RZVS1918BK1	0.31	Rear Only	1.31	17.75	17.84
RZVS1921BK1	0.31	Rear Only	1.31	17.75	20.84
RZVS1926BK1	0.31	Rear Only	1.31	17.75	25.84
RZVS1931BK1	0.31	Rear Only	1.31	17.75	30.84

Tags: Equipment Shelf with Grill, Plain Equipment Shelf

Data subject to change without notice

© 2025. Hammond Manufacturing Ltd. All rights reserved.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Hammond](#):

[RZVS1918BK1](#) [RZVS1921BK1](#) [RZVS1931BK1](#) [RZVS1926BK1](#)