


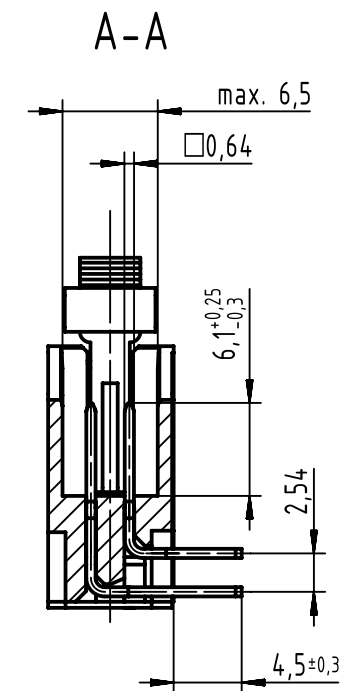
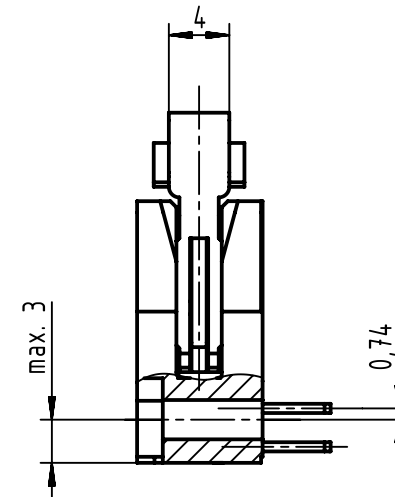
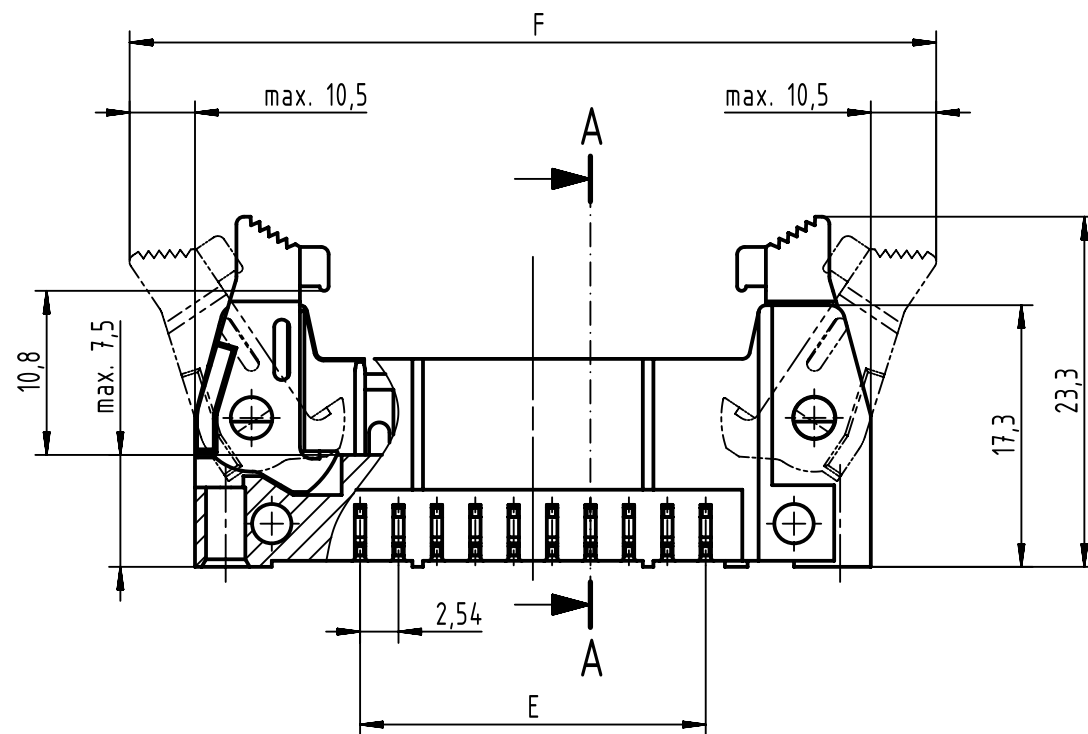
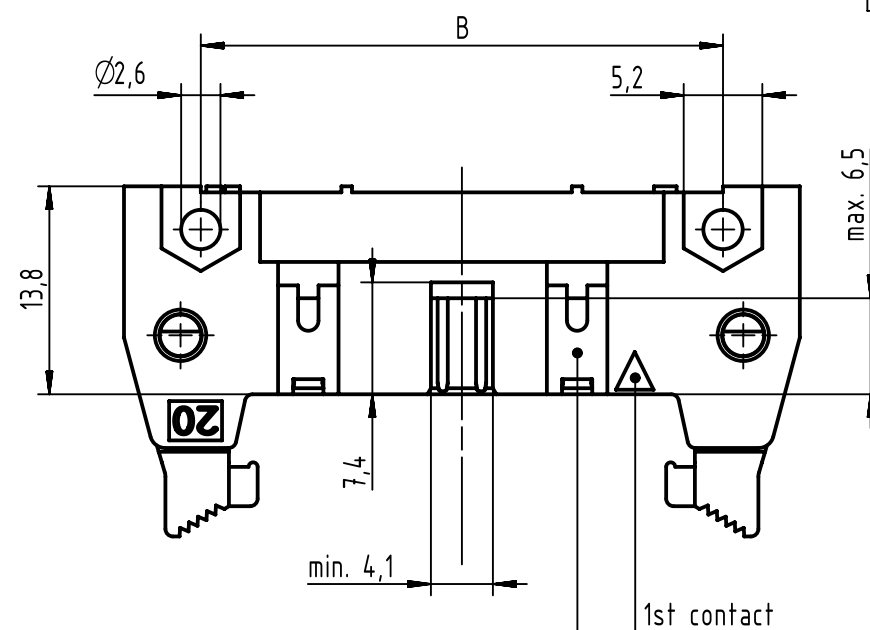


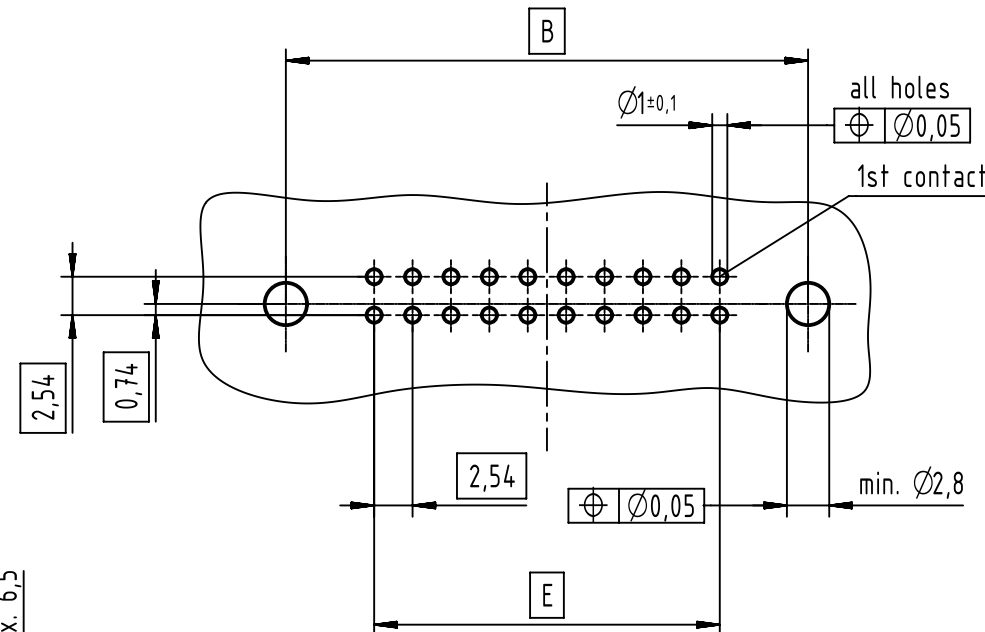

PCB layout
view component side
thickness up to 3,2

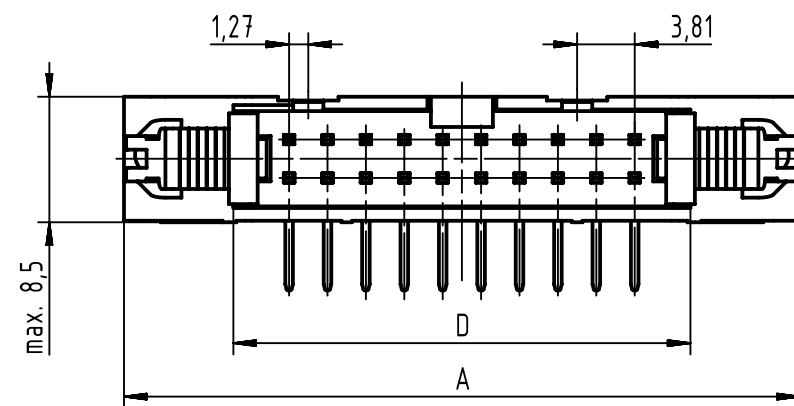

see table for coding,
feature arrangement and style

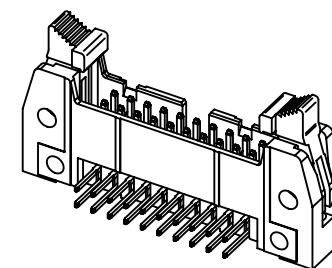

further information
see: DS 09181200001

full range of P/N's and
dimensions shown on page 2/2

coding style table

	style A: for connectors 6-pole
	style B: for connectors from 10 to 14-pole
	style C: for connectors from 16 to 64-pole

	All Dimensions in mm Original Size DIN A3		Scale 2:1	Free size tol. IEC 60603-13		Ref. Sub. TB 09185XXX911 / 500000087654 / 2015-04-08	
	All rights reserved Department EC PD - DE		Created by STORCK	Inspected by TADJE	Standardisation KOHLE	Date 2015-12-21	State Final Release
HARTING Electronics GmbH D-32339 Espelkamp		Title SEK 18 male standard conn angled with short lever 4.5					Doc-Key / ECM-Nr. 100154464/UGD/019/A 500000094595
		Type TB	Number 09185XXX911			Rev. A	Page 1/2

	1	2	3	4	5	6	7	8
A								
B								
C								
D								
E								
F								

no. of contacts	performance level			insulator colour	dimensions				
	PL3	PL2	S4		A max.	B	D	E	F
06	09 18 506 7911	09 18 506 6911	09 18 506 5911	grey	27,2	16,76	12,45	2,54 x 2 = 5,08	36,9
10	09 18 510 7911	09 18 510 6911	09 18 510 5911		32,3	21,84	17,53	2,54 x 4 = 10,16	42,0
14	09 18 514 7911	09 18 514 6911	09 18 514 5911		37,4	26,92	22,61	2,54 x 6 = 15,24	47,1
16	09 18 516 7911	09 18 516 6911	09 18 516 5911		39,9	29,46	25,15	2,54 x 7 = 17,78	49,6
20	09 18 520 7911	09 18 520 6911	09 18 520 5911		45,0	34,54	30,23	2,54 x 9 = 22,86	54,7
24	09 18 524 7911	09 18 524 6911	09 18 524 5911		50,1	39,62	35,91	2,54 x 11 = 27,94	59,8
26	09 18 526 7911	09 18 526 6911	09 18 526 5911		52,6	42,16	37,85	2,54 x 12 = 30,48	62,3
30	09 18 530 7911	09 18 530 6911	09 18 530 5911		58,0	47,24	43,83	2,54 x 14 = 35,56	68,2
34	09 18 534 7911	09 18 534 6911	09 18 534 5911		62,8	52,32	48,01	2,54 x 16 = 40,64	72,5
40	09 18 540 7911	09 18 540 6911	09 18 540 5911		70,4	59,94	55,63	2,54 x 19 = 48,26	80,1
50	09 18 550 7911	09 18 550 6911	09 18 550 5911		83,1	72,64	68,33	2,54 x 24 = 60,96	92,8
60	09 18 560 7911	09 18 560 6911	09 18 560 5911		95,8	85,34	81,03	2,54 x 29 = 73,66	105,5
64	09 18 564 7911	09 18 564 6911	09 18 564 5911		100,9	90,42	86,11	2,54 x 31 = 78,74	110,6
06	09 18 506 7911 001	09 18 506 6911 001	09 18 506 5911 001	black	27,2	16,76	12,45	2,54 x 2 = 5,08	36,9
10	09 18 510 7911 001	09 18 510 6911 001	09 18 510 5911 001		32,3	21,84	17,53	2,54 x 4 = 10,16	42,0
14	09 18 514 7911 001	09 18 514 6911 001	09 18 514 5911 001		37,4	26,92	22,61	2,54 x 6 = 15,24	47,1
16	09 18 516 7911 001	09 18 516 6911 001	09 18 516 5911 001		39,9	29,46	25,15	2,54 x 7 = 17,78	49,6
20	09 18 520 7911 001	09 18 520 6911 001	09 18 520 5911 001		45,0	34,54	30,23	2,54 x 9 = 22,86	54,7
24	09 18 524 7911 001	09 18 524 6911 001	09 18 524 5911 001		50,1	39,62	35,91	2,54 x 11 = 27,94	59,8
26	09 18 526 7911 001	09 18 526 6911 001	09 18 526 5911 001		52,6	42,16	37,85	2,54 x 12 = 30,48	62,3
30	09 18 530 7911 001	09 18 530 6911 001	09 18 530 5911 001		58,0	47,24	43,83	2,54 x 14 = 35,56	68,2
34	09 18 534 7911 001	09 18 534 6911 001	09 18 534 5911 001		62,8	52,32	48,01	2,54 x 16 = 40,64	72,5
40	09 18 540 7911 001	09 18 540 6911 001	09 18 540 5911 001		70,4	59,94	55,63	2,54 x 19 = 48,26	80,1
50	09 18 550 7911 001	09 18 550 6911 001	09 18 550 5911 001		83,1	72,64	68,33	2,54 x 24 = 60,96	92,8
60	09 18 560 7911 001	09 18 560 6911 001	09 18 560 5911 001		95,8	85,34	81,03	2,54 x 29 = 73,66	105,5
64	09 18 564 7911 001	09 18 564 6911 001	09 18 564 5911 001		100,9	90,42	86,11	2,54 x 31 = 78,74	110,6

	All rights reserved Department EC PD - DE	Created by STORCK	Inspected by TADJE	Standardisation KOHLER	Date 2015-12-21	State Final Release
HARTING Electronics GmbH D-32339 Espelkamp		Title SEK 18 male standard conn angled with short lever 4.5			Doc-Key / ECM-Nr. 100154464/UGD/019/A 500000094595	
		Type TB	Number 09185XXX911			Rev. A
					Page 2/2	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

HARTING:

[09185066911](#) [09185106911](#) [09185107911](#) [09185146911](#) [09185147911](#) [09185166911](#) [09185207911](#)
[09185266911](#) [09185345911](#) [09185347911](#) [09185405911](#) [09185406911](#) [09185407911](#) [09185506911](#) [09185605911](#)
[09185646911](#) [09185647911](#) [09185105911](#) [09185205911](#) [09185505911](#) [09185606911](#) [09185167911](#)
[09185265911](#) [09185346911](#) [09185645911](#) [09185206911](#) [09185607911](#) [09185065911](#) [09185067911](#) [09185145911](#)
[09185165911](#) [09185267911](#) [09185507911](#) [09185406911001](#)