

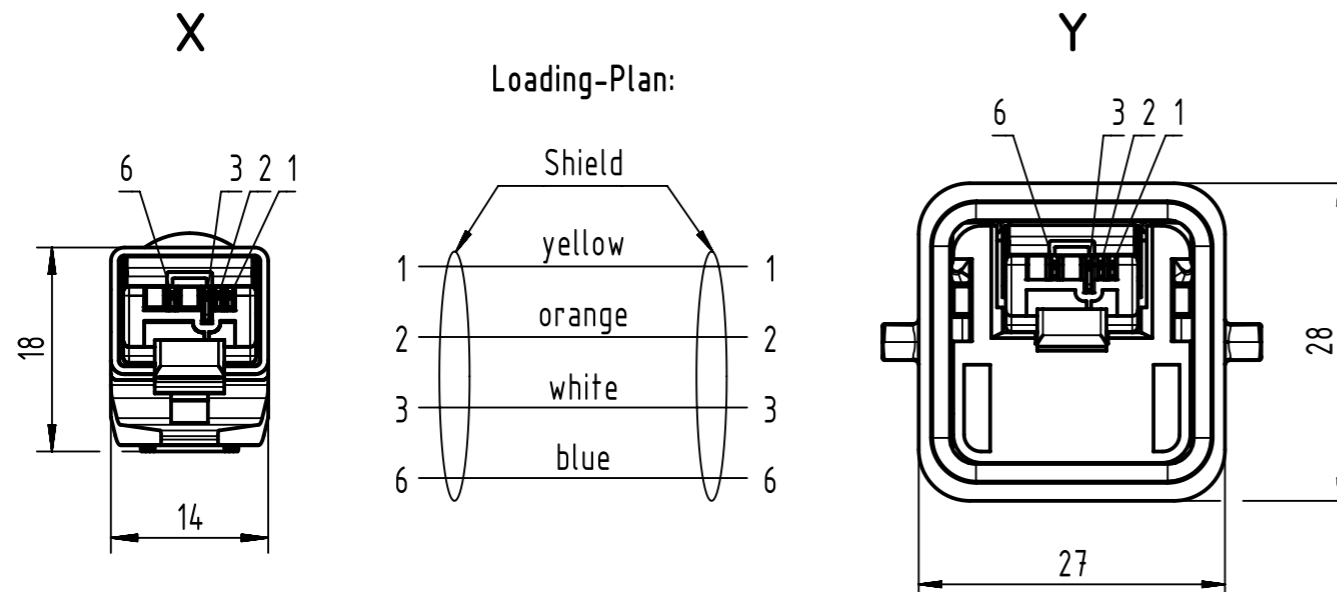


# Connector Location A

# Connector Location B

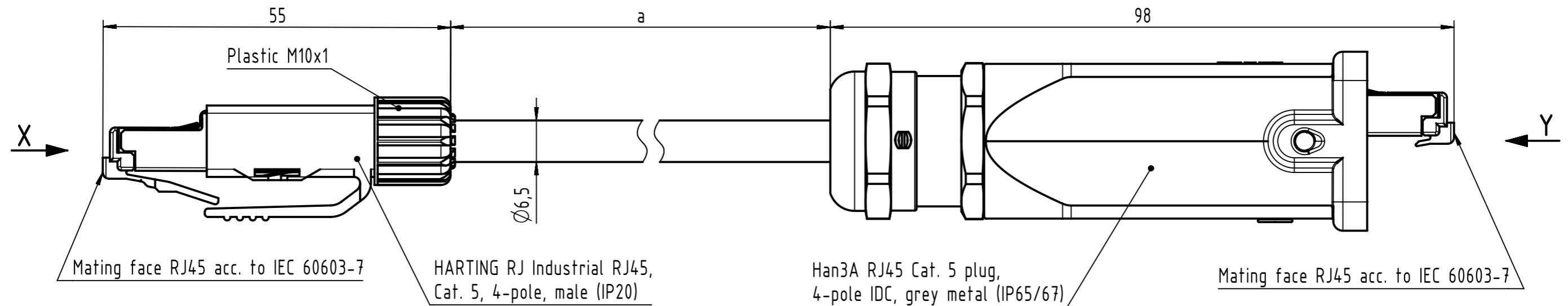

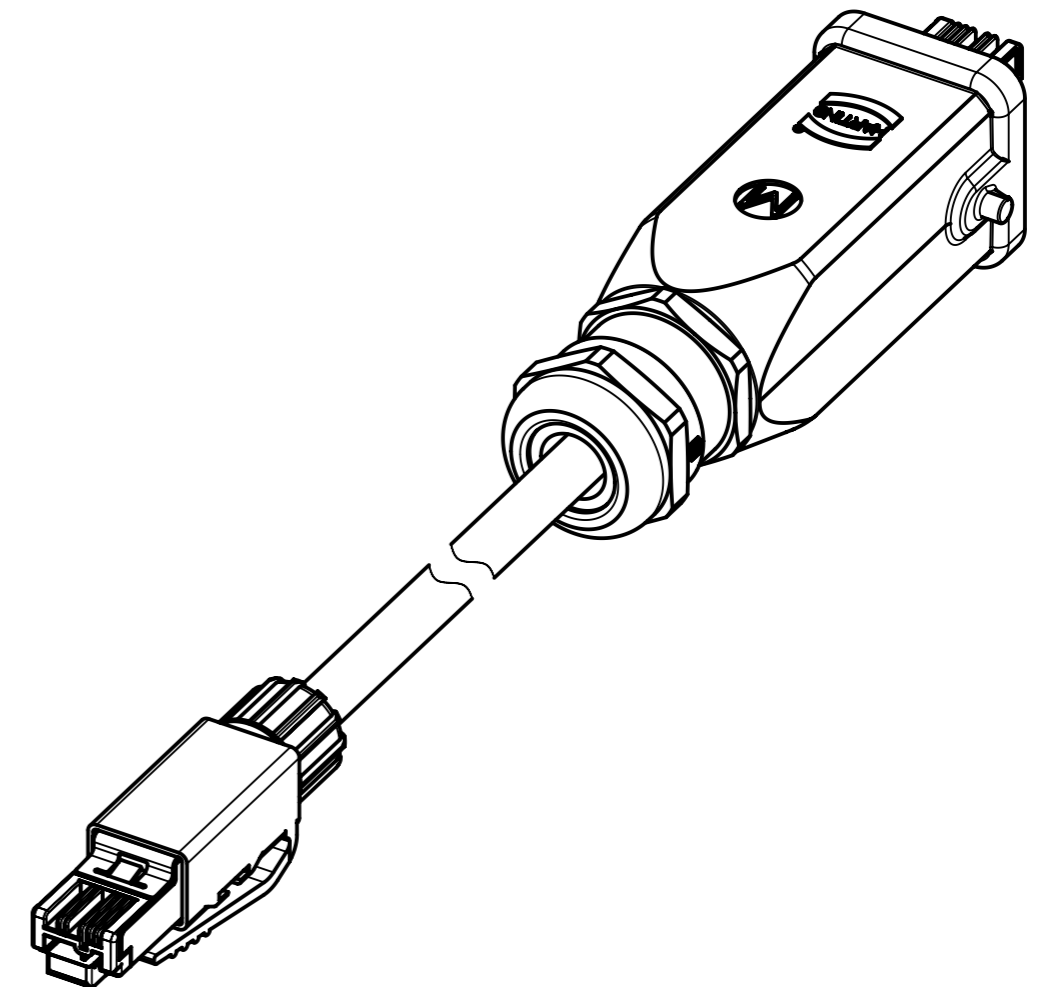

- Temperature range: -40°C...+70°C



		All Dimensions in mm		Tech. Character.		Free size tol.		According to production drawing	
All rights reserved		Created by		Inspected by		Standardisation		Date	
Department HCS - RO		STOCHECIC		COSTEA		MUNTEANV		2018-02-07	
HARTING Customised Solutions		Title		RJ Industrial Cable Assembly		Doc-Key / ECM-Nr.		100155468/UGD/006/C	
D-32339 Espelkamp		Type		TB		Number		0945700XXXX	
		Rev.		C		Page		1/2	

	1	2	3	4	5	6	7	8
A								
B	47	09457001183	RJ45 Ethernet stranded cable, 4xAWG22/7, PVC, Cat. 5+, green	100				
	46	09457001182		90				
	45	09457001181		80				
	44	09457001180		70				
	43	09457001179		60				
	42	09457001186		53				
	41	09457001178		50				
	40	09457001177		40				
	39	09457001184		33				
	38	09457001176		30				
C	37	09457001175		20				
	36	09457001174		15				
	35	09457001173		10				
	34	09457001172		9				
	33	09457001171		8				
	32	09457001185		7.5				
	31	09457001170		7				
	30	09457001169		6				
	29	09457001168		5				
	28	09457001167		4				
D	27	09457001166		3				
	26	09457001165		2				
	25	09457001164		1.5				
	24	09457001163		1				
	23	09457001162		0.5				
	22	09457001161	RJ45 Ethernet standard cable, AWG22/1, 2x2x0.64, PVC, Cat 5+, green	100				
	21	09457001160		90				
	20	09457001159		80				
	19	09457001158		70				
	18	09457001157		60				
	17	09457001156		50				
	16	09457001155		40				
	15	09457001154		30				
	14	09457001153		20				
	13	09457001152		15				
E	12	09457001151		10				
	11	09457001131		9				
	10	09457001130		8				
	9	09457001129		7				
	8	09457001128		6				
	7	09457001127		5				
	6	09457001126		4				
	5	09457001125		3				
	4	09457001124		2				
	3	09457001123		1.5				
F	2	09457001122		1				
	1	09457001121		0.5				
	Cont. no.	Part no.	Type of cable	Dim. a[m]				
	1							

For Information Only  
won't be replaced when changed

70	09457000061	RJ45 Ethernet trailing cable, AWG22/7, 2x2x0.75, PUR, Cat. 5+, green	100
69	09457000060		90
68	09457000059		80
67	09457000058		70
66	09457000057		60
65	09457000056		50
64	09457000055		40
63	09457000054		30
62	09457000053		20
61	09457000052		15
60	09457000032		12
59	09457000051		10
58	09457000031		9
57	09457000030		8
56	09457000029		7
55	09457000028		6
54	09457000027		5
53	09457000026		4
52	09457000025		3
51	09457000024		2
50	09457000023		1.5
49	09457000022		1
48	09457000021		0.5
Cont. no.	Part no.	Type of cable	Dim. a[m]
	All Dimensions in mm	Tech. Character.	Free size tol.
	All rights reserved Department HCS - RO	Created by STOCHECIC	Inspected by COSTEA
HARTING Customised Solutions D-32339 Espelkamp		Standardisation MUNTEANV	
		Date 2018-02-07	
		State Final Release	
		Doc-Key / ECM-Nr. 100155468/UGD/006/C 500000130817	
		Rev. C	
		Page 2/2	

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HARTING:](#)

[09457001184](#)