
 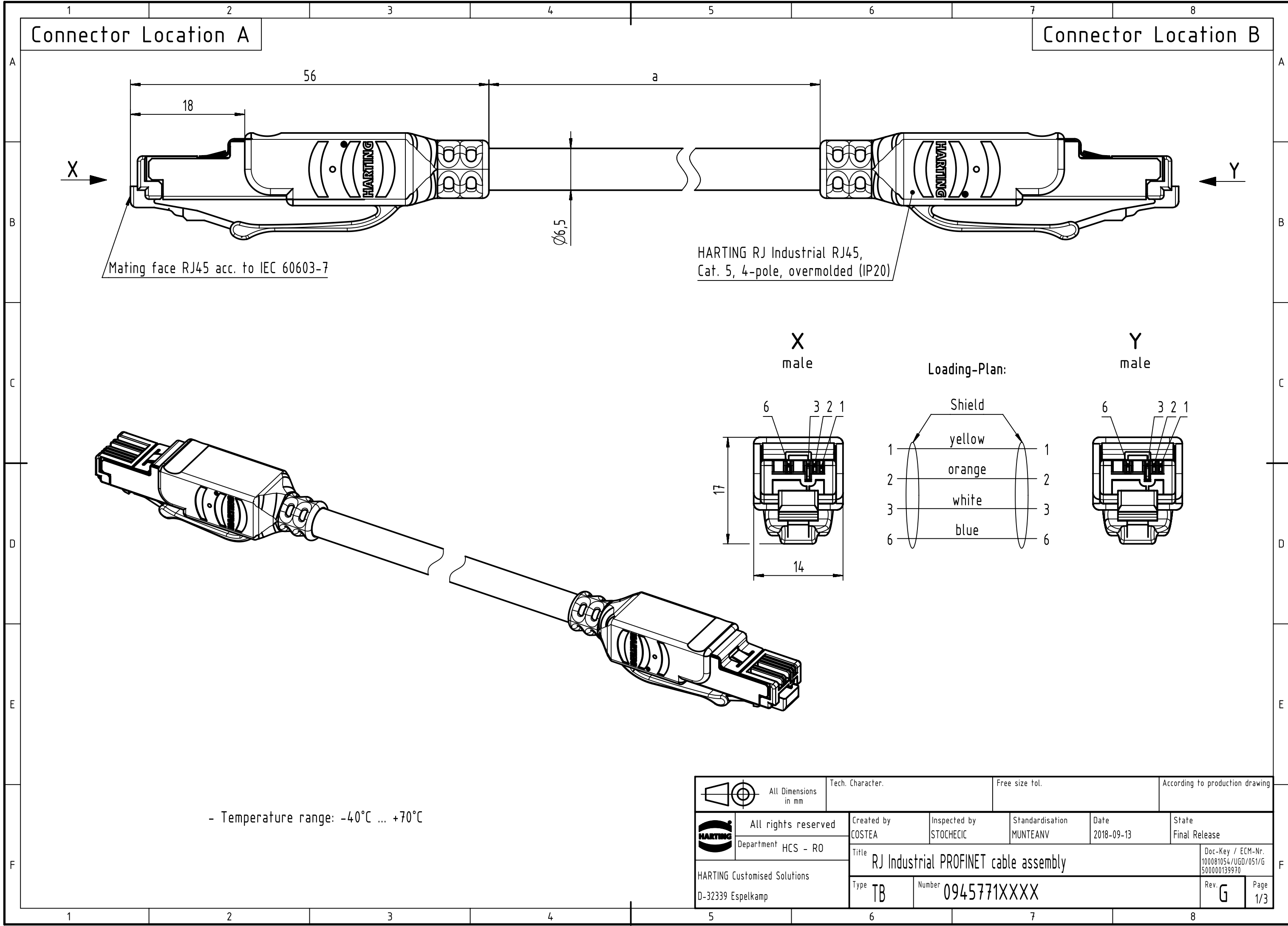




- Temperature range: -40°C ... +70°C

		All Dimensions in mm		Tech. Character.		Free size tol.		According to production drawing					
	All rights reserved			Created by COSTEA		Inspected by STOCHECIC		Standardisation MUNTEANV		Date 2018-09-13		State Final Release	
	Department HCS - RO												
	HARTING Customised Solutions D-32339 Espelkamp			Title RJ Industrial PROFINET cable assembly									Doc-Key / ECM-Nr. 100081054/UGD/051/G 500000139970
Type TB				Number 0945771XXXX							Rev. G		Page 1/3

1		2		3		4		5		6		7		8	
RJl Ethernet standard cable, AWG22/1, 2x2x0.64, PVC, Cat. 5+, green															
22		09457710061						100							
21		09457710060						90							
20		09457710059						80							
19		09457710058						70							
18		09457710057						60							
17		09457710056						50							
16		09457710055						40							
15		09457710054						30							
14		09457710053						20							
13		09457710052						15							
12		09457710051						10							
11		09457710031						9							
10		09457710030						8							
9		09457710029						7							
8		09457710028						6							
7		09457710027						5							
6		09457710026						4							
5		09457710025						3							
4		09457710024						2							
3		09457710023						1.5							
2		09457710022						1							
1		09457710021						0.5							
Cont. no.		Part no.		Type of cable				Dim. a[m]							

52		09457711161						100							
51		09457711160						90							
50		09457711159						80							
49		09457711158						70							
48		09457711157						60							
47		09457711156						50							
46		09457711155						40							
45		09457711154						30							
44		09457711153						20							
43		09457711152						15							
42		09457711132						13							
41		09457711151						10							
40		09457711131						9							
39		09457711130						8							
38		09457711129						7							
37		09457711128						6							
36		09457711127						5							
35		09457711136						4.5							
34		09457711126						4							
33		09457711135						3.5							
32		09457711125						3							
31		09457711140						2.2							
30		09457711124						2							
29		09457711139						1.8							
28		09457711123						1.5							
27		09457711122						1							
26		09457711138						0.9							
25		09457711121						0.5							
24		09457711134						0.3							
23		09457711137						0.15							
Cont. no.		Part no.		Type of cable				Dim. a[m]							
		All Dimensions in mm		Tech. Character.		Free size tol.		According to production drawing							
		All rights reserved Department HCS - RO		Created by COSTEA		Inspected by STOCHECIC		Standardisation MUNTEANV		Date 2018-09-13		State Final Release			
HARTING Customised Solutions D-32339 Espelkamp				Title RJ Industrial PROFINET cable assembly		Type TB		Number 0945771XXXXX		Rev. G		Page 2/3			

	1	2	3	4	5	6	7	8
A								
B	81	09457711183	RJ45 Ethernet trailing cable, AWG22/7, 2x2x0.75, PUR, Cat. 5+, green	100				
	80	09457711182		90				
	79	09457711181		80				
	78	09457711180		70				
	77	09457711179		60				
	76	09457711187		55				
	75	09457711178		50				
C	74	09457711177		40				
	73	09457711176		30				
	72	09457711175		20				
	71	09457711186		18				
	70	09457711174		15				
	69	09457711188		14				
	68	09457711189		12				
D	67	09457711173		10				
	66	09457711172		9				
	65	09457711171		8				
	64	09457711170		7				
	63	09457711169		6				
	62	09457711168		5				
E	61	09457711167		4				
	60	09457711166		3				
	59	09457711190		2.3				
	58	09457711165		2				
	57	09457711164		1.5				
	56	09457711163		1				
	55	09457711185		0.6				
	54	09457711162		0.5				
	53	09457711184		0.3				
F	Cont. no.	Part no.	Type of cable	Dim. a[m]				

	All rights reserved		Created by COSTEA		Inspected by STOCHECIC		Standardisation MUNTEANV		Date 2018-09-13		State Final Release		
	Department HCS - RO		Title RJ Industrial PROFINET cable assembly									Doc-Key / ECM-Nr. 100081054/UGD/051/G 500000139970	
	HARTING Customised Solutions D-32339 Espelkamp		Type TB		Number 0945771XXXX						Rev. G		Page 3/3

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

HARTING:

[09457710023](#) [09457710025](#) [09457710027](#) [09457710051](#) [09457710053](#) [09457710061](#) [09457711151](#)
[09457711156](#) [09457711161](#) [09457711164](#) [09457711166](#) [09457711168](#) [09457711173](#) [09457711175](#) [09457711178](#)
[09457711183](#) [09457711122](#) [09457711124](#) [09457711129](#) [09457711132](#) [09457711162](#) [09457711163](#)
[09457711165](#) [09457711169](#) [09457711174](#) [09457711184](#) [09457711123](#) [09457711125](#) [09457711127](#) [09457711153](#)
[09457711121](#) [09457711167](#) [09457711171](#) [09457711179](#) [09457711152](#) [09457711155](#) [09457711157](#)
[09457711177](#) [09457711176](#) [09457711128](#) [09457711134](#) [09457711188](#) [09457711170](#) [09457711180](#) [09457711126](#)
[09457711172](#) [09457710028](#) [09457710026](#) [09457710021](#)