
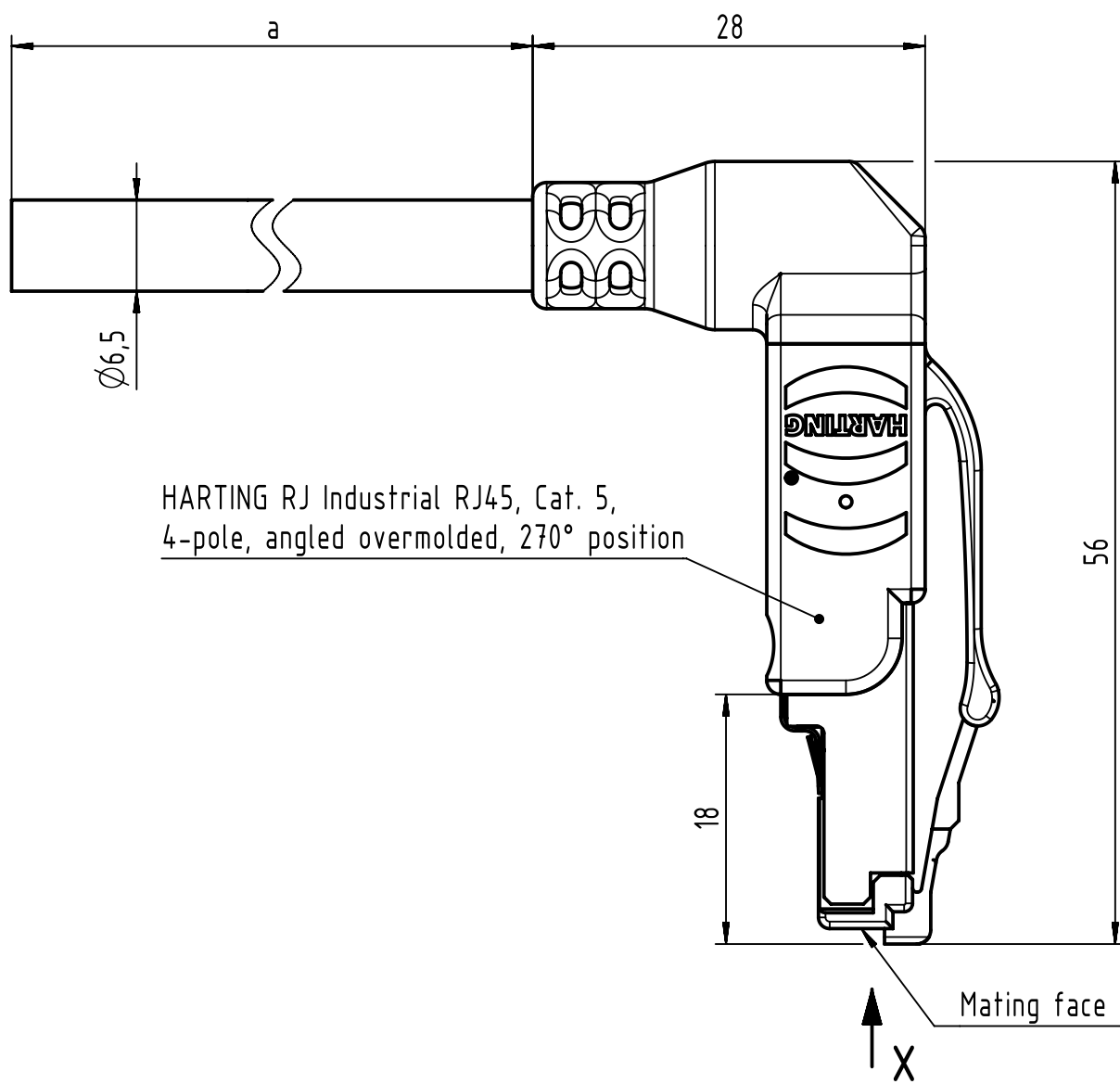


Connector Location A


Connector Location B

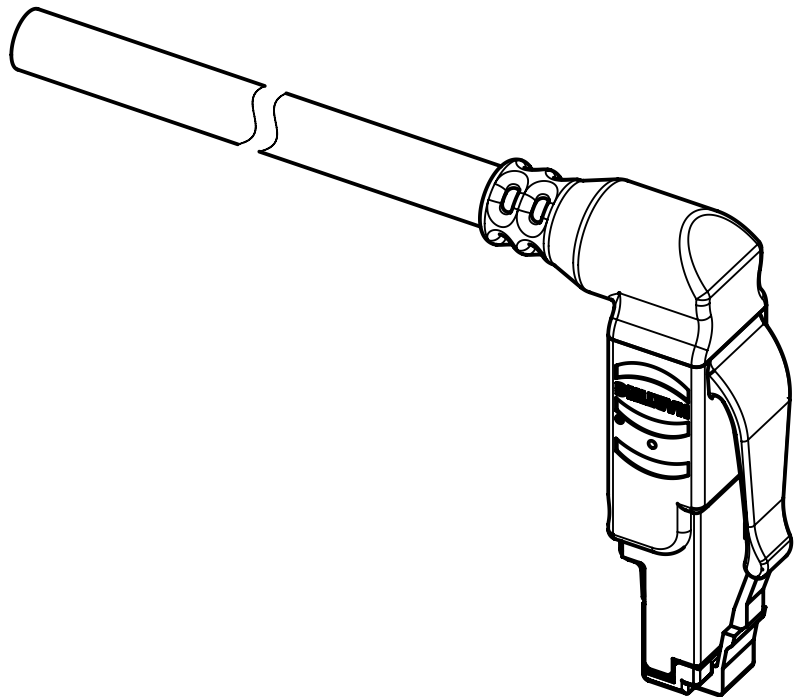


HARTING RJ Industrial RJ45, Cat. 5,
4-pole, angled overmolded, 270° position

Mating face RJ45 acc. to IEC 60603-7


Loading-Plan

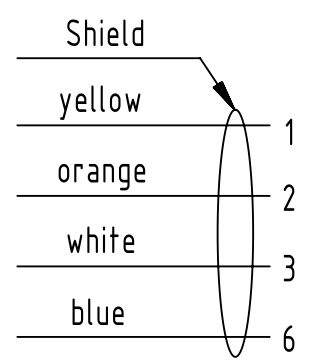

X
male

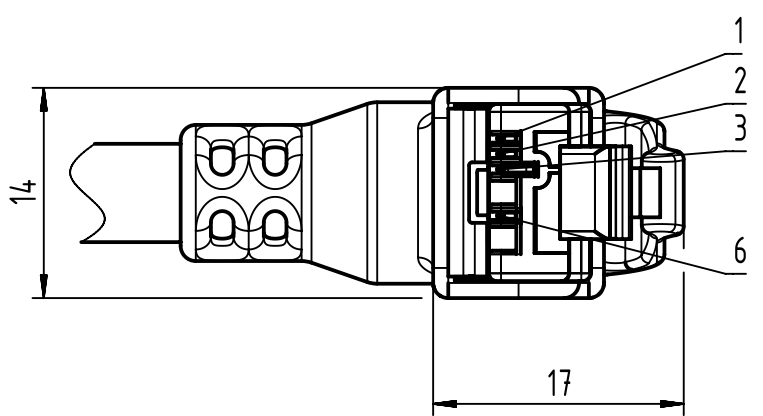

 - Protection level: IP20
- Temperature range: -40°C ... +70°C

 All Dimensions in mm		Tech. Character.		Free size tol.		According to production drawing	
All rights reserved		Created by STOCHECIC Stocheci		Inspected by COSTEA Costea		Standardisation MUNTEANV Muntean	
Department HCS - RO		Date 2018-05-17		State Final Release		Doc-Key / ECM-Nr. 100155463/UGD/015/C 500000135295	
HARTING Customised Solutions		Title RJ Industrial Cable Assembly		Type TB		Number 09470300XXX	
D-32339 Espelkamp		Rev. C		Page 1/2			

[illegible]

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

HARTING:

[09470300003](#) [09470300023](#) [09470300024](#) [09470300025](#) [09470300045](#) [09470300046](#) [09470300047](#)
[09470300048](#) [09470300049](#) [09470300026](#) [09470300027](#) [09470300029](#) [09470300034](#) [09470300051](#) [09470300001](#)
[09470300073](#)