

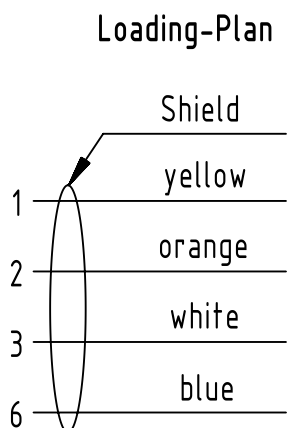
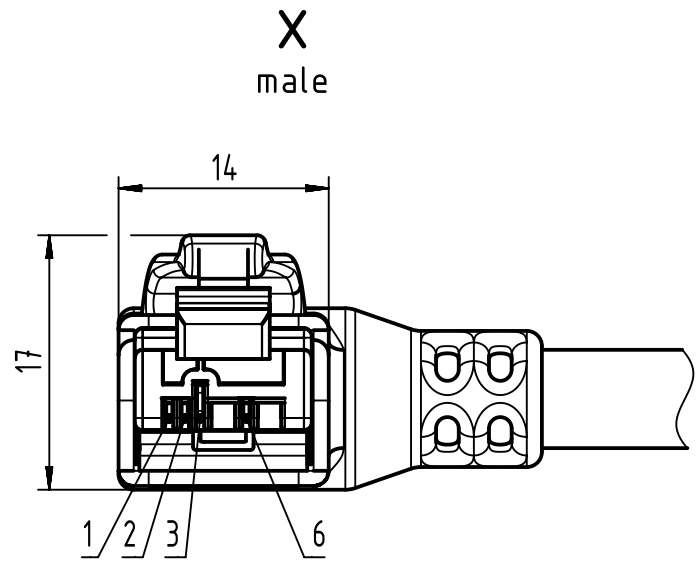


Connector Location A

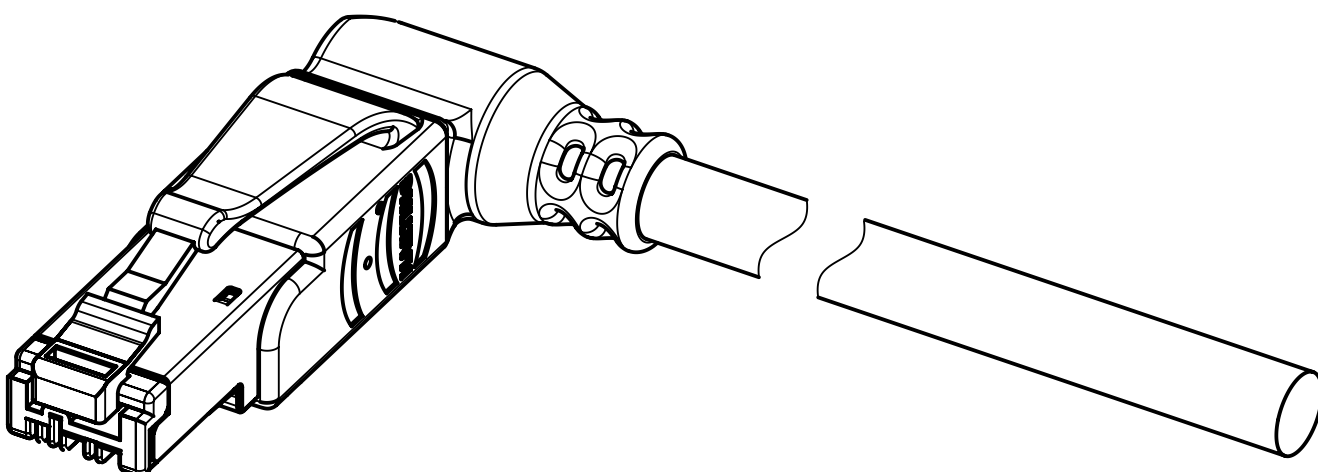

Connector Location B

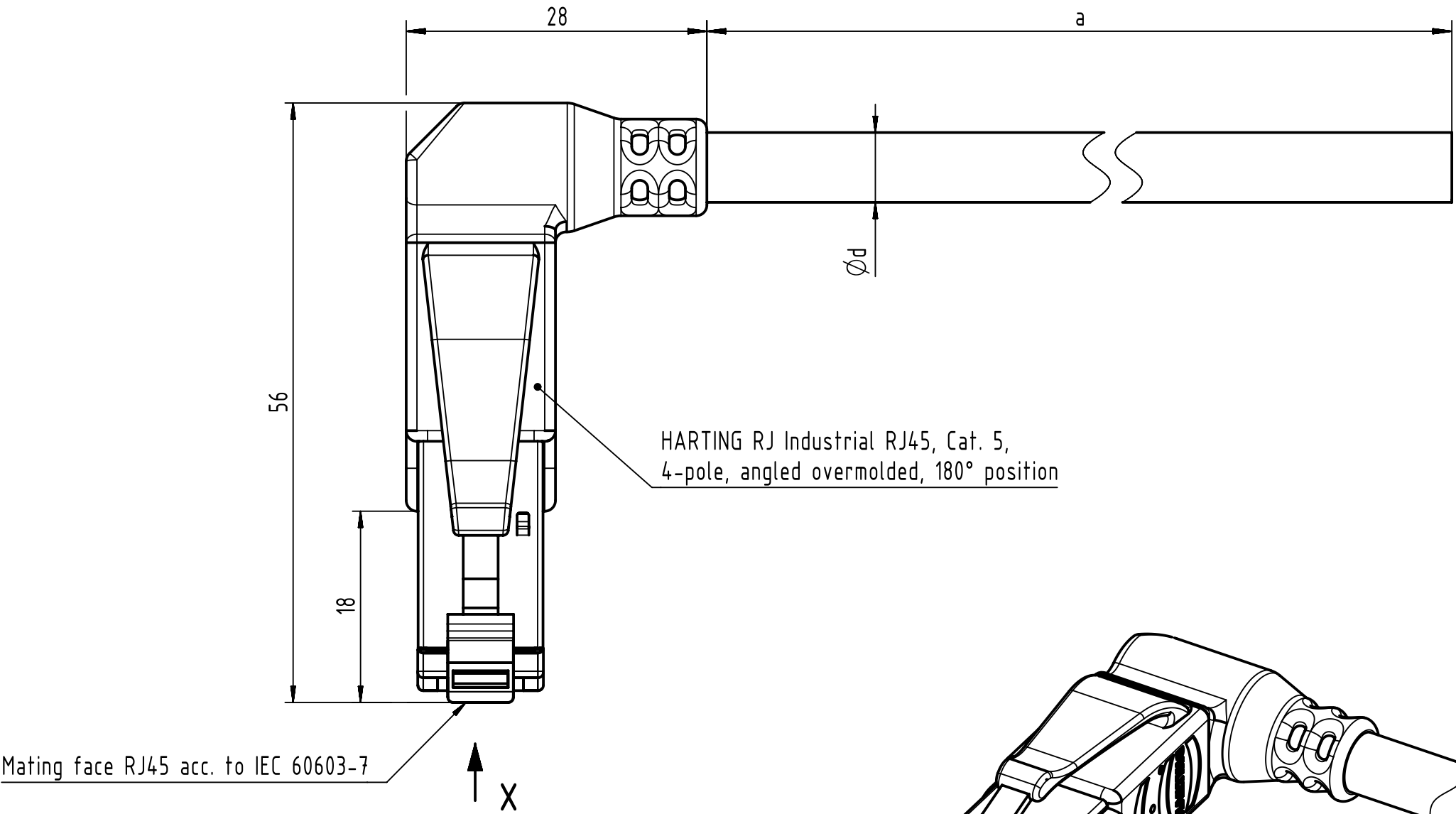

- Protection level: IP20
- Temperature range: -40°C ... +70°C

All Dimensions in mm		Tech. Character.		Free size tol.		According to production drawing	
	All rights reserved	Created by STOCHECIC Stocheci	Inspected by COSTEA Costea	Standardisation AVRAM Avram	Date 2018-05-11	State Final Release	
	Department HCS - RO	Title RJ Industrial Cable Assembly				Doc-Key / ECM-Nr. 100081066/UGD/014/E 500000134485	
	HARTING Customised Solutions D-32339 Espelkamp	Type TB	Number 094705000XX			Rev. E	Page 1/2

1		2		3		4		5		6		7		8		
A	52	09470500052		RJl Ethernet trailing cable, AWG22/7, 2x2x0.75, PUR, Cat. 5+, green		Ø6.5	6									
	51	09470500051					5									
	50	09470500050					4									
	49	09470500049					3									
	48	09470500048					2									
	47	09470500047					1.5									
B	46	09470500046			1											
	45	09470500045			0.5											
	44	09470500044			100											
	43	09470500043			90											
	42	09470500042			80											
	41	09470500041			70											
C	40	09470500040		RJl Ethernet stranded cable, 4xAWG22/7, PVC, Cat. 5+, green	60											
	39	09470500039			50											
	38	09470500038			40											
	37	09470500037			30											
	36	09470500036			20											
	35	09470500035			15											
D	34	09470500034			10											
	33	09470500033			9											
	32	09470500032			8											
	31	09470500031			7											
	30	09470500030			6											
	29	09470500029			5											
E	28	09470500028		RJl Ethernet standard cable, AWG22/1, 2x2x0.64, PVC, Cat. 5+, green	4											
	27	09470500027			3											
	26	09470500026			2											
	25	09470500025			1.5											
	24	09470500024			1											
	23	09470500023			0.5											
F	22	09470500022			100											
	21	09470500021			90											
	20	09470500020			80											
	19	09470500019			70											
	18	09470500018			60											
	17	09470500017			50											
G	16	09470500016		RJl Ethernet trailing cable, AWG22/7, 2x2x0.75, PUR, Cat. 5+, green	40											
	15	09470500015			30											
	14	09470500014			20											
	13	09470500013			15											
	12	09470500012			10											
	11	09470500011			9											
H	10	09470500010			8											
	9	09470500009			7											
	8	09470500008			6											
	7	09470500007			5											
	6	09470500006			4											
	5	09470500005			3											
I	4	09470500004			2											
	3	09470500003			1.5											
	2	09470500002			1											
	1	09470500001			0.5											
	Cont. no.	Part no.			Type of cable									Dim. d [mm]	Dim. a [m]	
	Cont. no.	Part no.			Type of cable									Dim. d [mm]	Dim. a [m]	

89	09470500089	RJl Ha-VIS EtherRail flexible data cable, AWG 22/7, 4x0.25, Cat. 5/5e, black	Ø6.6	1.5		
88	09470500088	RJl Ethernet stranded cable, AWG22/7, 2x2x0.75, outdoor, PVC, Cat. 5+, black	Ø6.5	100		
87	09470500087			90		
86	09470500086			80		
85	09470500085			70		
84	09470500084			60		
83	09470500083			50		
82	09470500082			40		
81	09470500081			30		
80	09470500080			20		
79	09470500079			15		
78	09470500078			10		
77	09470500077			9		
76	09470500076			8		
75	09470500075			7		
74	09470500074			6		
73	09470500073			5		
72	09470500072	4				
71	09470500071	3				
70	09470500070	2				
69	09470500069	1.5				
68	09470500068	1				
67	09470500067	0.5				
66	09470500066	RJl Ethernet trailing cable, AWG22/7, 2x2x0.75, PUR, Cat. 5+, green		100		
65	09470500065			90		
64	09470500064			80		
63	09470500063			70		
62	09470500062			60		
61	09470500061			50		
60	09470500060			40		
59	09470500059			30		
58	09470500058			20		
57	09470500057			15		
56	09470500056			10		
55	09470500055			9		
54	09470500054			8		
53	09470500053			7		
Cont. no.	Part no.			Type of cable	Dim. d [mm]	Dim. a [m]
 All Dimensions in mm				Tech. Character.		Free size tol.
 All rights reserved		Created by STOCHECIC Stocheci	Inspected by COSTEA Costea	Standardisation AVRAM Avram		
Department HCS - RO		Date 2018-05-11				
Title RJ Industrial Cable Assembly		State Final Release				
HARTING Customised Solutions		Doc-Key / ECM-Nr. 100081066/UGD/014/E 500000134485				
D-32339 Espelkamp		Type TB	Number 094705000XX	Rev. E		
		Page 2/2				

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HARTING:](#)

[09470500073](#)