
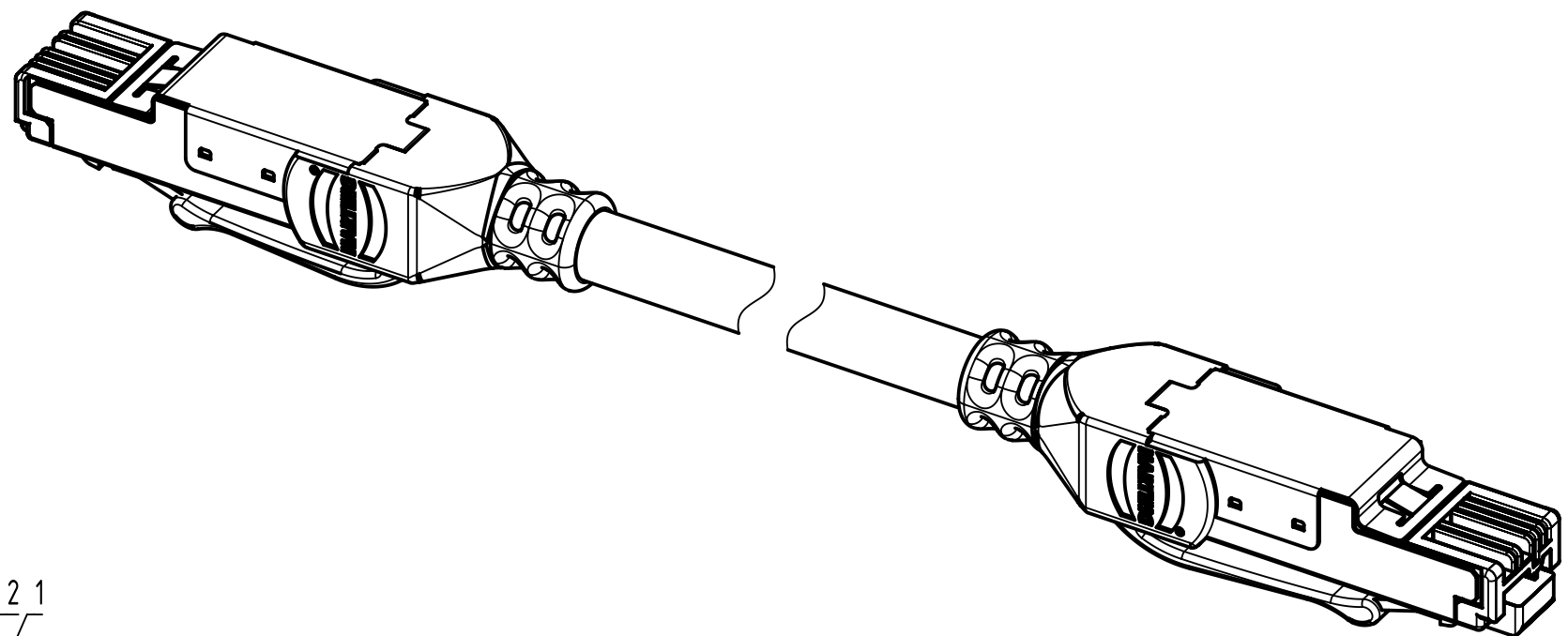


Connector Location A




Connector Location B

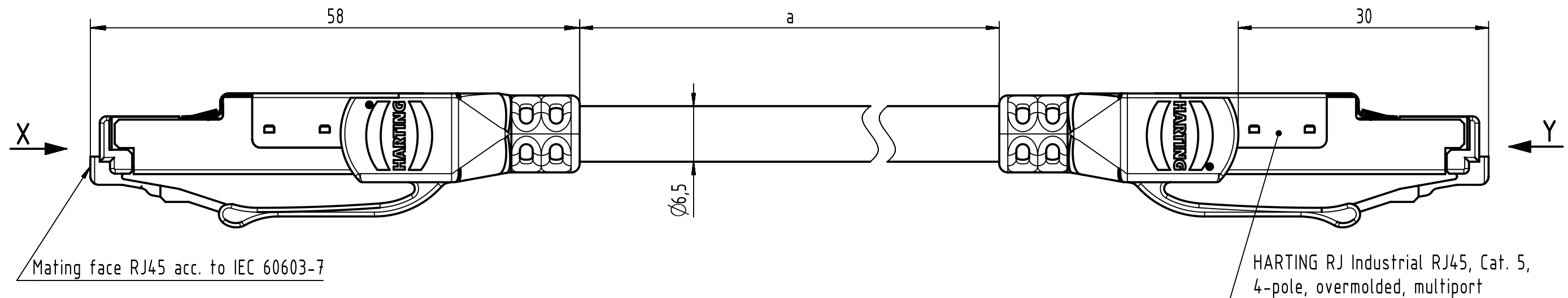

X
male

 
Y
male

Loading-Plan

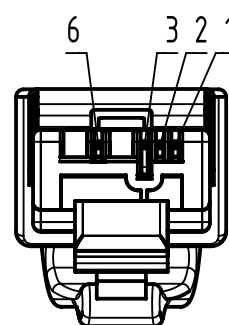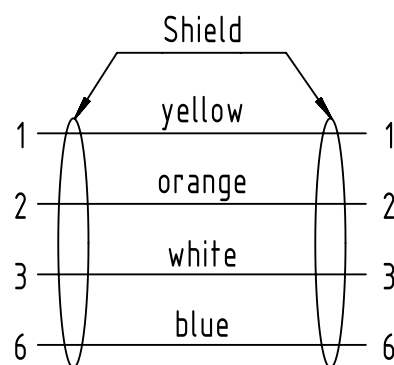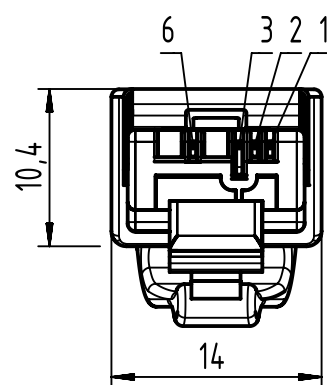

-Protection level: IP20
-Temperature range: -40°C ... +70°C



		All Dimensions in mm		Tech. Character.		Free size tol.		According to production drawing	
		All rights reserved		Created by STOCHECIC Stocheci		Inspected by COSTEA Costea		Standardisation MUNTEANV Muntean	
Department HCS - RO		Title RJ Industrial Cable Assembly		Date 2018-06-13		State Final Release		Doc-Key / ECM-Nr. 100155469/UGD/026/E 500000136213	
HARTING Customised Solutions D-32339 Espelkamp		Type TB		Number 09473434XXX		Rev. E		Page 1/3	

1		2		3		4		5		6		7		8	
A															
	48	09473434048	RJl Ethernet stranded cable, 4xAWG22/7, PVC, Cat. 5+, green		20	92	09473434092	RJl Ethernet trailing cable, AWG22/7, 2x2x0.75, PUR, Cat. 5+, green		2.5					
	47	09473434047			15	91	09473434091			2					
	46	09473434046			10	90	09473434090			1.5					
	45	09473434045			9	89	09473434089			1					
	44	09473434044			8	88	09473434088			0.6					
	43	09473434043			7.5	87	09473434087			0.5					
	42	09473434042			7	86	09473434086			0.3					
	41	09473434041			6	85	09473434085			0.2					
	40	09473434040			5	84	09473434084			100					
39	09473434039	4			83	09473434083	90								
B	38	09473434038	3.5	82	09473434082	80									
	37	09473434037	3	81	09473434081	70									
	36	09473434036	2.5	80	09473434080	60									
	35	09473434035	2	79	09473434079	50									
	34	09473434034	1.5	78	09473434078	40									
	33	09473434033	1	77	09473434077	30									
	32	09473434032	0.6	76	09473434076	20									
	31	09473434031	0.5	75	09473434075	15									
	30	09473434030	0.3	74	09473434074	10									
	29	09473434029	0.2	73	09473434073	9									
C	28	09473434028	100	72	09473434072	8									
	27	09473434027	90	71	09473434071	7.5									
	26	09473434026	80	70	09473434070	7									
	25	09473434025	70	69	09473434069	6									
	24	09473434024	60	68	09473434068	5									
	23	09473434023	50	67	09473434067	4									
	22	09473434022	40	66	09473434066	3.5									
	21	09473434021	30	65	09473434065	3									
	20	09473434020	20	64	09473434064	2.5									
	19	09473434019	15	63	09473434063	2									
D	18	09473434018	10	62	09473434062	1.5									
	17	09473434017	9	61	09473434061	1									
	16	09473434016	8	60	09473434060	0.6									
	15	09473434015	7.5	59	09473434059	0.5									
	14	09473434014	7	58	09473434058	0.3									
	13	09473434013	6	57	09473434057	0.2									
	12	09473434012	5	56	09473434056	100									
	11	09473434011	4	55	09473434055	90									
	10	09473434010	3.5	54	09473434054	80									
	9	09473434009	3	53	09473434053	70									
E	8	09473434008	2.5	52	09473434052	60									
	7	09473434007	2	51	09473434051	50									
	6	09473434006	1.5	50	09473434050	40									
	5	09473434005	1	49	09473434049	30									
	4	09473434004	0.6	Cont. no.	Part no.	Type of cable	Dim. a[m]								
	3	09473434003	0.5	 All Dimensions in mm	Tech. Character.		Free size tol.		According to production drawing						
	2	09473434002	0.3		Created by STOCHECIC Stocheci		Inspected by COSTEA Costea	Standardisation MUNTEANV Muntean	Date 2018-06-13	State Final Release					
	1	09473434001	0.2	HARTING Customised Solutions D-32339 Espelkamp		Title RJ Industrial Cable Assembly		Doc-Key / ECM-Nr. 100155469/UGD/026/E 500000136213							
	Cont. no.		Part no.	Type of cable	Dim. a[m]	Type TB	Number 09473434XXX		Rev. E	Page 2/3					
	1		2		3		4		5		6		7		8

	1	2	3	4	5	6	7	8
A								
	142	09473434140		100				
	141	09473434139		90				
	140	09473434138		80				
	139	09473434137		70				
	138	09473434136		60				
	137	09473434135		50				
	136	09473434134		40				
	135	09473434142		35				
B	134	09473434133		30				
	133	09473434141		25				
	132	09473434132		20				
	131	09473434131		15				
	130	09473434130		10				
	129	09473434129		9				
	128	09473434128		8				
	127	09473434127		7.5				
	126	09473434126		7				
	125	09473434125		6				
C	124	09473434124		5				
	123	09473434123		4				
	122	09473434122		3.5				
	121	09473434121		3				
	120	09473434120		2.5				
	119	09473434119		2				
	118	09473434118		1.5				
	117	09473434117		1				
	116	09473434116		0.6				
	115	09473434115		0.5				
D	114	09473434114		0.3				
	113	09473434113		0.2				
	112	09473434112		100				
	111	09473434111		90				
	110	09473434110		80				
	109	09473434109		70				
	108	09473434108		60				
	107	09473434107		50				
	106	09473434106		40				
	105	09473434105		30				
E	104	09473434104		20				
	103	09473434103		15				
	102	09473434102		10				
	101	09473434101		9				
	100	09473434100		8				
	99	09473434099		7.5				
	98	09473434098		7				
	97	09473434097		6				
	96	09473434096		5				
	95	09473434095		4				
	94	09473434094		3.5				
F	93	09473434093		3				
	Cont. no.	Part no.	Type of cable	Dim. a[m]				
	1	2	3	4	5	6	7	8

RJI Ethernet stranded cable,
AWG22/7, 2x2x0.75, outdoor,
PVC, Cat. 5+, black

RJI Ethernet trailing cable,
AWG22/7, 2x2x0.75, PUR, Cat. 5+, green

		All Dimensions in mm		Tech. Character.		Free size tol.		According to production drawing	
		All rights reserved		Created by STOCHECIC Stocheci		Inspected by COSTEA Costea		Standardisation MUNTEANV Muntean	
Department HCS - RO		Title RJ Industrial Cable Assembly		Date 2018-06-13		State Final Release		Doc-Key / ECM-Nr. 100155469/UGD/026/E 500000136213	
HARTING Customised Solutions D-32339 Espelkamp		Type TB		Number 09473434XXX		Rev. E		Page 3/3	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HARTING:](#)

[09473434009](#)