
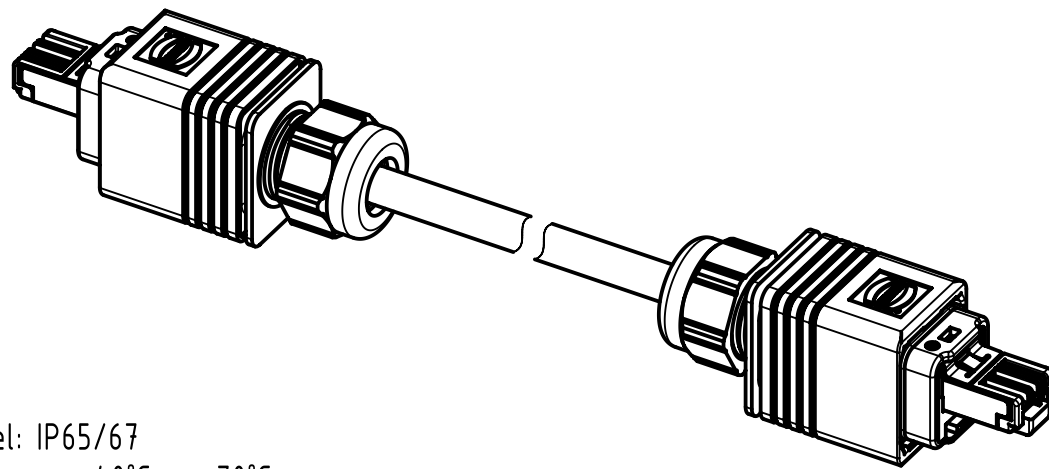





1	2
Connector Location A	

7	8
Connector Location B	

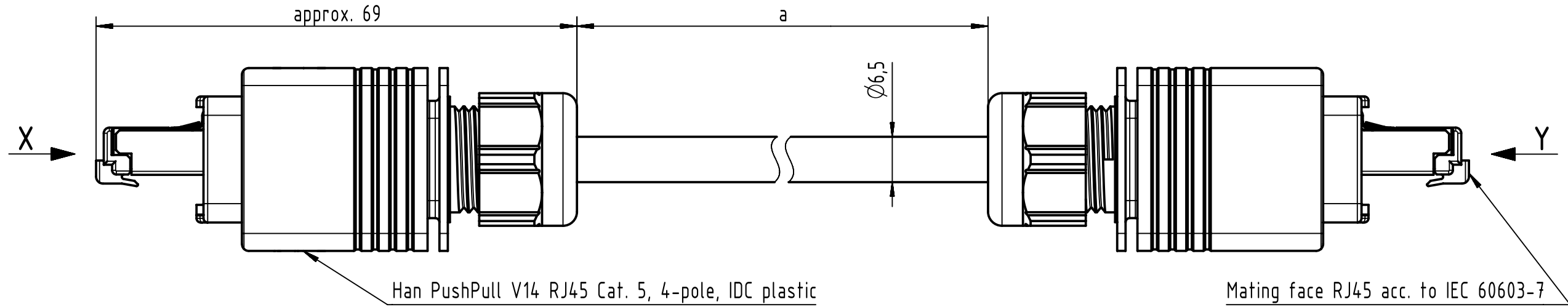

- Protection level: IP65/67
- Temperature range: -40°C ... +70°C

22	09475555022	RJ45 Ethernet Standard Cable, 4xAWG 22/1, PVC, Cat. 5+, green	100
21	09475555021		90
20	09475555020		80
19	09475555019		70
18	09475555018		60
17	09475555017		50
16	09475555016		40
15	09475555015		30
14	09475555014		20
13	09475555013		15
12	09475555012		10
11	09475555011		9
10	09475555010		8
9	09475555009		7
8	09475555008		6
7	09475555007		5
6	09475555006		4
5	09475555005		3
4	09475555004		2
3	09475555003		1.5
2	09475555002		1
1	09475555001		0.5
Cont. no.	Part no.	Type of cable	Dim. a[m]

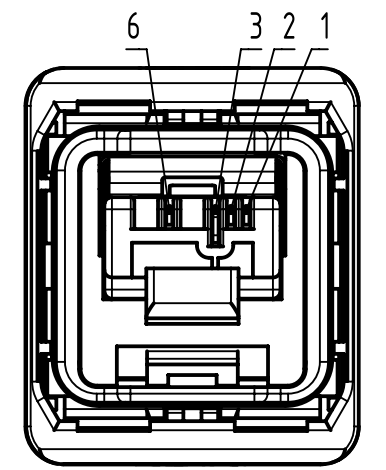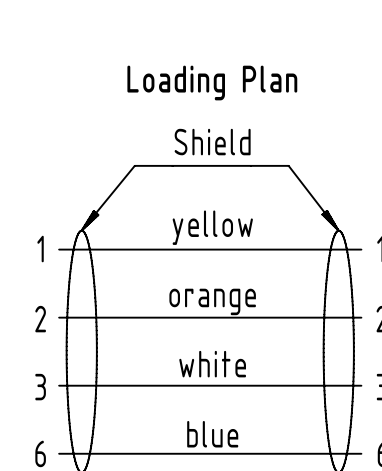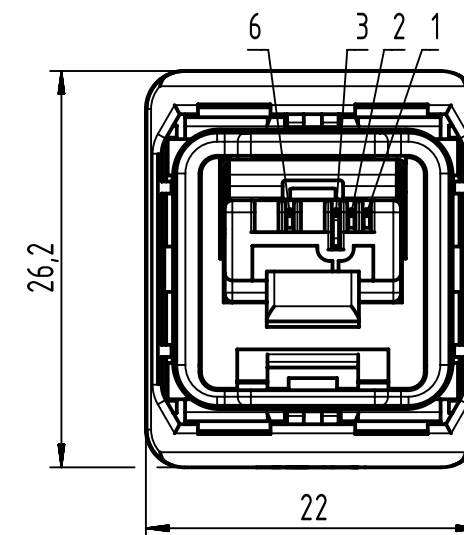

		All Dimensions in mm		Tech. Character.		Free size tol.		According to production drawing	
		All rights reserved Department HCS - RO		Created by STOCHEIC Stocheci		Inspected by COSTEA Costea		Standardisation MUNTEANV Muntean	
HARTING Customised Solutions D-32339 Espelkamp		Title RJ Industrial Cable Assembly		Date 2019-09-04		State Final Release		Doc-Key / ECM-Nr. 100155398/UGD/004/D 500000157673	
		Type TB		Number 09475555XXX		Rev. D		Page 1/2	

[illegible]

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

HARTING:

[09475555167](#) [09475555172](#) [09475555174](#) [09475555163](#) [09475555165](#) [09475555162](#)