




Connector Location A

Connector Location B


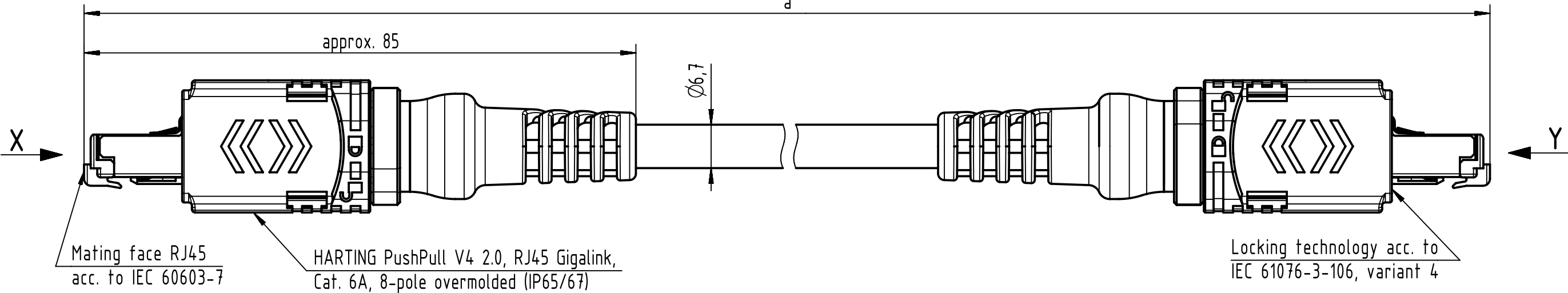


Loading Plan
acc. to TIA/EIA 568B

X
male

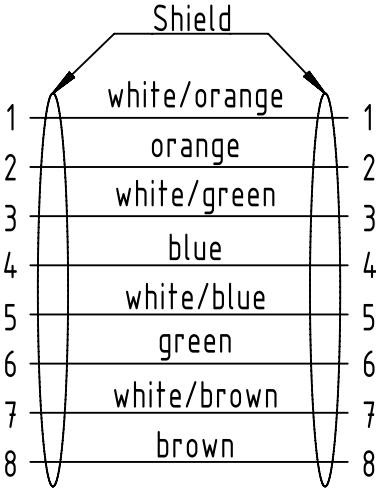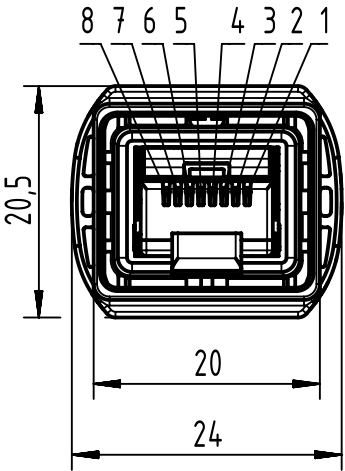

Y
male

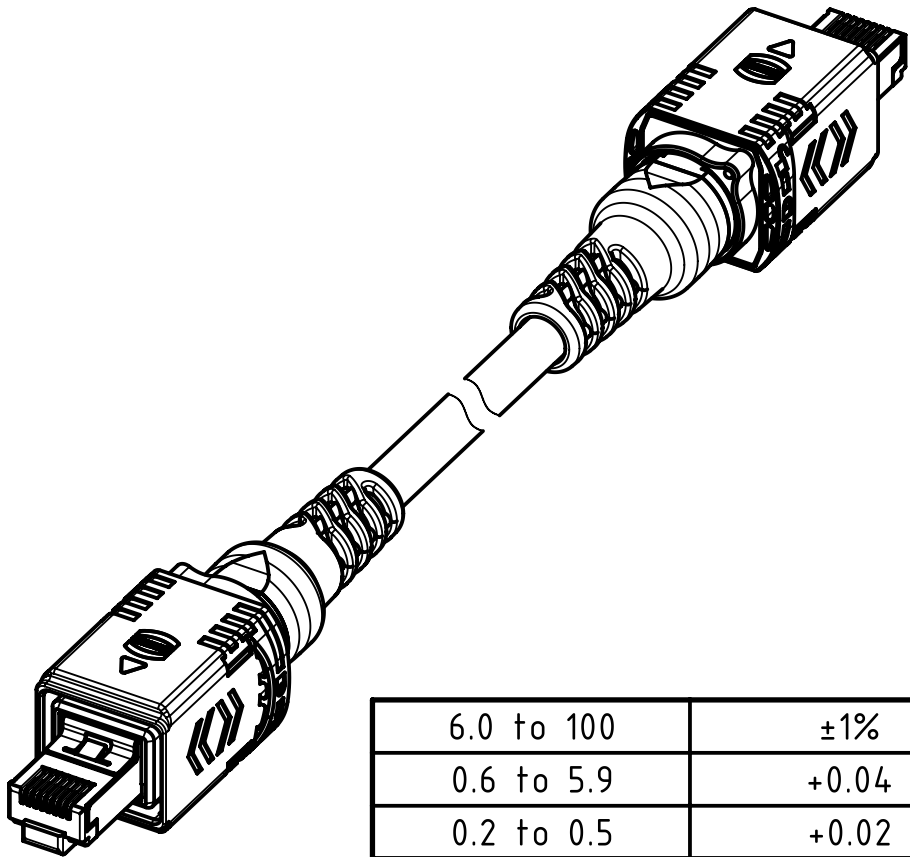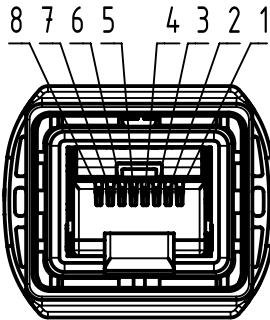

6.0 to 100	±1%
0.6 to 5.9	+0.04
0.2 to 0.5	+0.02
a [m]	Tolerance

length in "1m" step	100	XXX=000
	99	XXX=990
	.	.
	12	XXX=120
length in "0.1m" step	11	XXX=110
	10	XXX=100
	9.9	XXX=099
	9.8	XXX=098
	.	.
	0.5	XXX=005
	0.4	XXX=004
	0.3	XXX=003
	0.2	XXX=002
Step	a [m]	XXX

RJ45 Ethernet Stranded Cable,
4x2xAWG 26/7, PUR,
Cat. 6A, yellow

09482828756XXX

Type of cable

Part no.

Temperature range: -40°C +70°C

All Dimensions in mm		Tech. Character.		Free size tol.		According to production drawing	
	All rights reserved	Created by STOCHECIC Stocheci	Inspected by COSTEA Costea	Standardisation MUNTEANV Muntean	Date 2019-08-07	State Final Release	
	Department HCS - RO	Title HA PPV4 2.0 RJ45 Cat6A PUR				Doc-Key / ECM-Nr. 100696412/UGD/001/D 500000154771	
	HARTING Customised Solutions D-32339 Espelkamp	Type TB	Number 09482828756XXX			Rev. D	Page 1/1

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HARTING:](#)

[09482828756020](#)