
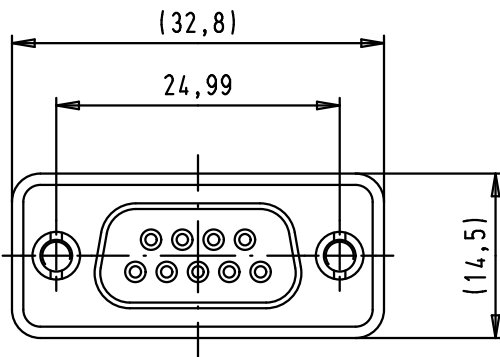
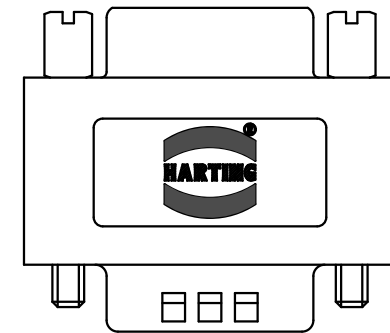
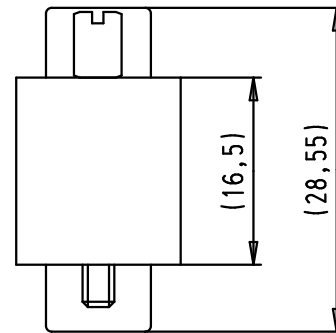


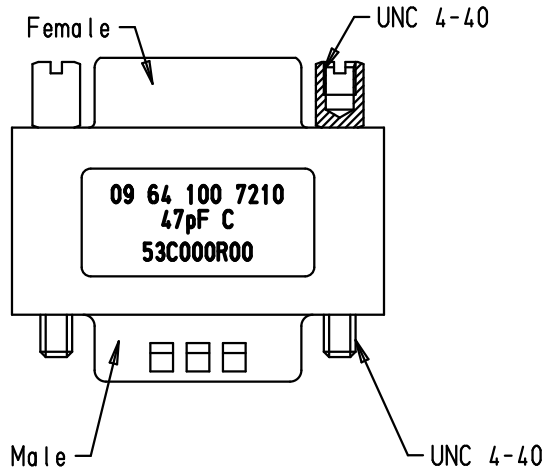

 
SPECIFICATIONS

Filter type	C
Capacitance	47 pF±20%
Working voltage	100 V
Current rating	6,5 A

Minimum insertion loss

FREQUENCY (MHz)	ATTENUATION (dB)
5	-
10	-
50	-
100	-
500	30
1000	35

Note: Jack-screws are not pre-mounted to allow mounting from any ends

				Dat.	Name	 All Dim. in mm Orig. Size DIN A 4	Male / Female D-Sub filter adapter, 9 poles, 47 pF	Maßstab/ Scale 1,5:1
			Detail.	03/09/07	JS			
			Insp.					
			Stand.					
34901	01/04/08	BB					TB 09 64 100 7210	Blatt/ Page 1 / 1
34894	12/03/08	PK						
	03/09/07	JS						
Mod.	Dat.	Name				HARTING EURL F-95972 Paris	Sub.	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HARTING:](#)

[09641007210](#)