



5

4

3

2



1

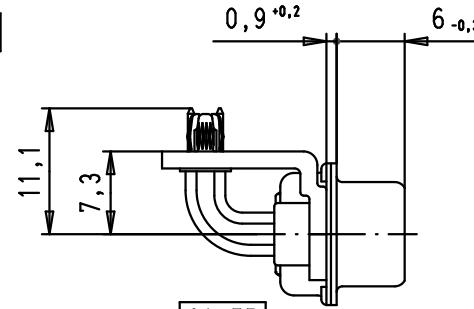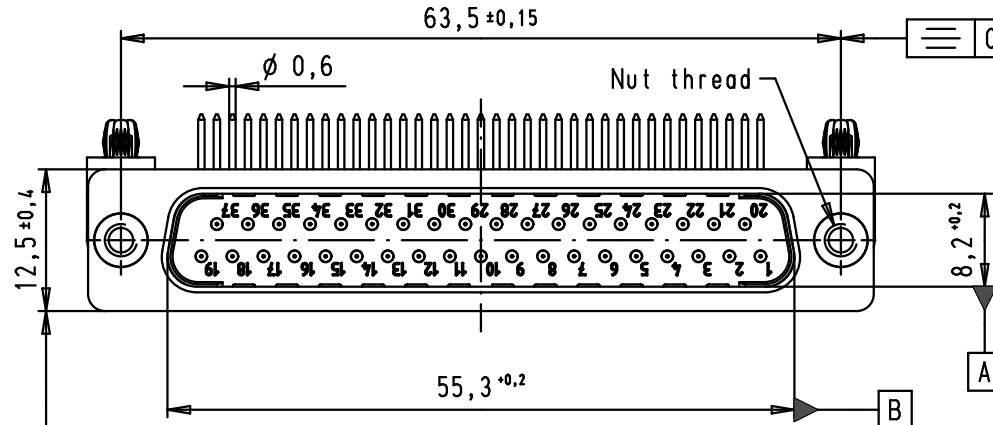

SPECIFICATIONS

Performance level	PL2
Filter type	C
Capacitance	1000 pF $\pm 20\%$
Working voltage	100 V
Current rating	7,5 A
Insulation resistance	>1 G Ω


FREQUENCY (MHz)	ATTENUATION (dB)
5	1
10	3
50	12
100	20
500	34
1000	30

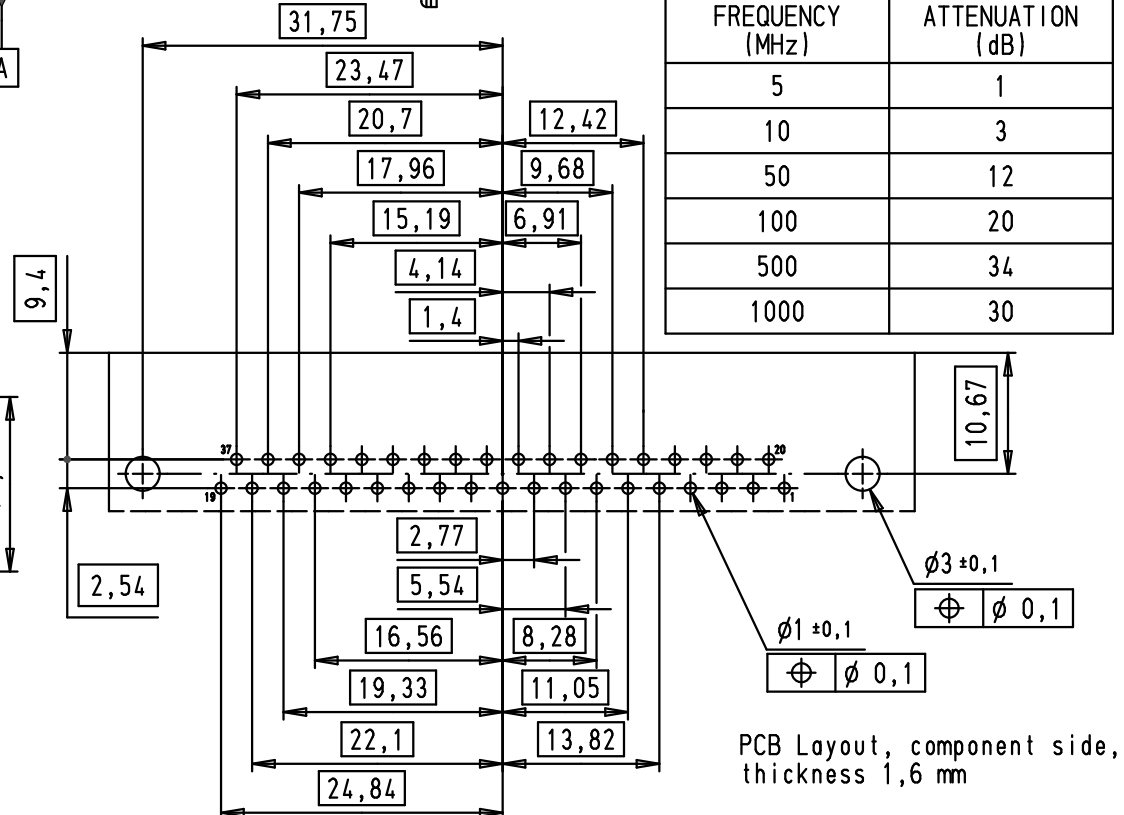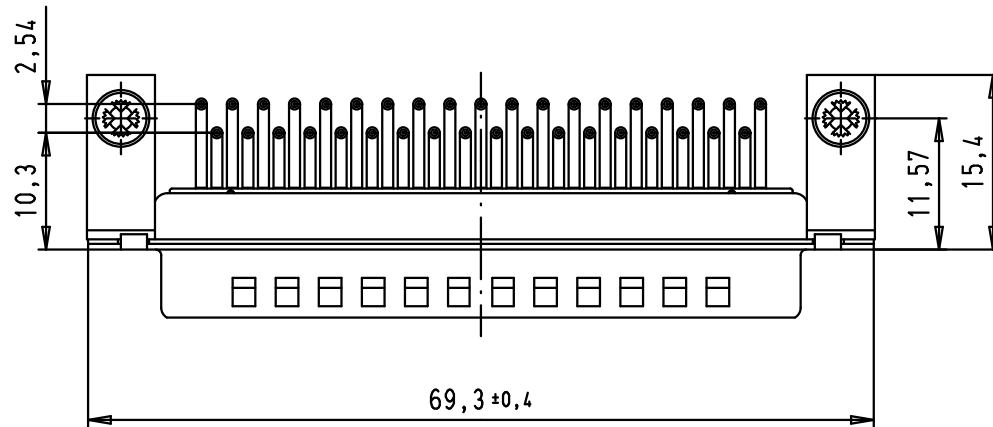

PCB Layout, component side, thickness 1,6 mm

Mod.	Dat.	Name
36283	12/01/12	SD
35300	01/12/08	PK
33800	02/08/06	PK
31058	08/07/02	CV
Mod.	Dat.	Name

HARTING EURL
F-95972 Paris

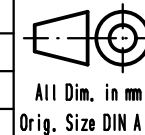

D-Sub, male, angled,
37 poles, turned solder pins,
clinch nuts and
brackets with board locks

Maßstab/
Scale
1,5:1

TB 09 64 424 723X

Blatt/ Page
1 / 4

09 64 424 7233	M3
09 64 424 7232	4-40 UNC-2B
Part number	Nut thread

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

HARTING:

[09644247232](#) [09644247233](#)