

1		2		3		4		5		6		7		8	




har-flex angled male connector




TAPE LAYOUT & PACKAGING

Tape acc. to IEC 60286-3

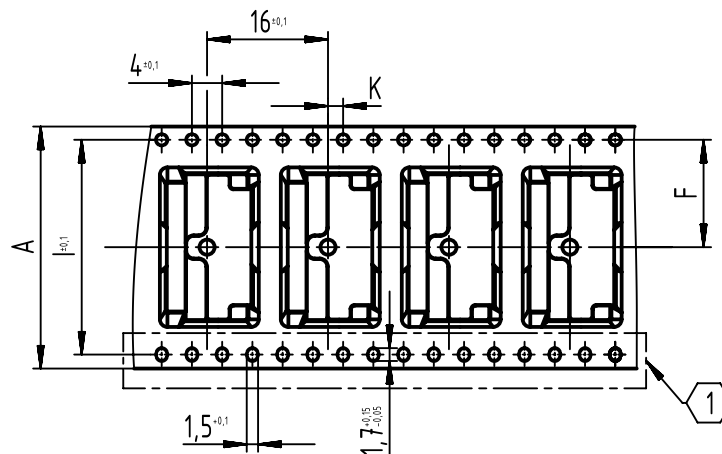


Tape dimensions:	A	F	I	K
poles 06 to 12	24,0±0,3/-0,1	11,5±0,1	-	2±0,1
poles 14 to 20	32,0±0,3	14,2±0,1	28,4	2±0,1
poles 22 to 40	44,0±0,3	20,2±0,1	40,4	2±0,15
poles 42 to 56	56,0±0,3	26,2±0,1	52,4	2±0,15
poles 58 to 80	72,0±0,3	34,2±0,3	68,4	2±0,2
poles 82 to 100	88,0±0,3	42,2±0,3	84,4	2±0,2

1 NO DOUBLE SPROCKET HOLES FOR 06, 08, 10 AND 12 POLE NUMBERS (TAPE SIZE 24)

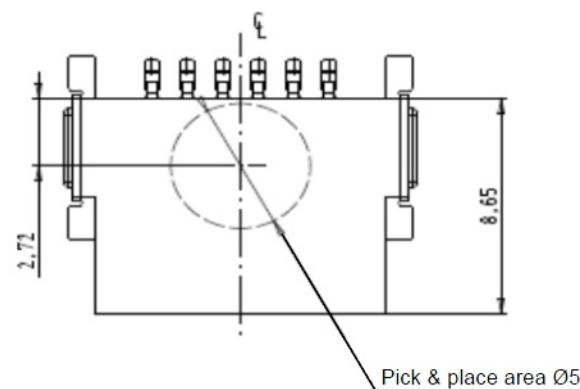

Packaging indices ("XXX" in part number)		
Index	Packaging unit	Packaging
000	560	Tape & reel
333	1	Tape


REEL DIMENSIONS

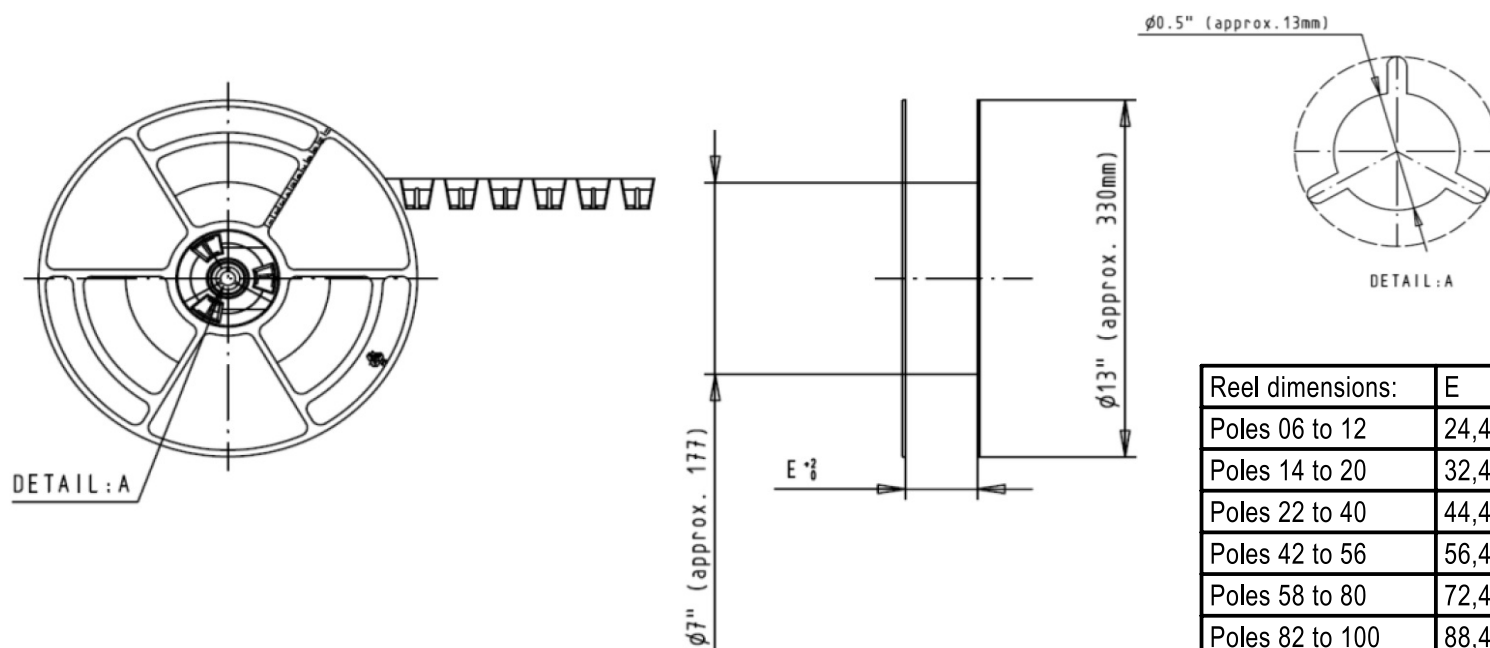

Reel dimensions:	E
Poles 06 to 12	24,4
Poles 14 to 20	32,4
Poles 22 to 40	44,4
Poles 42 to 56	56,4
Poles 58 to 80	72,4
Poles 82 to 100	88,4


APPLICATION INFORMATION

angled male

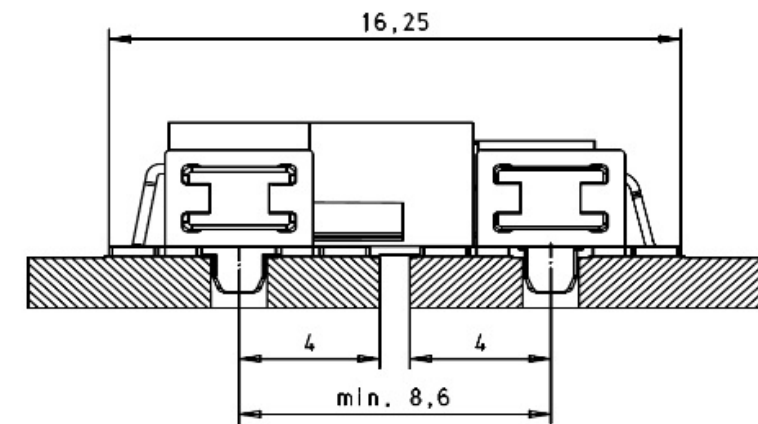

angled female

angled male

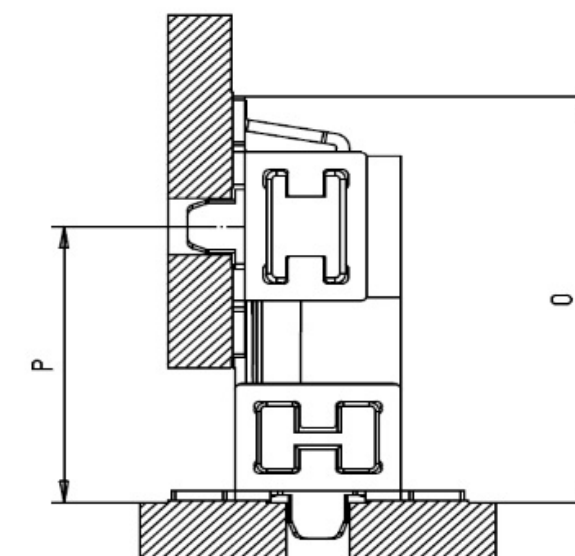

straight female

9,05	10,5	14,33
6,25	7,7	11,53
Y	P min.	0



All Dimensions in mm
Original Size DIN A3

Scale
1:1

Free size tol.

Ref.

Sub.



All rights reserved
Department EC PD - CN

Created by
ZHUANGJ

Inspected by
LUOK

Standardisation
HOFFMANN

Date
2018-05-21

State
Final Release

Title
har-flex male angled

Doc-Key / ECM-Nr.
100578045/UGD/000/C
500000135280

HARTING Electronics GmbH

D-32339 Espelkamp

Type
DS

Number
15151200301

Rev.
C

Page
2/2

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

HARTING:

<u>15150122601000</u>	<u>15150402601000</u>	<u>15150502601000</u>	<u>15150802601000</u>	<u>15150202601000</u>	<u>15150682601000</u>
<u>15150062601000</u>	<u>15150162601000</u>	<u>15150262601000</u>	<u>15150322601000</u>	<u>15151002601000</u>	<u>15150102601000</u>
<u>15150382601000</u>	<u>15150082601000</u>	<u>15150482601000</u>	<u>15150126601000</u>	<u>15150142601000</u>	<u>15150625601000</u>
<u>15150342601000</u>	<u>15150642601000</u>	<u>15150066601000</u>	<u>15150302601000</u>	<u>15150422601000</u>	<u>15150266601000</u>
<u>15150962601000</u>	<u>15150065601000</u>	<u>15150765601000</u>	<u>15150242601000</u>	<u>15150622601000</u>	<u>15150326601000</u>
<u>15150186601000</u>	<u>15150086601000</u>	<u>15150206601000</u>	<u>15150405601000</u>	<u>15150842601000</u>	<u>15150325601000</u>
<u>15150106601000</u>					