
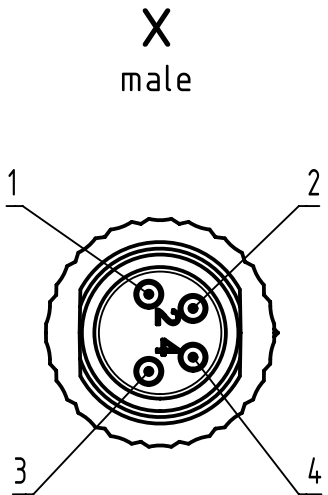



Connector Location A

Connector Location B

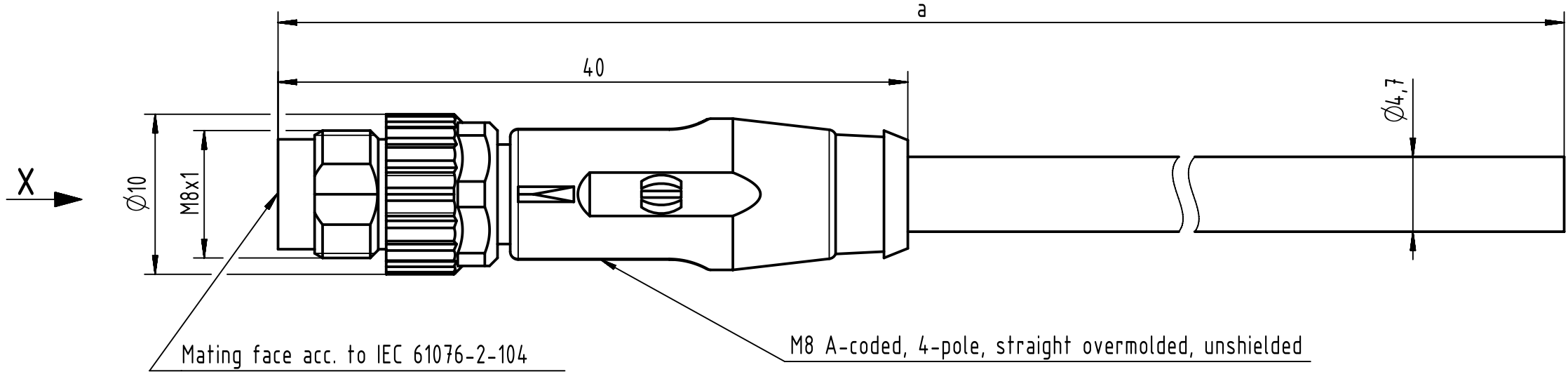

Loading-Plan	
1	brown
2	white
3	blue
4	black

- Protection level: IP67
- Temperature range: -25°C ... +80°C

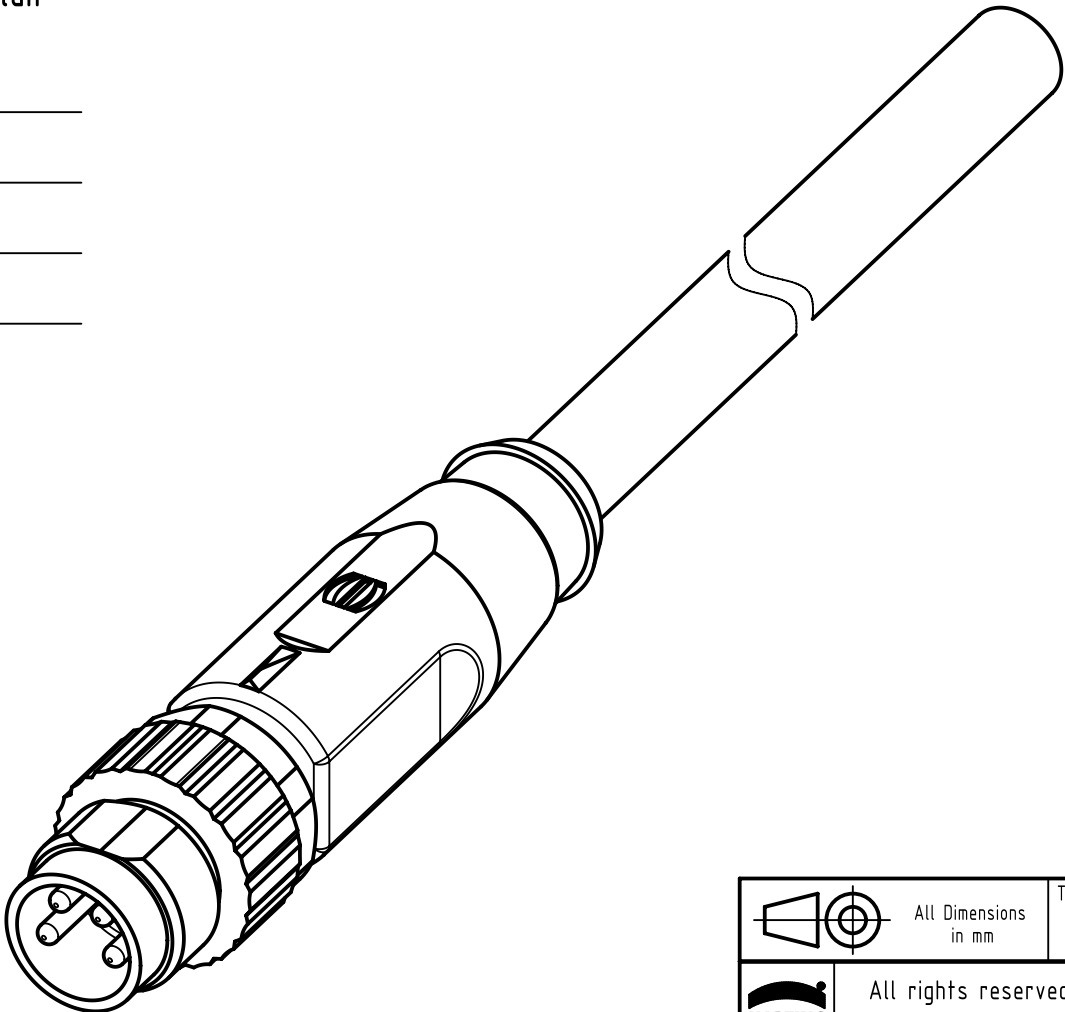

4.0 to 40	±1%
0.1 to 3.9	+0.04
a [m]	Tolerance

length in "1m" step	40	XXX=400
	39	XXX=390
	.	.
	12	XXX=120
length in "0.1m" step	11	XXX=110
	10	XXX=100
	9.9	XXX=099
	9.8	XXX=098
	.	.
	0.4	XXX=004
	0.3	XXX=003
	0.2	XXX=002
	0.1	XXX=001
Step	a [m]	XXX

PVC grey, 4x0.25mm²	21348000481XXX
Type of cable	Part no.

All Dimensions in mm		Tech. Character.		Free size tol.		According to production drawing	
All rights reserved		Created by STOCHECIC Stocbeci		Inspected by COSTEA Costea		Standardisation MUNTEANV Muntean	
Department HCS - RO		Date 2018-12-17		State Final Release		Doc-Key / ECM-Nr. 100577961/UGD/009/C 500000144934	
HARTING Customised Solutions		Title M8 Cable Assembly 4-poles st/- m/-		Rev. C		Page 1/1	
D-32339 Espelkamp		Type TB		Number 21348000481XXX			

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

HARTING:

[21348000481005](#) [21348000481020](#) [21348000481100](#) [21348000481015](#) [21348000481075](#) [21348000481050](#)
[21348000481010](#) [21348000481040](#) [21348000481060](#)