

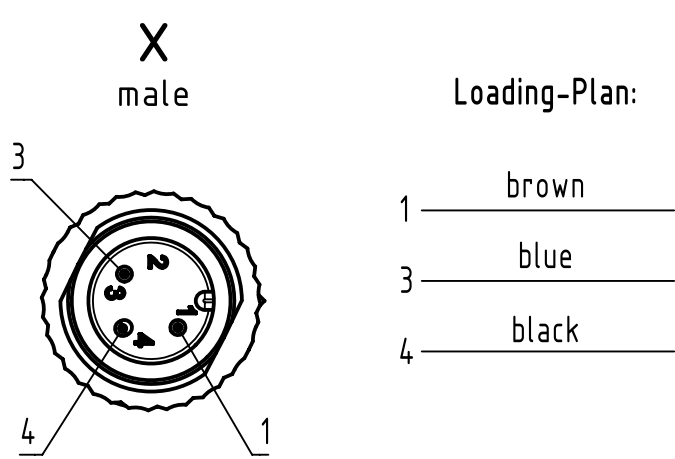


Connector Location A

Connector Location B

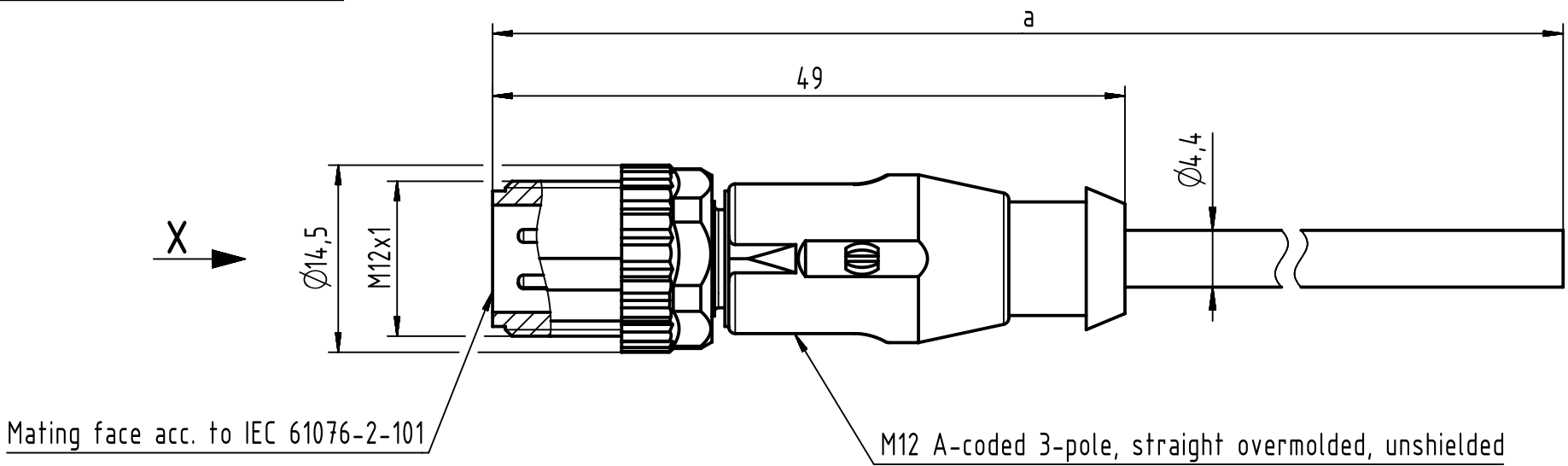

- Protection level: IP67
- Temperature range: -25°C ... +80°C

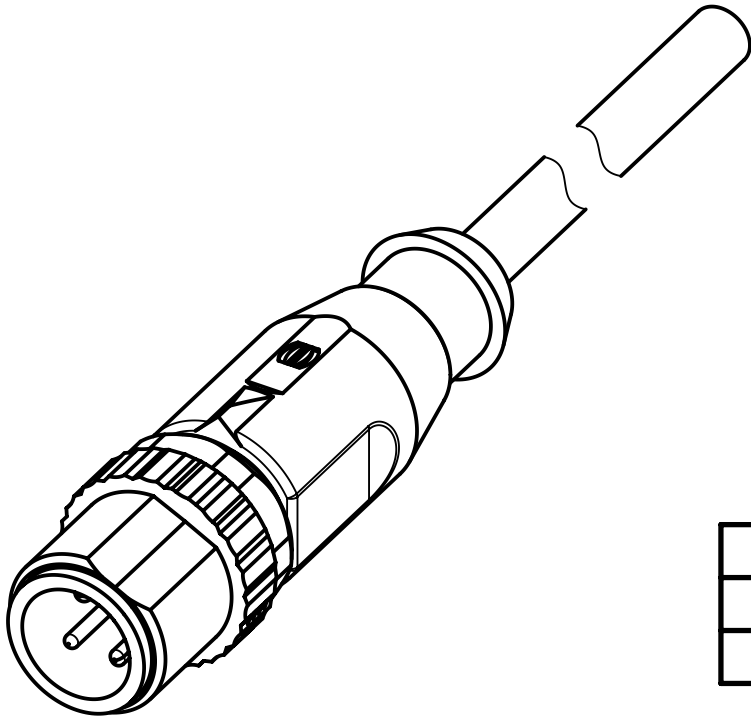

4.0 to 40	±1%
0.1 to 3.9	+0.04
a [m]	Tolerance

length in "1m" step	40	XXX=40
	39	XXX=39
	.	.
	12	XXX=120
	11	XXX=110
length in "0.1m" step	10	XXX=100
	9.9	XXX=099
	9.8	XXX=098
	.	.
	0.4	XXX=004
	0.3	XXX=003
	0.2	XXX=002
Step	0.1	XXX=001
	a [m]	XXX

PVC grey, 3x0.34mm ²	21348400383XXX
Type of cable	Part no.

All Dimensions in mm		Tech. Character.		Free size tol.		According to production drawing	
All rights reserved		Created by COSTEA Costea		Inspected by STOCHECIC Stocheci		Standardisation MUNTEANV Muntean	
Department HCS - RO		Date 2018-12-17		State Final Release		Doc-Key / ECM-Nr. 100578777/UGD/009/C 500000144899	
HARTING Customised Solutions		Title M12 Cable Assembly A-cod st/- m/-		Rev. C		Page 1/1	
D-32339 Espelkamp		Type TB		Number 21348400383XXX			

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

HARTING:

[21348400383075](#) [21348400383100](#) [21348400383005](#) [21348400383015](#) [21348400383020](#) [21348400383010](#)
[21348400383050](#)