



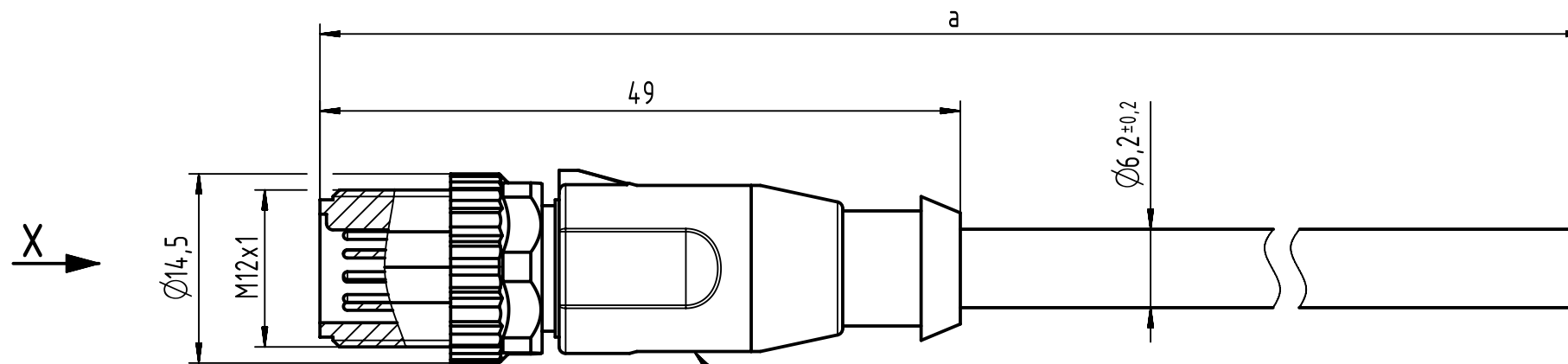


M12 A-coded 12-poles, male straight connector

Loading-Plan:

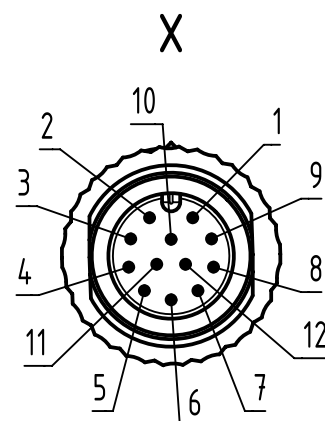

- | | |
|----|-----------|
| 1 | brown |
| 2 | blue |
| 3 | white |
| 4 | green |
| 5 | pink |
| 6 | yellow |
| 7 | black |
| 8 | grey |
| 9 | red |
| 10 | violet |
| 11 | grey-pink |
| 12 | red-blue |

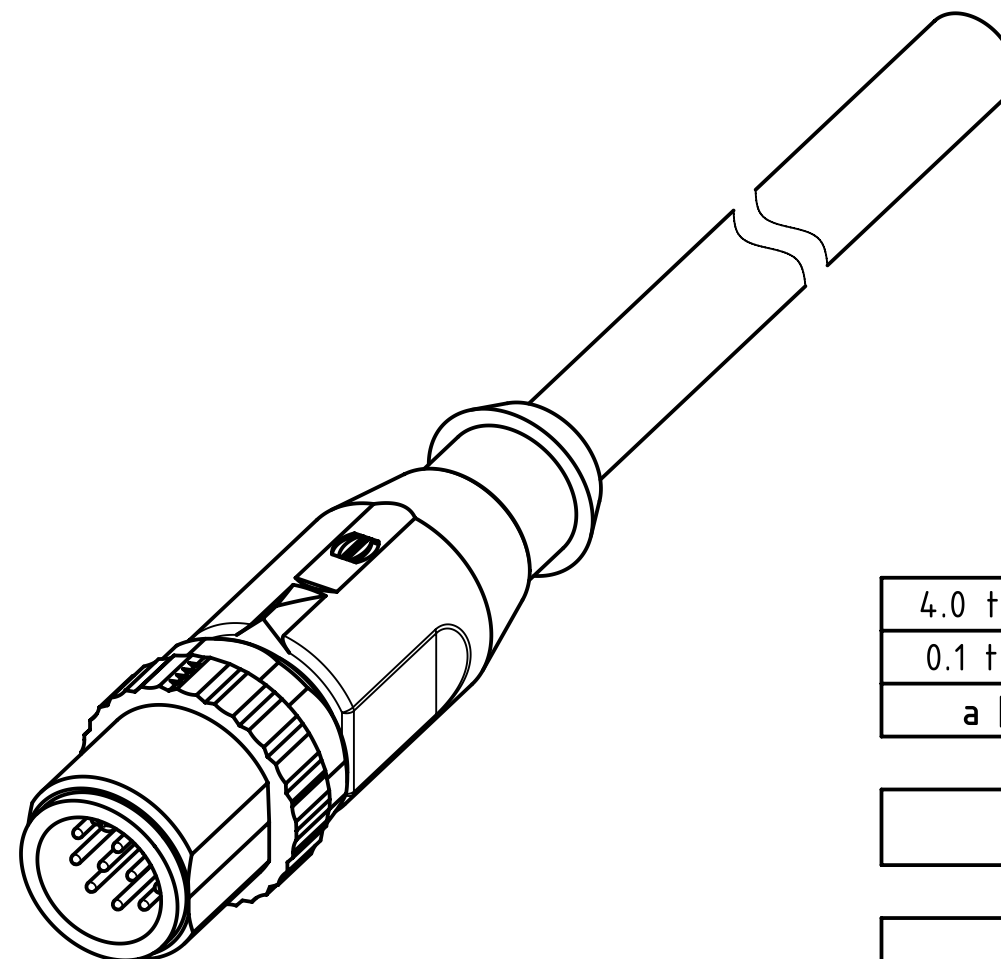

length in "1m" step	100	XXX=000
	99	XXX=990
	.	.
	12	XXX=120
length in "0.1m" step	11	XXX=110
	10	XXX=100
	9.9	XXX=099
	9.8	XXX=098
	.	.
	0.4	XXX=004
	0.3	XXX=003
	0.2	XXX=002
	0.1	XXX=001

4.0 to 100	+1%
0.1 to 3.9	+0.04
a [m]	Tolerance

Part no.	21348400CXXXXX
----------	----------------

Type of cable	XX
PVC grey, 12x0.14mm ²	XX=79

- Protection level: IP67
- Temperature range: -30°C ... +80°C

		All Dimensions in mm Original Size DIN A3		Scale 2:1		Free size tol.		Ref.					
								Sub.					
		All rights reserved		Created by MUNTEANV		Inspected by AVRAM		Standardisation HOFFMANN		Date 2016-03-22		State Final Release	
HARTING Electronics GmbH D-32339 Espelkamp		Department EC PD - RO		Title M12 A-coded Cable Assembly								Doc-Key / ECM-Nr. 100583095/UGD/009/B 500000102141	
				Type TB		Number 21348400CXXXXX						Rev. B	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HARTING:](#)

[21348400C79010](#) [21348400C79050](#) [21348400C79020](#) [21348400C79015](#) [21348400C79005](#) [21348400C79075](#)
[21348400C79100](#) [21348400C79250](#)