


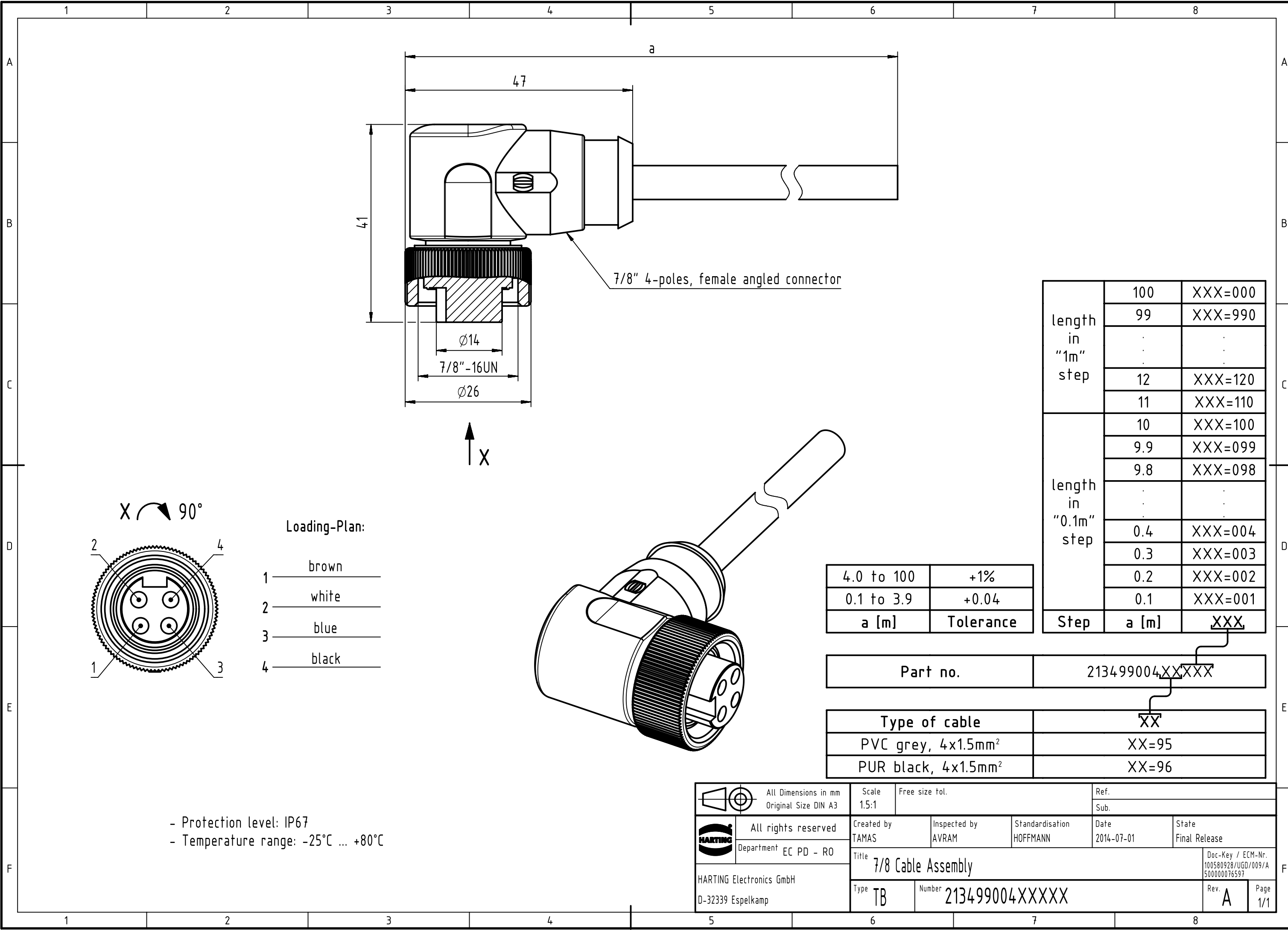

- Protection level: IP67
- Temperature range: -25°C ... +80°C

length in "1m" step	100	XXX=000
	99	XXX=990
	.	.
	.	.
	12	XXX=120
length in "0.1m" step	11	XXX=110
	10	XXX=100
	9.9	XXX=099
	9.8	XXX=098
	.	.
	.	.
	0.4	XXX=004
	0.3	XXX=003
	0.2	XXX=002
	0.1	XXX=001
Step	a [m]	XXX

4.0 to 100	+1%
0.1 to 3.9	+0.04
a [m]	Tolerance

Part no.	213499004XXXXX
----------	----------------

Type of cable	XX
PVC grey, 4x1.5mm ²	XX=95
PUR black, 4x1.5mm ²	XX=96

	All Dimensions in mm Original Size DIN A3		Scale 1.5:1	Free size tol.		Ref.	
						Sub.	
	All rights reserved		Created by TAMAS	Inspected by AVRAM	Standardisation HOFFMANN	Date 2014-07-01	State Final Release
	Department EC PD - RO		Title 7/8 Cable Assembly				Doc-Key / ECM-Nr. 100580928/UGD/009/A 500000076597
	HARTING Electronics GmbH D-32339 Espelkamp		Type TB	Number 213499004XXXXX			Rev. A Page 1/1

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HARTING:](#)

[21349900495030](#) [21349900496100](#) [21349900495050](#) [21349900496030](#) [21349900495015](#) [21349900496050](#)
[21349900495075](#) [21349900496015](#) [21349900496075](#) [21349900495100](#) [21349900495010](#)