


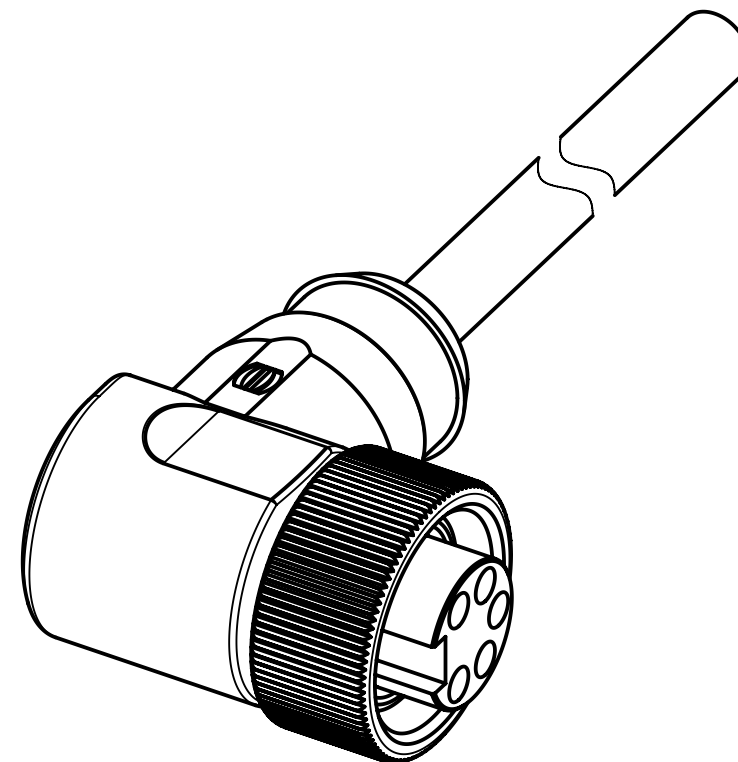

- | | |
|----|--------------|
| 1 | black |
| 2 | blue |
| PE | green-yellow |
| 4 | brown |
| 5 | white |



length in "1m" step	100	XXX=000
	99	XXX=990
	.	.
	.	.
	12	XXX=120
	11	XXX=110
length in "0.1m" step	10	XXX=100
	9.9	XXX=099
	9.8	XXX=098
	.	.
	.	.
	0.4	XXX=004
	0.3	XXX=003
	0.2	XXX=002
	0.1	XXX=001
Step	a [m]	<u>XXX</u>

Type of cable	XX
PVC grey, 5x1.5mm ²	XX=97
PUR black, 5x1.5mm ²	XX=98

- Protection level: IP 65/67
- Temperature range: -25°C ... +80°C

		All Dimensions in mm		Tech. Character.		Free size tol.		According to production drawing 2016-09-07							
		All rights reserved		Created by MUNTEANV		Inspected by POPESCUD		Standardisation AVRAM		Date 2016-10-18		State Final Release			
Department HCS - RO		Title 7/8" Cable Assembly										Doc-Key / ECM-Nr. 100580963/UGD/009/B 500000110271			
HARTING Customised Solutions															
D-32427 Minden		Type TB		Number 213499005XXXXX								Rev. B		Page 1/1	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

HARTING:

[21349900597050](#) [21349900597075](#) [21349900597015](#) [21349900598030](#) [21349900598075](#) [21349900598050](#)
[21349900598100](#) [21349900597030](#) [21349900597100](#) [21349900598015](#)