



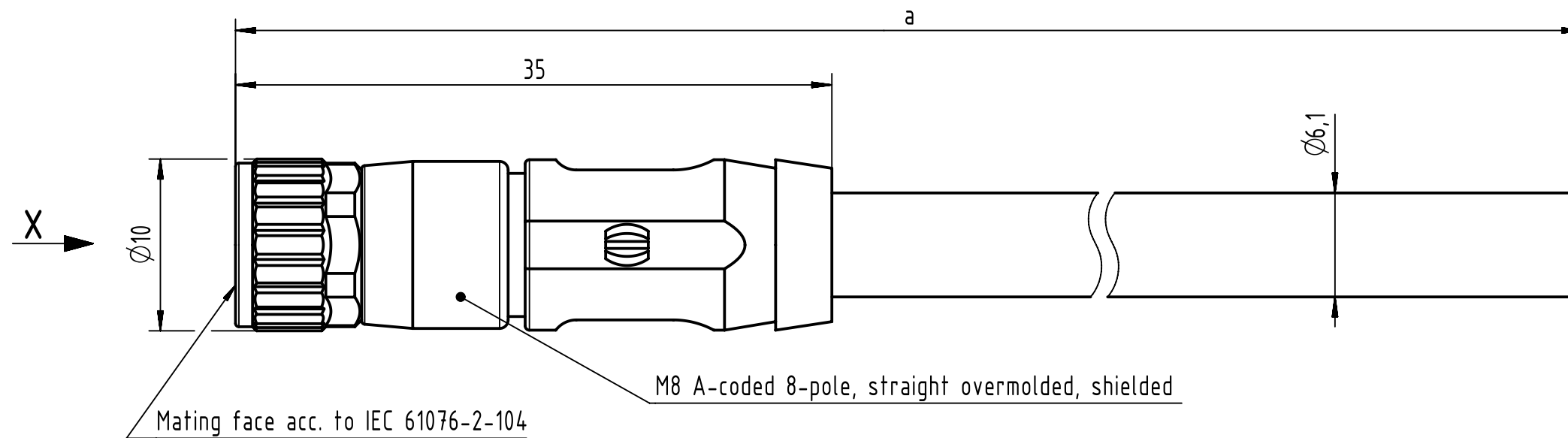

Shield

|   |        |
|---|--------|
| 1 | white  |
| 2 | brown  |
| 3 | green  |
| 4 | yellow |
| 5 | grey   |
| 6 | pink   |
| 7 | blue   |
| 8 | red    |

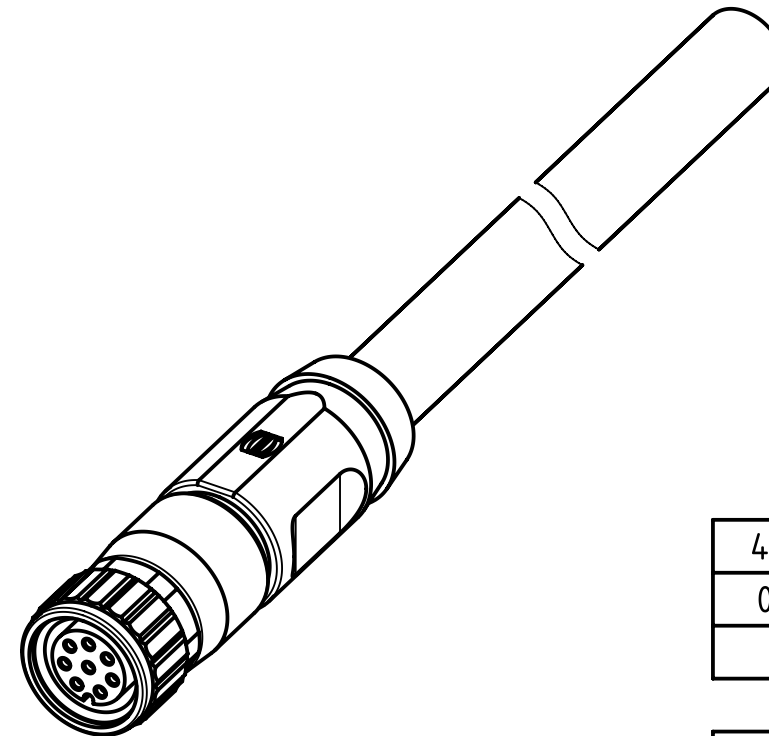

|              |                  |
|--------------|------------------|
| 4.0 to 100   | ±1%              |
| 0.1 to 3.9   | +0.04            |
| <b>a [m]</b> | <b>Tolerance</b> |

|                                |         |            |
|--------------------------------|---------|------------|
| length<br>in<br>"1m"<br>step   | 100     | XXX=000    |
|                                | 99      | XXX=990    |
|                                | .       | .          |
|                                | .       | .          |
|                                | 12      | XXX=120    |
| length<br>in<br>"0.1m"<br>step | 11      | XXX=110    |
|                                | 10      | XXX=100    |
|                                | 9.9     | XXX=099    |
|                                | 9.8     | XXX=098    |
|                                | .       | .          |
|                                | .       | .          |
|                                | 0.4     | XXX=004    |
|                                | 0.3     | XXX=003    |
|                                | 0.2     | XXX=002    |
| 0.1                            | XXX=001 |            |
| Step                           | a [m]   | <u>XXX</u> |

|                                  |                 |
|----------------------------------|-----------------|
| Part no.                         | 2134B2008XXXXXX |
| Type of cable                    | XX              |
| PVC grey, 8x0.14mm <sup>2</sup>  | XX=21           |
| TPU black, 8x0.14mm <sup>2</sup> | XX=22           |

- Protection level: IP67
- Temperature range: -30°C ... +80°C

|                                                                                       |  |                                            |  |                                      |  |                                  |  |                                                          |  |
|---------------------------------------------------------------------------------------|--|--------------------------------------------|--|--------------------------------------|--|----------------------------------|--|----------------------------------------------------------|--|
|  |  | All Dimensions<br>in mm                    |  | Tech. Character.                     |  | Free size tol.                   |  | According to production drawing                          |  |
|  |  | All rights reserved                        |  | Created by<br>STOCHECIC<br>Stochechi |  | Inspected by<br>COSTEA<br>Costea |  | Standardisation<br>MUNTEANV<br>Muntean                   |  |
| Department HCS - RO                                                                   |  |                                            |  |                                      |  | Date<br>2018-12-12               |  | State<br>Final Release                                   |  |
| HARTING Customised Solutions<br>D-32339 Espelkamp                                     |  | Title<br>M8 Shielded Assy 8-poles st/- f/- |  |                                      |  |                                  |  | Doc-Key / ECM-Nr.<br>100686394/UGD/000/B<br>500000144261 |  |
|                                                                                       |  | Type<br>TB                                 |  | Number<br>2134B2008XXXXX             |  |                                  |  | Rev. B                                                   |  |
|                                                                                       |  |                                            |  |                                      |  |                                  |  | Page<br>1/1                                              |  |

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HARTING:](#)

[2134B200821020](#) [2134B200821005](#) [2134B200821010](#) [2134B200821050](#) [2134B200821015](#) [2134B200821075](#)  
[2134B200821100](#)