
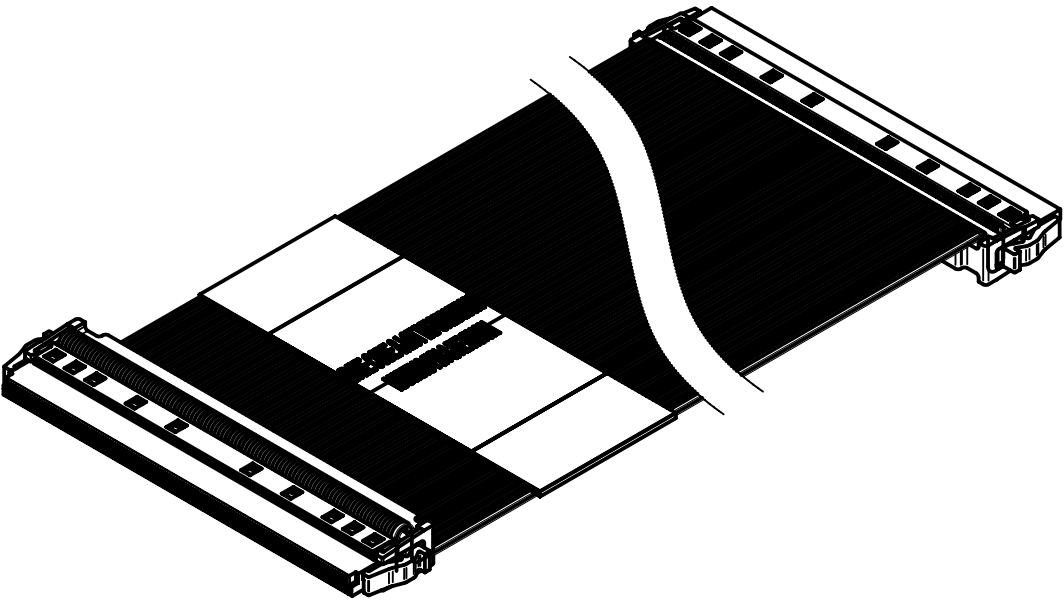


 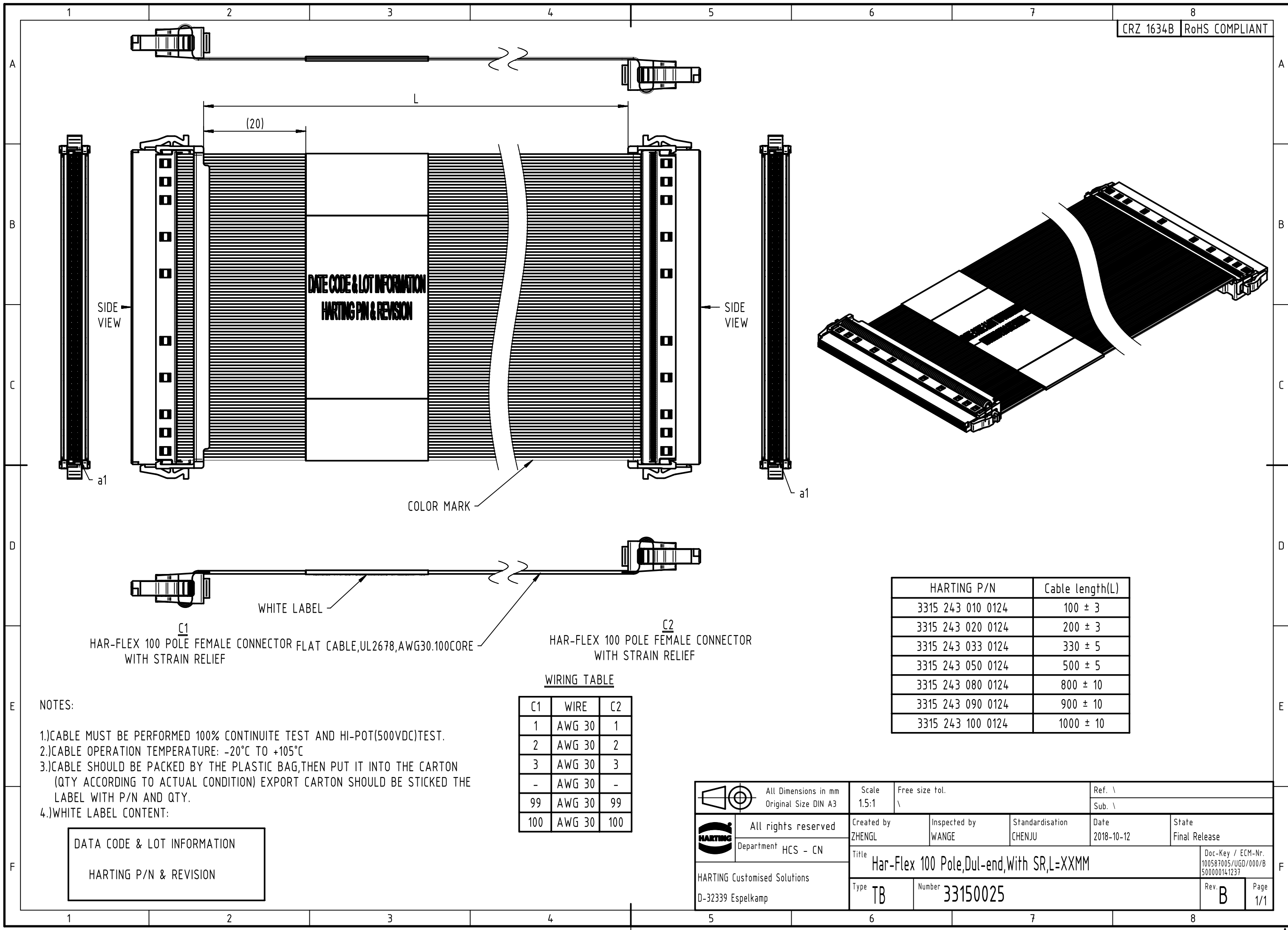


HARTING P/N	Cable length(L)
3315 243 010 0124	100 ± 3
3315 243 020 0124	200 ± 3
3315 243 033 0124	330 ± 5
3315 243 050 0124	500 ± 5
3315 243 080 0124	800 ± 10
3315 243 090 0124	900 ± 10
3315 243 100 0124	1000 ± 10

WIRING TABLE		
C1	WIRE	C2
1	AWG 30	1
2	AWG 30	2
3	AWG 30	3
-	AWG 30	-
99	AWG 30	99
100	AWG 30	100

- NOTES:
- 1.)CABLE MUST BE PERFORMED 100% CONTINUITE TEST AND HI-POT(500VDC)TEST.
 - 2.)CABLE OPERATION TEMPERATURE: -20°C TO +105°C
 - 3.)CABLE SHOULD BE PACKED BY THE PLASTIC BAG,THEN PUT IT INTO THE CARTON (QTY ACCORDING TO ACTUAL CONDITION) EXPORT CARTON SHOULD BE STICKED THE LABEL WITH P/N AND QTY.
 - 4.)WHITE LABEL CONTENT:

DATA CODE & LOT INFORMATION
HARTING P/N & REVISION

		All Dimensions in mm Original Size DIN A3		Scale 1.5:1		Free size tol. \\		Ref. \		
								Sub. \		
		All rights reserved		Created by ZHENGL		Inspected by WANGE		Standardisation CHENJU		
		Department HCS - CN						Date 2018-10-12		
								State Final Release		
HARTING Customised Solutions D-32339 Espelkamp		Title Har-Flex 100 Pole,Dul-end,With SR,L=XXMM							Doc-Key / ECM-Nr. 100587005/UGD/000/B 500000141237	
		Type TB		Number 33150025					Rev. B	
									Page 1/1	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

HARTING:

[33152430200124](#) [33152430500124](#) [33152430100124](#)