
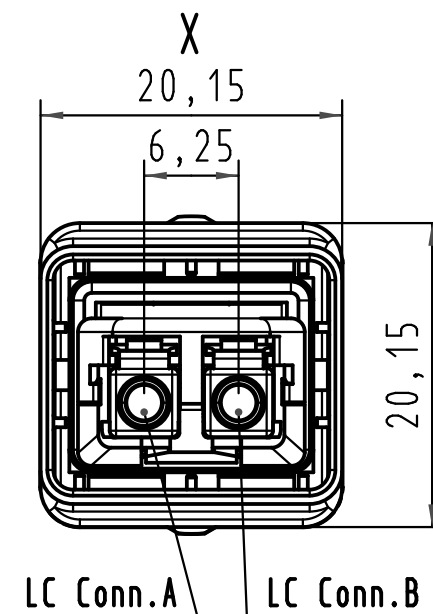
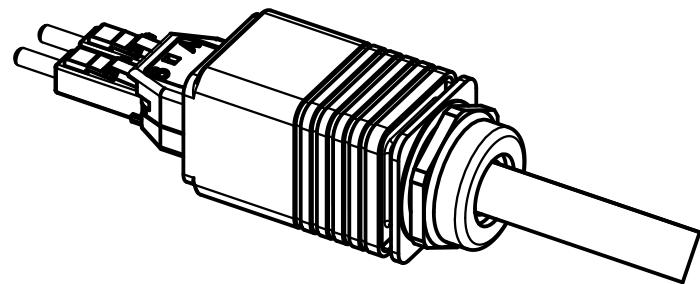


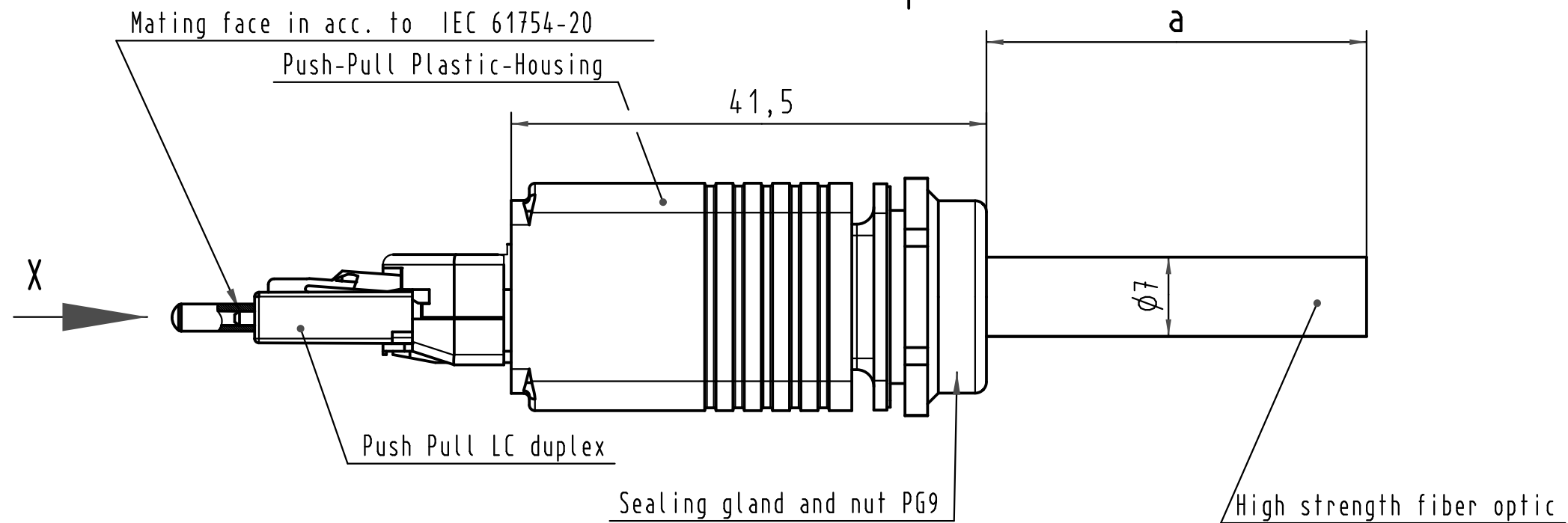

Loading-Plan

A	blue
B	orange

-Protection level: IP67/65
-Temperature range: -40°C ...+70°C

9	High strength fiber optic breakout cable multimode	33 58 111 300 0001	300 m
8	High strength fiber optic breakout cable multimode	33 58 111 100 0001	100 m
7	High strength fiber optic breakout cable multimode	33 58 111 060 0001	60 m
6	High strength fiber optic breakout cable multimode	33 58 111 050 0001	50 m
5	High strength fiber optic breakout cable multimode	33 58 111 040 0001	40 m
4	High strength fiber optic breakout cable multimode	33 58 111 020 0001	20 m
3	High strength fiber optic breakout cable multimode	33 58 111 010 0001	10 m
2	High strength fiber optic breakout cable multimode	33 58 111 005 0001	5 m
1	High strength fiber optic breakout cable multimode	33 58 111 001 0001	1 m

Cont No.	Type of cable	Part-No.	Dim. a
----------	---------------	----------	--------

			All Dimensions in mm Original Size DIN A 3			Techn. Character.			Nicht tolerierte Maß/Free size tolerances			
				Dat.	Name	Maßstab/Scale 2:1	Push Pull fiber optic assembly 1xPush Pull LC DUPLEX, plastic multimode, 62.5 µm					
			Detail.	05.08.08	MS							
			Insp.									
EC00166	17.02.09	MR	Stand.									
35025	10.11.08	MS	HARTING Electronics GmbH & Co. KG				TB 33 58 111 xxx 0001			Blatt/ page /		
35008			D-32339 ESPELKAMP									
Mod.	Dat.	Name										
							Sub.			Sub		

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

HARTING:

[33581110010001](#) [33581110050001](#) [33581110100001](#) [33581110200001](#) [33581110400001](#) [33581110500001](#)
[33581111000001](#)