




Hexagonal head screw driver
for cylinder head cap screw
Part number: 6103 600 0021
Max. torque = 0,4Nm

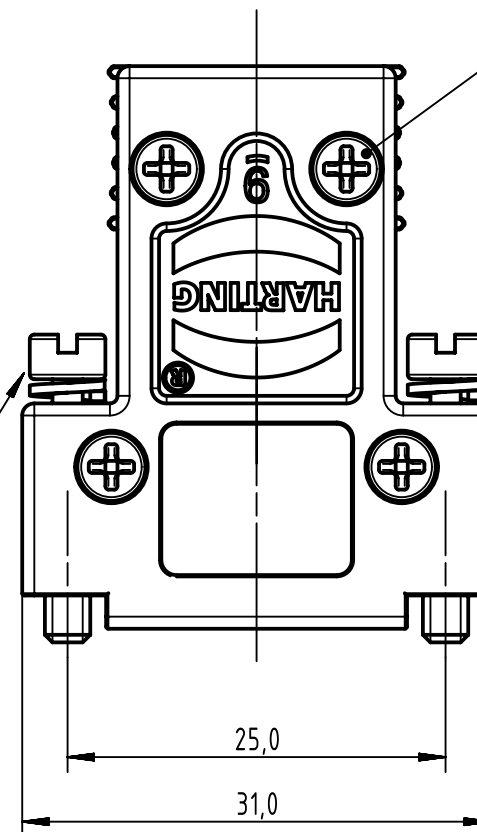

Cover screws(x4)
M2,5x8,0
Type Z phillips
Screwdriver head #1
Max. torque = 0,3Nm

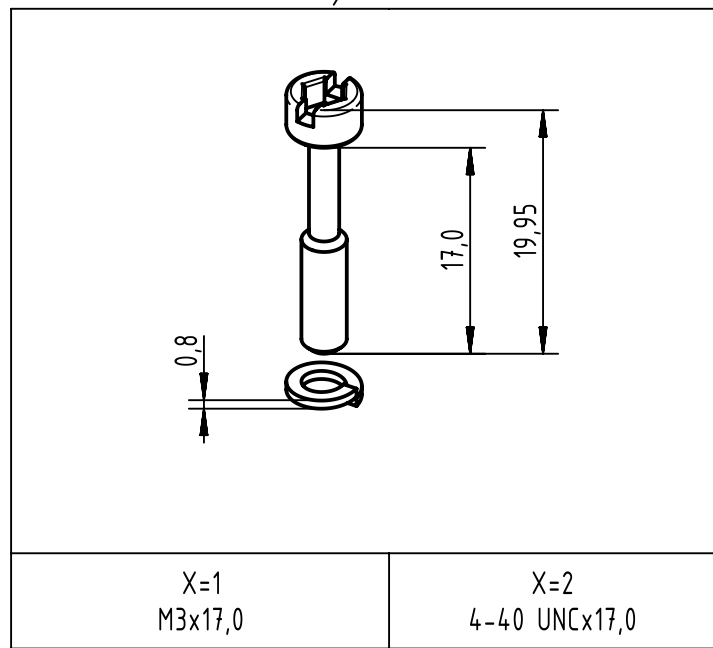

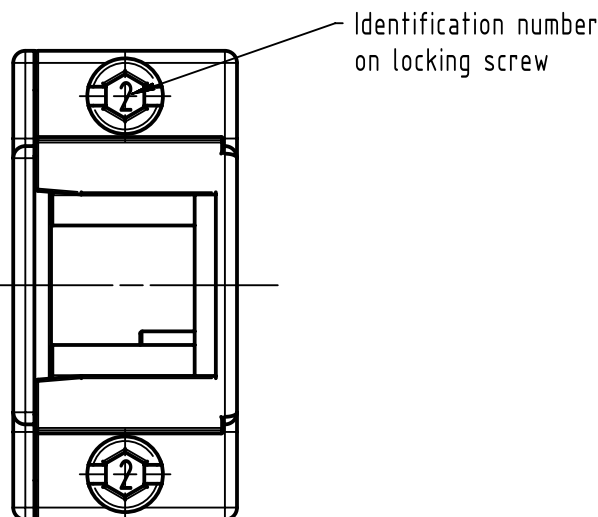

X=1
M3x17,0

X=2
4-40 UNCx17,0

Note: Full metal hood made with Zinc diecast

6103 001 X010 123		
6103 001 2010 123	4-40UNC x 17,0	2
6103 001 1010 123	M3 x 17,0	without number
Part number	Screw size	Identification number

		All Dimensions in mm Original Size DIN A3		Scale 2:1		Free size tol.		Ref.	
								Sub.	
		All rights reserved		Created by LUOK		Inspected by WANGSTE		Standardisation HOFFMANN	
		Department EC PD - CN				Date 2014-03-11		State Final Release	
HARTING Electronics GmbH D-32339 Espelkamp		Title InduCom 9-pole straight full metal hood for coding							Doc-Key / ECM-Nr. 100233374/UGD/000/C 500000072589
		Type TB		Number 6103001X010123					Rev. C

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

HARTING:

[61030012010123](#) [61030011010123](#)