

Han TC650 female contact 150mm²

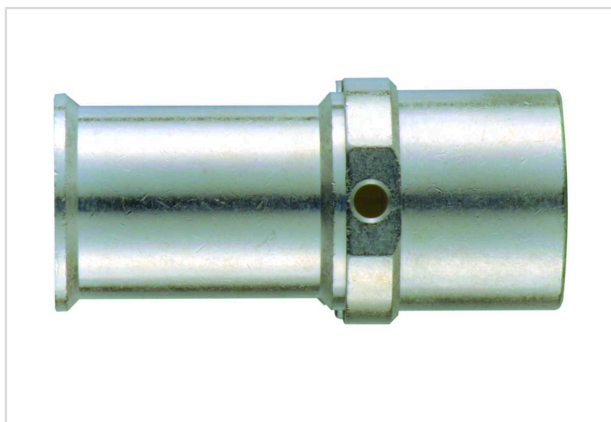


Image is for illustration purposes only. Please refer to product description.

Part number	09 11 000 6264
Specification	Han TC650 female contact 150mm ²
HARTING eCatalogue	https://b2b.harting.com/09110006264

Identification

Category	Contacts
Series	TC 650
Type of contact	Crimp contact

Version

Gender	Female
Manufacturing process	Turned contacts

Technical characteristics

Conductor cross-section	150 mm ²
Operating current	≤650 A
Contact resistance	≤0.3 mΩ
Limiting temperature	-40 ... +125 °C
Stripping length	42 mm
Mating cycles	≥500

Material properties

Material (contacts)	Copper alloy
Surface (contacts)	Silver plated
RoHS	compliant
ELV status	compliant with exemption
China RoHS	50
REACH Annex XVII substances	No



Pushing Performance

Material properties

REACH ANNEX XIV substances	No
REACH SVHC substances	No

Specifications and approvals

Specifications	EN 60664-1 IEC 61984
----------------	-------------------------

Commercial data

Packaging size	1
Net weight	133.2 g
Country of origin	Romania
European customs tariff number	85359000
eCl@ss	27440204 Contact for industrial connectors

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

HARTING:

09110006264