

HPP V4 USB 2.0 type A to type B

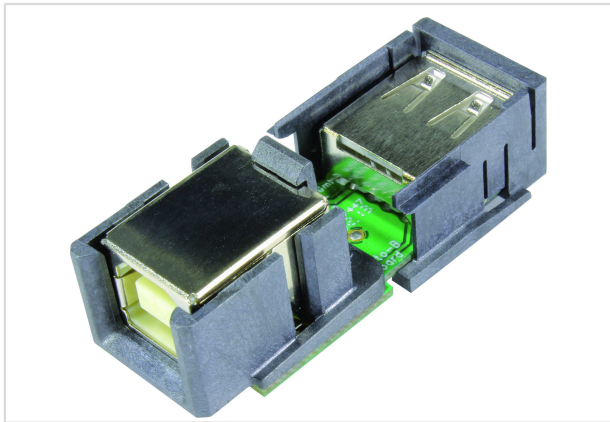


Image is for illustration purposes only. Please refer to product description.

Part number	09 45 541 1910
Specification	HPP V4 USB 2.0 type A to type B
HARTING eCatalogue	https://b2b.harting.com/09455411910

Identification

Category	Connectors
Series	HARTING PushPull (V4)
Identification	USB
Element	Adapter PCB
Specification	USB 2.0 type A to USB 2.0 type B USB 2.0 type B to USB 2.0 type A
Adapter for	Jack to jack

Version

Shielding	Fully shielded, 360° shielding contact
Number of contacts	4

Technical characteristics

Limiting temperature	-40 ... +70 °C
Mating cycles	≥750

Material properties

RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	No
REACH ANNEX XIV substances	No

Material properties

REACH SVHC substances	No
-----------------------	----


Specifications and approvals

Specifications	IEC 61076-3-106 Variant 4 (V4)
Approvals	DNV GL


Commercial data

Packaging size	1
Net weight	7.68 g
Country of origin	Germany
European customs tariff number	85366990
eCl@ss	27440205 Contact insert for industrial connectors

Mounting instruction

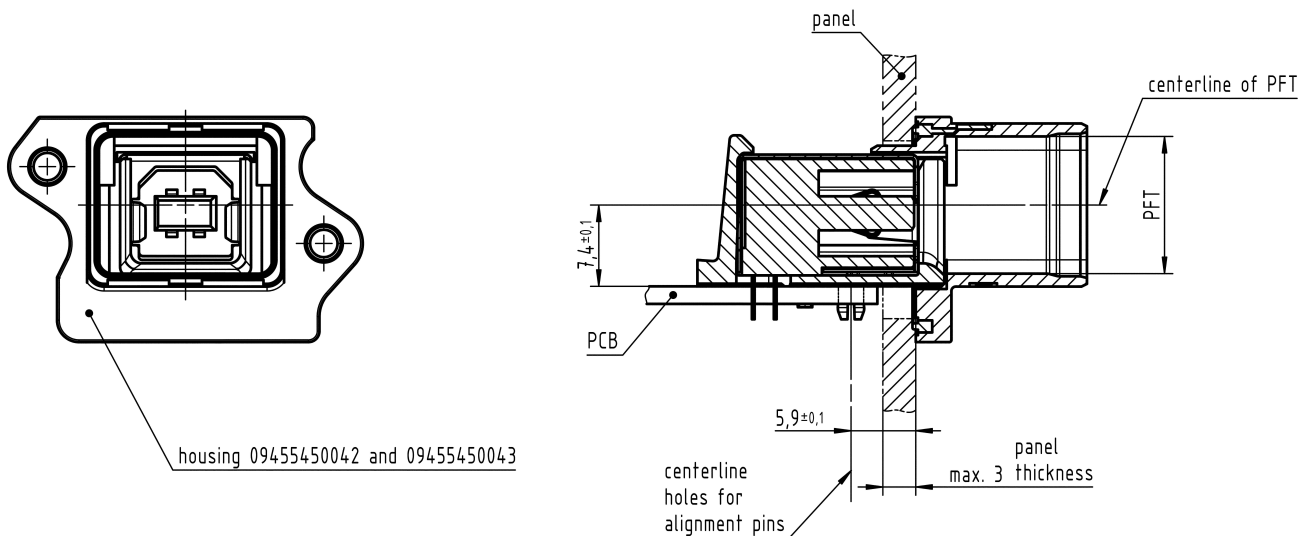

Mounting instruction

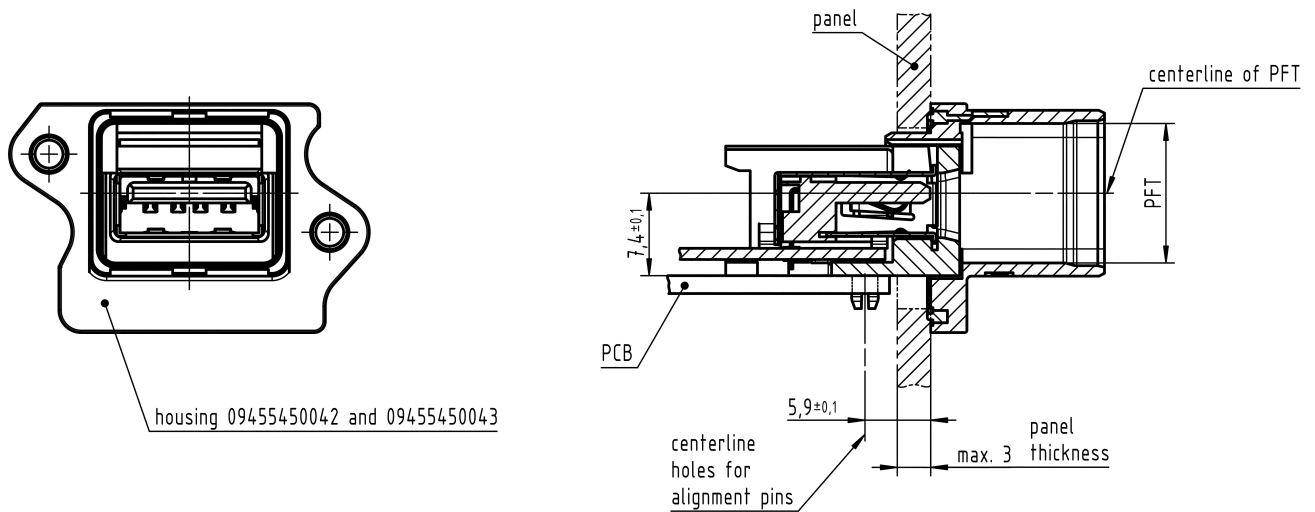

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

HARTING:

09455411910