

Han High Temp 10B Base Panel 2 levers

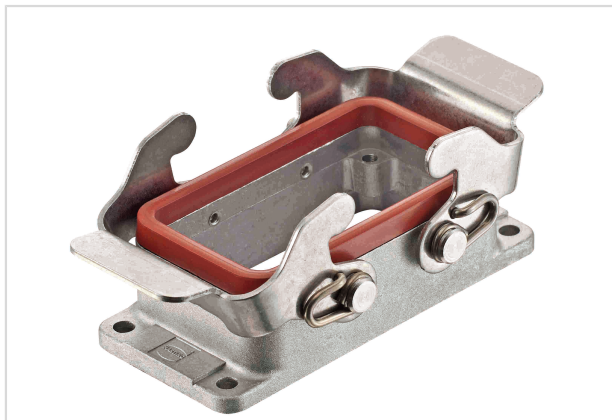


Image is for illustration purposes only. Please refer to product description.

Part number	09 62 810 0391
Specification	Han High Temp 10B Base Panel 2 levers
HARTING eCatalogue	https://b2b.harting.com/09628100391

Identification

Category	Hoods/Housings
Series of hoods/housings	Han® High Temp
Type of hood/housing	Bulkhead mounted housing
Type	Low construction

Version

Locking type	Double locking lever
Size	10 B

Technical characteristics

Limiting temperature	-40 ... +200 °C With Han® High Temp components
Degree of protection acc. to IEC 60529	IP65

Material properties

Material (hood/housing)	Aluminium die-cast
Surface (hood/housing)	Uncoated
Colour (hood/housing)	Unpainted
Material (seal)	FPM
Colour (seal)	Red
Material (locking)	Stainless steel
RoHS	compliant
ELV status	compliant
China RoHS	e



Pushing Performance

Material properties

REACH Annex XVII substances	No
REACH ANNEX XIV substances	No
REACH SVHC substances	No

Commercial data

Packaging size	1
Net weight	145.7 g
Country of origin	Germany
European customs tariff number	85389099
eCl@ss	27440202 Shell for industrial connectors

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

HARTING:

09628100391