


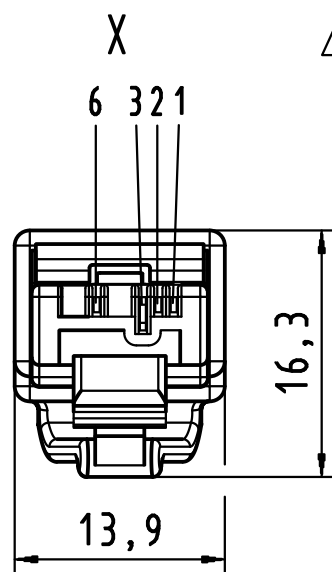


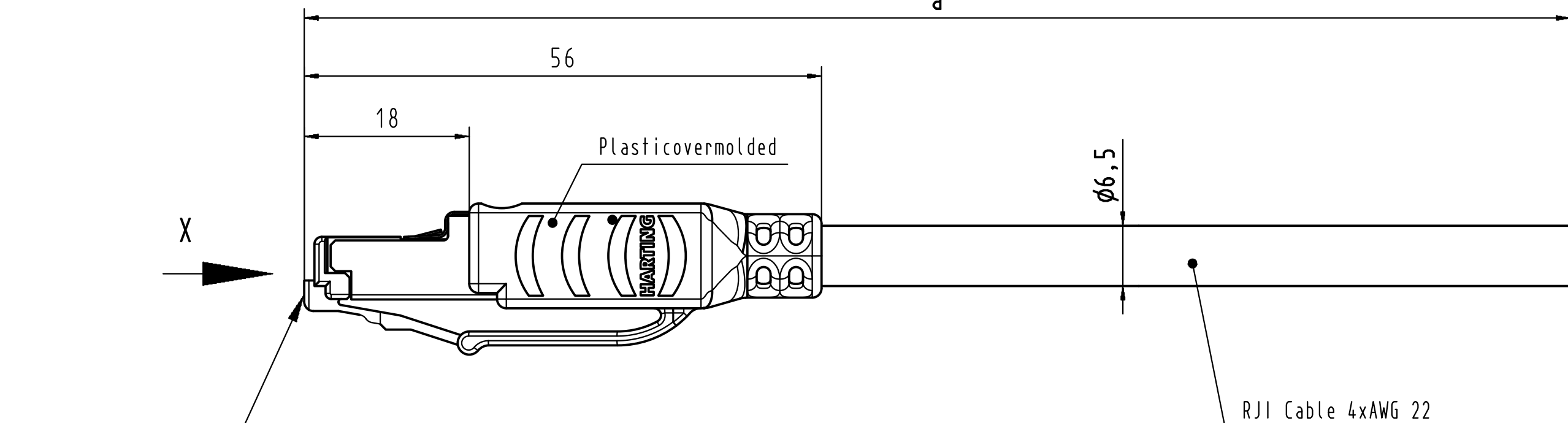

Loading-Plan:

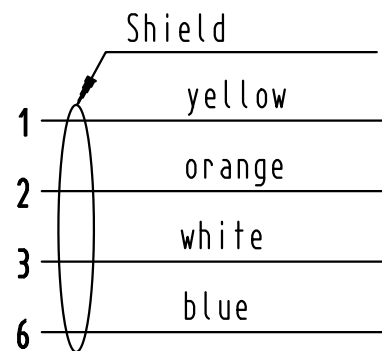

- Transmission properties in accordance with ISO/IEC 11801:2002: Class D.
- Protection level: IP20
- Temperature range: -40°C ...+70°C

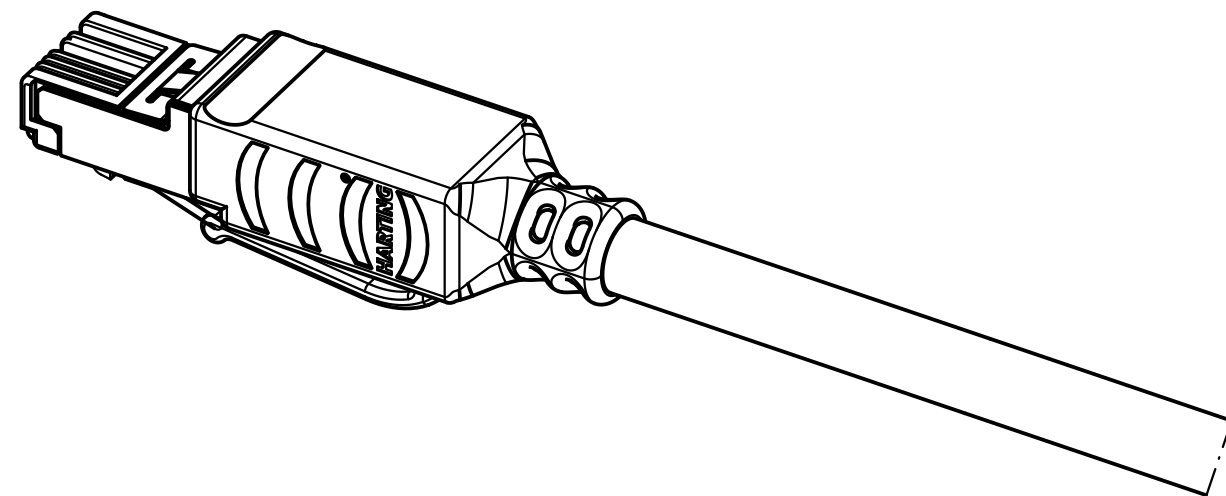

For Information Only
won't be replaced when changed

 All Dimensions in mm Original Size DIN A 4			Techn. Character.			Nicht tolerierte Maß/Free size tolerances			
				Dat.	Name	Maßstab/Scale 2:1	RJ45 cord, IP20 overmolded, 4xAWG , 1x RJ45 plug, CAT 5		
			Detail.	11.02.08	MS				
			Insp.						
			Stand.						
			HARTING Electronics GmbH & Co. KG				TB 09 45 771 0xxx		Blatt/ page 1/2
34530			D-32339 ESPELKAMP				Sub.		
Mod.	Dat.	Name							

	1	2	3	4		5	6	7	8	
	Cont. no.	Part number	Type of cable	Dim. a		Cont. no.	Part number	Type of cable	Dim. a	
A	1	09 45 771 0062	4AWG 22/1 solid	0,5 m		52	09 45 771 0169	4AWG 22/7 trailing	6 m	A
	2	09 45 771 0063	4AWG 22/1 solid	1 m		53	09 45 771 0170	4AWG 22/7 trailing	7 m	
	3	09 45 771 0064	4AWG 22/1 solid	1,5 m		54	09 45 771 0171	4AWG 22/7 trailing	8 m	
	4	09 45 771 0065	4AWG 22/1 solid	2 m		55	09 45 771 0172	4AWG 22/7 trailing	9 m	
	5	09 45 771 0066	4AWG 22/1 solid	3 m		56	09 45 771 0173	4AWG 22/7 trailing	10 m	
B	6	09 45 771 0067	4AWG 22/1 solid	4 m		57	09 45 771 0174	4AWG 22/7 trailing	15 m	B
	7	09 45 771 0068	4AWG 22/1 solid	5 m		58	09 45 771 0175	4AWG 22/7 trailing	20 m	
	8	09 45 771 0069	4AWG 22/1 solid	6 m		59	09 45 771 0176	4AWG 22/7 trailing	30 m	
	9	09 45 771 0070	4AWG 22/1 solid	7 m		60	09 45 771 0177	4AWG 22/7 trailing	40 m	
	10	09 45 771 0071	4AWG 22/1 solid	8 m		61	09 45 771 0178	4AWG 22/7 trailing	50 m	
C	11	09 45 771 0072	4AWG 22/1 solid	9 m		62	09 45 771 0179	4AWG 22/7 trailing	60 m	C
	12	09 45 771 0073	4AWG 22/1 solid	10 m		63	09 45 771 0180	4AWG 22/7 trailing	70 m	
	13	09 45 771 0074	4AWG 22/1 solid	15 m		64	09 45 771 0181	4AWG 22/7 trailing	80 m	
	14	09 45 771 0075	4AWG 22/1 solid	20 m		65	09 45 771 0182	4AWG 22/7 trailing	90 m	
	15	09 45 771 0076	4AWG 22/1 solid	30 m		66	09 45 771 0183	4AWG 22/7 trailing	100 m	
D	16	09 45 771 0077	4AWG 22/1 solid	40 m		67	09 45 771 0100	4AWG 22/7 "outdoor"	0,5 m	D
	17	09 45 771 0078	4AWG 22/1 solid	50 m		68	09 45 771 0101	4AWG 22/7 "outdoor"	1 m	
	18	09 45 771 0079	4AWG 22/1 solid	60 m		69	09 45 771 0102	4AWG 22/7 "outdoor"	1,5 m	
	19	09 45 771 0080	4AWG 22/1 solid	70 m		70	09 45 771 0103	4AWG 22/7 "outdoor"	2 m	
	20	09 45 771 0081	4AWG 22/1 solid	80 m		71	09 45 771 0104	4AWG 22/7 "outdoor"	3 m	
E	21	09 45 771 0082	4AWG 22/1 solid	90 m		72	09 45 771 0105	4AWG 22/7 "outdoor"	4 m	E
	22	09 45 771 0083	4AWG 22/1 solid	100 m		73	09 45 771 0106	4AWG 22/7 "outdoor"	5 m	
	23	09 45 771 0121	4AWG 22/7 stranded	0,5 m		74	09 45 771 0107	4AWG 22/7 "outdoor"	6 m	
	24	09 45 771 0122	4AWG 22/7 stranded	1 m		75	09 45 771 0108	4AWG 22/7 "outdoor"	7 m	
	25	09 45 771 0123	4AWG 22/7 stranded	1,5 m		76	09 45 771 0109	4AWG 22/7 "outdoor"	8 m	
F	26	09 45 771 0124	4AWG 22/7 stranded	2 m		77	09 45 771 0110	4AWG 22/7 "outdoor"	9 m	F
	27	09 45 771 0125	4AWG 22/7 stranded	3 m		78	09 45 771 0111	4AWG 22/7 "outdoor"	10 m	
	28	09 45 771 0126	4AWG 22/7 stranded	4 m		79	09 45 771 0112	4AWG 22/7 "outdoor"	15 m	
	29	09 45 771 0127	4AWG 22/7 stranded	5 m		80	09 45 771 0113	4AWG 22/7 "outdoor"	20 m	
	30	09 45 771 0128	4AWG 22/7 stranded	6 m		81	09 45 771 0114	4AWG 22/7 "outdoor"	30 m	
	31	09 45 771 0129	4AWG 22/7 stranded	7 m		82	09 45 771 0115	4AWG 22/7 "outdoor"	40 m	
	32	09 45 771 0130	4AWG 22/7 stranded	8 m		83	09 45 771 0116	4AWG 22/7 "outdoor"	50 m	
	33	09 45 771 0131	4AWG 22/7 stranded	9 m		84	09 45 771 0117	4AWG 22/7 "outdoor"	60 m	
	34	09 45 771 0151	4AWG 22/7 stranded	10 m		85	09 45 771 0118	4AWG 22/7 "outdoor"	70 m	
	35	09 45 771 0152	4AWG 22/7 stranded	15 m		86	09 45 771 0119	4AWG 22/7 "outdoor"	80 m	
	36	09 45 771 0153	4AWG 22/7 stranded	20 m		87	09 45 771 0120	4AWG 22/7 "outdoor"	90 m	
	37	09 45 771 0154	4AWG 22/7 stranded	30 m		88	09 45 771 0132	4AWG 22/7 "outdoor"	100 m	
	38	09 45 771 0155	4AWG 22/7 stranded	40 m						
	39	09 45 771 0156	4AWG 22/7 stranded	50 m						
	40	09 45 771 0157	4AWG 22/7 stranded	60 m						
	41	09 45 771 0158	4AWG 22/7 stranded	70 m						
	42	09 45 771 0159	4AWG 22/7 stranded	80 m						
	43	09 45 771 0160	4AWG 22/7 stranded	90 m						
	44	09 45 771 0161	4AWG 22/7 stranded	100 m						
	45	09 45 771 0162	4AWG 22/7 trailing	0.5 m						
	46	09 45 771 0163	4AWG 22/7 trailing	1 m						
	47	09 45 771 0164	4AWG 22/7 trailing	1.5 m						
	48	09 45 771 0165	4AWG 22/7 trailing	2 m						
	49	09 45 771 0166	4AWG 22/7 trailing	3 m						
	50	09 45 771 0167	4AWG 22/7 trailing	4 m						
	51	09 45 771 0168	4AWG 22/7 trailing	5 m						

For Information Only
won't be replaced when changed

			All Dimensions in mm Original Size DIN A 4			Techn. Character.			Nicht tolerierte Maß/Free size tolerances		
				Dat.	Name	Maßstab/Scale 2:1	RJ1 cord, IP20 overmolded, 4xAWG , 1x RJ45 plug, CAT 5				
			Detail.	11.02.08	MS						
			Insp.								
			Stand.								
			HARTING Electronics GmbH & Co. KG				TB 09 45 771 0xxx				Blatt/ page 2/2
34530			D-32339 ESPELKAMP				Sub.				
Mod.	Dat.	Name									

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

HARTING:

[09457710100](#) [09457710101](#) [09457710102](#) [09457710103](#) [09457710104](#) [09457710105](#) [09457710106](#)
[09457710107](#) [09457710108](#) [09457710109](#) [09457710110](#) [09457710111](#) [09457710122](#) [09457710163](#) [09457710171](#)
[09457710124](#) [09457710113](#)