

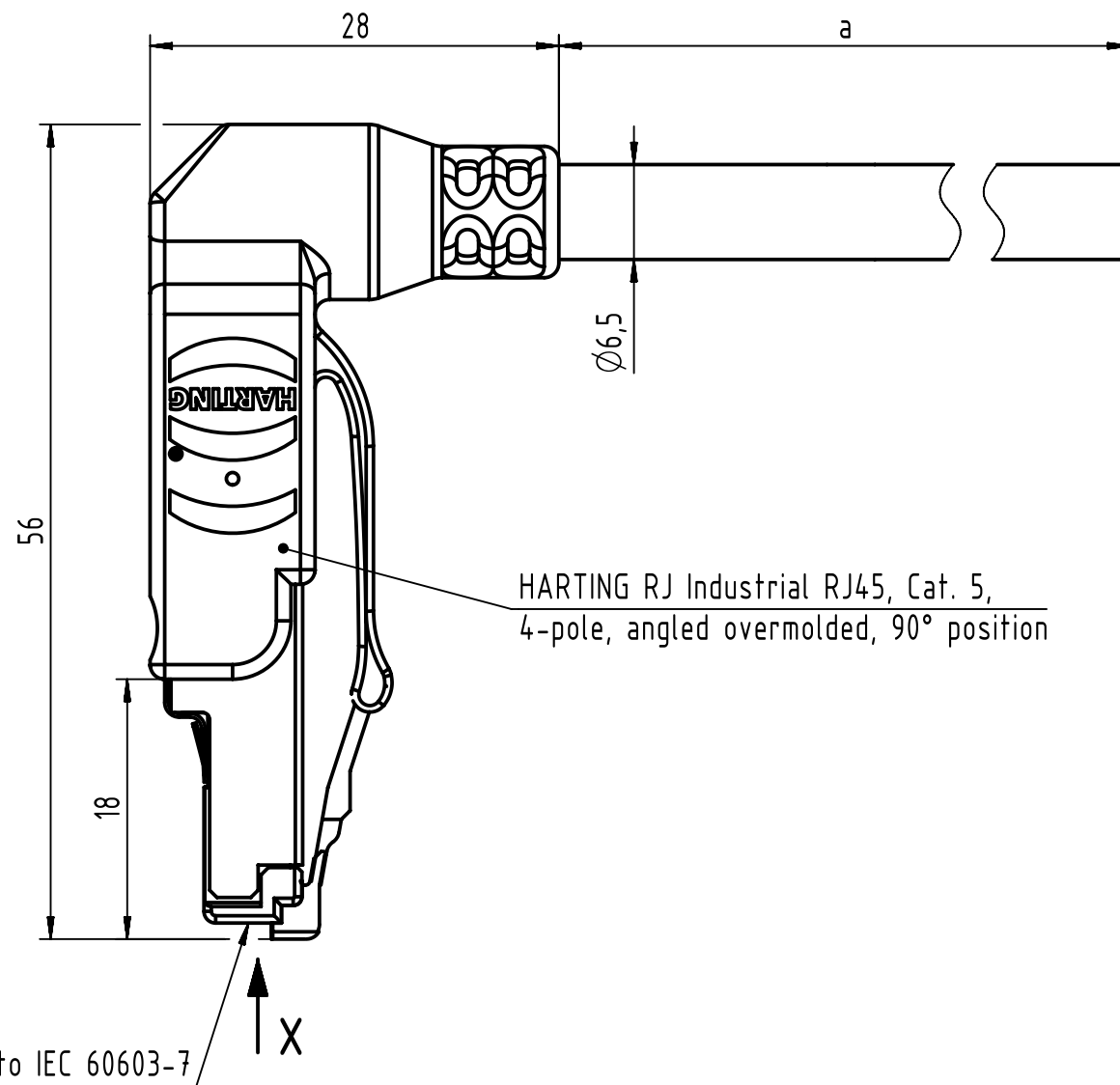


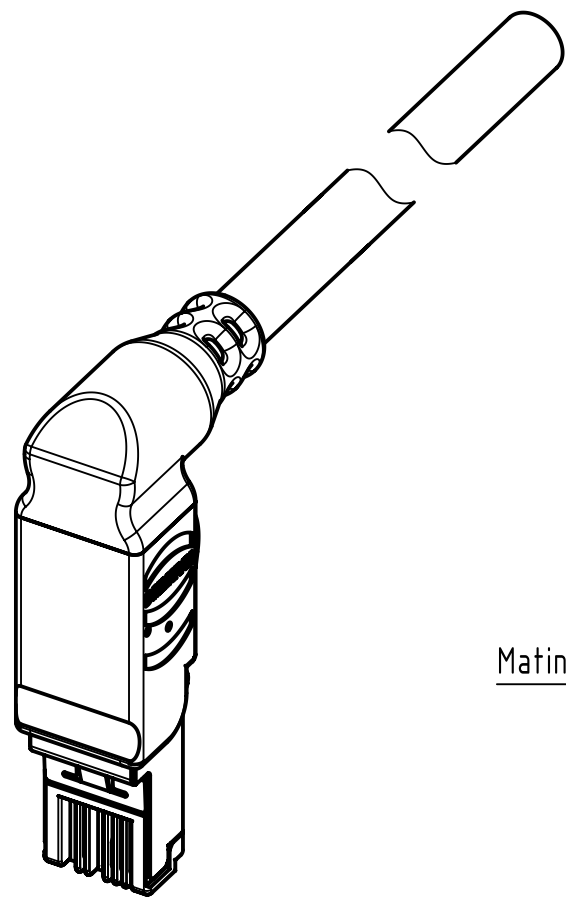


Mating face RJ45 acc. to IEC 60603-7

X

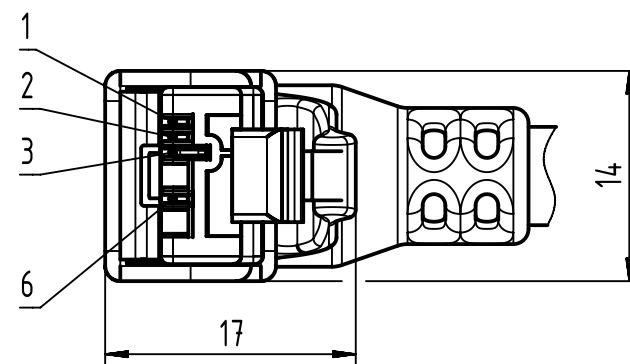

Loading-Plan:

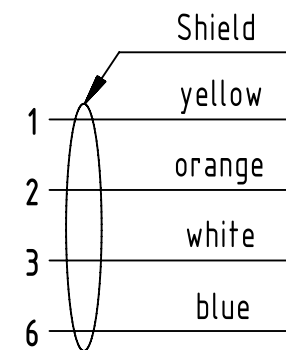

- Protection level: IP20
- Temperature range: -40°C ... +70°C

 		All Dimensions in mm Original Size DIN A3		Scale 2:1		Free size tol.		Ref.	
								Sub.	
		All rights reserved		Created by MUNTEANV		Inspected by AVRAM		Standardisation HOFFMANN	
Department EC PD - RO				Date 2014-11-19		State Final Release			
HARTING Electronics GmbH D-32339 Espelkamp		Title RJ Industrial Cable Assembly						Doc-Key / ECM-Nr. 100155463/UGD/013/B 50000082085	
		Type TB		Number 09470400XXX				Rev. B	Page 1/2

1				2				3				4				5				6				7				8																						
A																	90	09470400088				RJl Ethernet stranded cable, AWG 22/7, 2x2x0.75, outdoor, PVC, Cat. 5+, black				100				A																				
																	89	09470400087								90																								
																	88	09470400086								80																								
																	87	09470400085								70																								
																	86	09470400084								60																								
																	85	09470400083								50																								
																	84	09470400082								40																								
																	83	09470400081								30																								
																	82	09470400080								20																								
																	81	09470400079								15																								
B	45	09470400044								RJl Ethernet stranded cable, 4xAWG22/7, PVC, Cat. 5+, green				100				80	09470400078				10				B																							
	44	09470400043												90				79	09470400077				9																											
	43	09470400042												80				78	09470400076				8																											
	42	09470400041												70				77	09470400075				7																											
	41	09470400040												60				76	09470400074				6																											
	40	09470400039												50				75	09470400073				5																											
	39	09470400038												40				74	09470400072				4																											
	38	09470400037												30				73	09470400071				3																											
	37	09470400036												20				72	09470400070				2																											
	36	09470400035												15				71	09470400069				1.5																											
C	35	09470400134								12				70	09470400068				1				C																											
	34	09470400034								10				69	09470400067				0.5																															
	33	09470400033								9				68	09470400066				100																															
	32	09470400032								8				67	09470400065				90																															
	31	09470400031								7				66	09470400064				80																															
	30	09470400030								6				65	09470400063				70																															
	29	09470400029								5				64	09470400062				60																															
	28	09470400028								4				63	09470400061				50																															
	27	09470400027								3				62	09470400060				40																															
	26	09470400026								2				61	09470400059				30																															
D	25	09470400025								1.5				60	09470400058				20				D																											
	24	09470400024								1				59	09470400057				15																															
	23	09470400023								0.5				58	09470400056				10																															
	22	09470400022								100				57	09470400055				9																															
	21	09470400021								90				56	09470400054				8																															
	20	09470400020								80				55	09470400053				7																															
	19	09470400019								70				54	09470400052				6																															
	18	09470400018								60				53	09470400051				5																															
	17	09470400017								50				52	09470400050				4																															
	16	09470400016								40				51	09470400049				3																															
E	15	09470400015								30				50	09470400048				2				E																											
	14	09470400014								20				49	09470400047				1.5																															
	13	09470400013								15				48	09470400046				1																															
	12	09470400012								10				47	09470400045				0.5																															
	11	09470400011								9				46	09470400145				0.3																															
	10	09470400010								8				Cont. no.	Part no.				Type of cable					Dim. a[m]																										
	9	09470400009								7				 All Dimensions in mm Original Size DIN A3								Scale 1:1				Free size tol.				Ref.																				
	8	09470400008								6												 All rights reserved Department EC PD - RO								Created by MUNTEANV				Inspected by AVRAM				Standardisation HOFFMANN				Date 2014-11-19				State Final Release				
	7	09470400007								5																				HARTING Electronics GmbH D-32339 Espelkamp								Title RJ Industrial Cable Assembly				Doc-Key / ECM-Nr. 100155463/UGD/013/B 500000082085								
	6	09470400006								4																												Type TB				Number 09470400XXX				Rev. B				Page 2/2
5	09470400005								3																																									
4	09470400004								2																																									
3	09470400003								1.5																																									
2	09470400002								1																																									
1	09470400001								0.5																																									
Cont. no.				Part no.				Type of cable				Dim. a[m]																																						
1				2				3				4				5				6				7				8																						

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

HARTING:

[09470400025](#) [09470400026](#) [09470400027](#) [09470400029](#) [09470400045](#) [09470400047](#) [09470400048](#)
[09470400049](#) [09470400051](#) [09470400023](#) [09470400024](#) [09470400046](#) [09470400056](#) [09470400003](#) [09470400067](#)
[09470400002](#) [09470400058](#) [09470400001](#) [09470400007](#) [09470400034](#)